


LED Arbeitsplatzleuchte


LED workplace luminaire

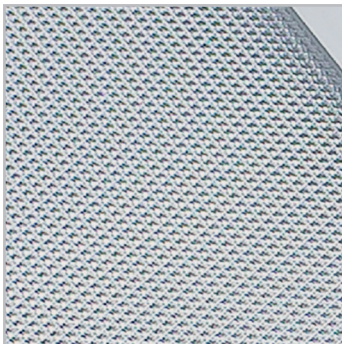

PROFILED DC, 1000 mm, mit Dimmer, Abdeckung Mikroprismen, 24V DC

Artikel-Nr.:	150714-02
EAN:	4260556623832
Zolltarifnr.:	94054099

Bestellnr.:	150714-02
Modell:	PROFILED
Bauform:	Profilleuchte mit T-Nut rückseitig
Leuchtmittel:	SMD LED
Lampenleistung:	~23 W
Lampenlichtstrom:	3565 lm
Lampenlichtausbeute:	145 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte:	24V DC \pm 10%
Anschluss Leuchte:	M12 Steckverbinder A-kodiert
Schutzart:	IP40
Schutzklasse:	III
Entblendung:	Mikroprismen
Abstrahlwinkel:	100°
Betriebstemperatur:	-10... +60 °C
Farbwiedergabe (Ra):	> 85
Lampenlebensdauer:	> 60.000 h
Material Gehäuse:	Aluminium
Material Abdeckung:	Kunststoff
Höhe [B] x Breite [C]:	65 mm x 45 mm
Länge [A]:	1000 mm
Gewicht:	1875 g
Bruttogewicht:	2520 g
Risikogruppe:	freie Gruppe
Befestigungszubehör:	optional
Dimmbar:	Dimmer intern
Kennzeichnung:	CE
Gefertigt in:	Deutschland
Besonderheit:	mit Dimmer, universell als Werkbankleuchte, Systemleuchte oder Industrieleuchte

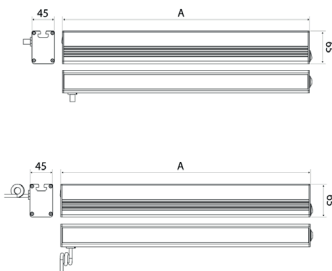

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Arbeitsplatzleuchte
LED workplace luminaire



**PROFILED DC, 1000 mm, with dimmer
micro prisms cover, 24V DC**

Item number:	150714-02
EAN:	4260556623832
Customs tariff number:	94054099

Order number:	150714-02
Model:	PROFILED
Type:	profiled luminaire with t-slot backsided
Illuminant:	SMD LED
Power consumption:	~23 W
Lamp luminous flux:	3565 lm
Lamp luminous efficiency:	145 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	24V DC ± 10%
Connection (connector):	M12 A-type encoded
Degree of protection:	IP40
Class of protection:	III
Glare-free	micro prisms
Beam angle (optics):	100°
Operating temperature:	-10... +60 °C
Colour rendering (Ra):	> 85
Lamps lifetime:	> 60,000 h
Housing material:	aluminium
Cover material:	plastics
Height [B] x Width [C]:	65 mm x 45 mm
Length [A]:	1000 mm
Weight (net):	1875 g
Gross weight:	2520 g
Risk group (DIN EN 62471):	free group
Mounting accessories:	optional
Dimmable:	internal dimmer control
Marking:	CE
Made in:	Germany
Feature:	with dimming control, universally accepted as workbench lighting, system luminaire or industrial light

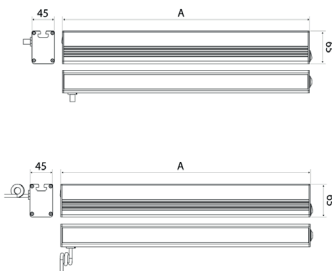

Lamps lifetime in operation hours (L80/B10)