


LED Arbeitsplatzleuchte


LED workplace luminaire

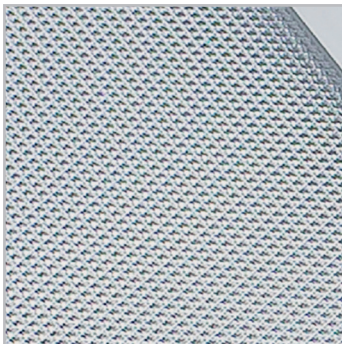

PROFILED AC, 500 mm, mit Dimmer, Abdeckung Mikroprismen, 220-240V AC


Artikel-Nr.:	150314-04
EAN:	4260556623894
Zolltarifnr.:	94054099

Bestellnr.:	150314-04
Modell:	PROFILED
Bauform:	Profilleuchte mit T-Nut rückseitig
Leuchtmittel:	SMD LED
Lampenleistung:	~14 W
Lampenlichtstrom:	1575 lm
Lampenlichtausbeute:	145 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte:	220-240V AC ± 10%, 50-60 Hz
Betriebsgerät:	integriert
Anschluss Leuchte:	3m Anschlussleitung mit SCHUKO Winkelstecker
Schutzart:	IP40
Schutzklasse:	I
Entblendung:	Mikroprismen
Abstrahlwinkel:	100°
Betriebstemperatur:	-10... +45 °C
Farbwiedergabe (Ra):	> 85
Lampenlebensdauer:	> 50.000 h
Material Gehäuse:	Aluminium
Material Abdeckung:	Kunststoff
Höhe [B] x Breite [C]:	65 mm x 45 mm
Länge [A]:	500 mm
Gewicht:	1400 g
Bruttogewicht:	1850 g
Risikogruppe:	freie Gruppe
Befestigungszubehör:	optional
Dimmbar:	Dimmer intern
Kenzeichnung:	CE
Gefertigt in:	Deutschland
Besonderheit:	Universalleuchte mit Dimmer

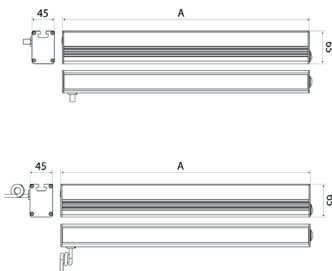

Lampenlebensdauer in Betriebstunden (L80/B10)


LED Arbeitsplatzleuchte
LED workplace luminaire

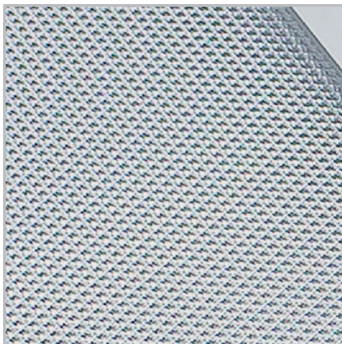

**PROFILED AC, 500 mm, with dimmer
micro prisms cover, 220-240V AC**

Item number:	150314-04
EAN:	4260556623894
Customs tariff number:	94054099

Order number:	150314-04
Model:	PROFILED
Type:	profiled luminaire with t-slot backsided
Illuminant:	SMD LED
Power consumption:	~14 W
Lamp luminous flux:	1575 lm
Lamp luminous efficiency:	145 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	220-240V AC ± 10%, 50-60 Hz
Power supply:	inbuilt
Connection (connector):	connection cable 3 m with angled SHUKO plug
Degree of protection:	IP40
Class of protection:	I
Glare-free	micro prisms
Beam angle (optics):	100°
Operating temperature:	-10... +45 °C
Colour rendering (Ra):	> 85
Lamps lifetime:	> 50,000 h
Housing material:	aluminium
Cover material:	plastics
Height [B] x Width [C]:	65 mm x 45 mm
Length [A]:	500 mm
Weight (net):	1400 g
Gross weight:	1850 g
Risk group (DIN EN 62471):	free group
Mounting accessories:	optional
Dimmable:	internal dimmer control
Marking:	CE
Made in:	Germany
Feature:	universal luminaire, dimmable

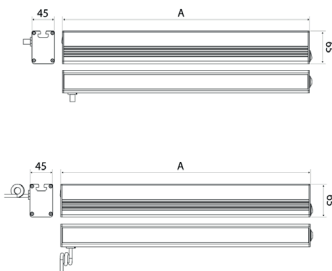

Lamps lifetime in operation hours (L80/B10)