


## LED Arbeitsplatzleuchte


### LED workplace luminaire

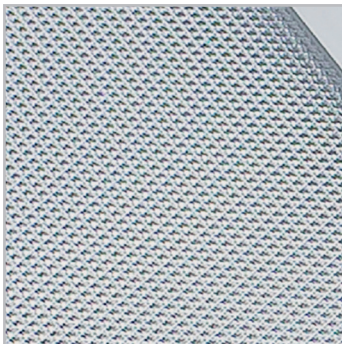

## PROFILED AC, 900 mm, mit Dimmer, Abdeckung Mikroprismen, 220-240V AC


<b>Artikel-Nr.:</b>	150614-04
<b>EAN:</b>	4260556623900
<b>Zolltarifnr.:</b>	94054099

<b>Bestellnr.:</b>	150614-04
<b>Modell:</b>	PROFILED
<b>Bauform:</b>	Profilleuchte mit T-Nut rückseitig
<b>Leuchtmittel:</b>	SMD LED
<b>Lampenleistung:</b>	~27 W
<b>Lampenlichtstrom:</b>	3150 lm
<b>Lampenlichtausbeute:</b>	145 lm/W
<b>Lichtverteilung:</b>	direkt
<b>Lichtfarbe:</b>	Tageslichtweiß (5200 - 5700K)
<b>Anschlusswert Leuchte:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Betriebsgerät:</b>	integriert
<b>Anschluss Leuchte:</b>	3m Anschlussleitung mit SCHUKO Winkelstecker
<b>Schutzart:</b>	IP40
<b>Schutzklasse:</b>	I
<b>Entblendung:</b>	Mikroprismen
<b>Abstrahlwinkel:</b>	100°
<b>Betriebstemperatur:</b>	-10... +45 °C
<b>Farbwiedergabe (Ra):</b>	> 85
<b>Lampenlebensdauer:</b>	> 50.000 h
<b>Material Gehäuse:</b>	Aluminium
<b>Material Abdeckung:</b>	Kunststoff
<b>Höhe [B] x Breite [C]:</b>	65 mm x 45 mm
<b>Länge [A]:</b>	900 mm
<b>Gewicht:</b>	2200 g
<b>Bruttogewicht:</b>	2750 g
<b>Risikogruppe:</b>	freie Gruppe
<b>Befestigungszubehör:</b>	optional
<b>Dimmbar:</b>	Dimmer intern
<b>Kenzeichnung:</b>	CE
<b>Gefertigt in:</b>	Deutschland
<b>Besonderheit:</b>	Universalleuchte mit Dimmer

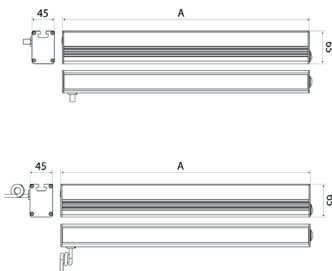

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Arbeitsplatzleuchte  
LED workplace luminaire

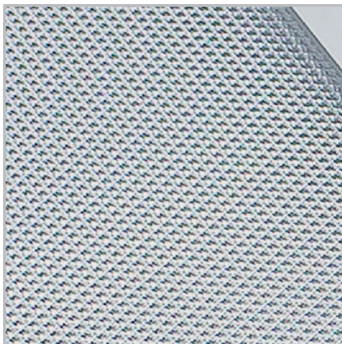

**PROFILED AC, 900 mm, with dimmer  
micro prisms cover, 220-240V AC**

<b>Item number:</b>	150614-04
<b>EAN:</b>	4260556623900
<b>Customs tariff number:</b>	94054099

<b>Order number:</b>	150614-04
<b>Model:</b>	PROFILED
<b>Type:</b>	profiled luminaire with t-slot backsided
<b>Illuminant:</b>	SMD LED
<b>Power consumption:</b>	~27 W
<b>Lamp luminous flux:</b>	3150 lm
<b>Lamp luminous efficiency:</b>	145 lm/W
<b>Light distribution:</b>	direct
<b>Light colour:</b>	daylight white (5200 - 5700K)
<b>Connected load:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Power supply:</b>	inbuilt
<b>Connection (connector):</b>	connection cable 3 m with angled SHUKO plug
<b>Degree of protection:</b>	IP40
<b>Class of protection:</b>	I
<b>Glare-free</b>	micro prisms
<b>Beam angle (optics):</b>	100°
<b>Operating temperature:</b>	-10... +45 °C
<b>Colour rendering (Ra):</b>	> 85
<b>Lamps lifetime:</b>	> 50,000 h
<b>Housing material:</b>	aluminium
<b>Cover material:</b>	plastics
<b>Height [B] x Width [C]:</b>	65 mm x 45 mm
<b>Length [A]:</b>	900 mm
<b>Weight (net):</b>	2200 g
<b>Gross weight:</b>	2750 g
<b>Risk group (DIN EN 62471):</b>	free group
<b>Mounting accessories:</b>	optional
<b>Dimmable:</b>	internal dimmer control
<b>Marking:</b>	CE
<b>Made in:</b>	Germany
<b>Feature:</b>	universal luminaire, dimmable

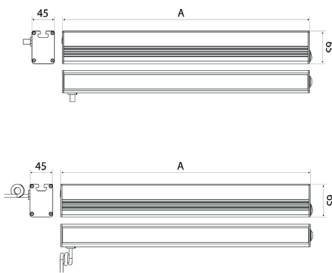

Lamps lifetime in operation hours (L80/B10)