

LED Maschinenleuchte
LED machine luminaire

TUBELED_40 Element AC, 540 mm, 220-240V AC
Artikel-Nr.: 119310-03

EAN: 4260556624433

Zolltarifnr.: 94054099

Bestellnr.: 119310-03

Modell: TUBELED_40 Element

Bauform: LED Aufbauleuchte

Leuchtmittel: SMD LED

Lampenleistung: ~17 W

Lampenlichtstrom: 2060 lm

Lampenlichtausbeute: 127 lm/W

Lichtverteilung: direkt

Lichtfarbe: Tageslichtweiß (5200 - 5700K)

Anschlusswert Leuchte: 220-240V AC ± 10%, 50-60 Hz

Anschluss Leuchte: M12 S-kodiert

Schutzart: IP54

Schutzklasse: I

Entblendung: Diffusor, PMMA

Abstrahlwinkel: 100°

Betriebstemperatur: -30... +50 °C

Farbwiedergabe (Ra): > 80

Lampenlebensdauer: > 50.000 h

Material Gehäuse: Aluminium, Endkappen Kunststoff

Material Abdeckung: PMMA, gefrostet

Höhe [B] x Breite [C]: 29 mm x 40 mm

Länge [A]: 540 mm

Gewicht: 690 g


Bruttogewicht: 900 g

Risikogruppe: freie Gruppe

Kennzeichnung: CE

Befestigungszubehör: optional

Gefertigt in: Deutschland

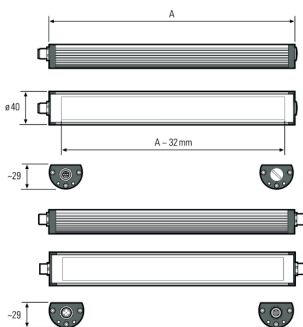Besonderheit: 220-240V AC Anschluss, temperaturbeständig


Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Maschinenleuchte
LED machine luminaire



TUBELED_40 Element AC, 540 mm, 220-240V AC

Item number:	119310-03
EAN:	4260556624433
Customs tariff number:	94054099

Order number:	119310-03
Model:	TUBELED_40 Element
Type:	LED surface-mounted luminaire
Illuminant:	SMD LED
Power consumption:	~17 W
Lamp luminous flux:	2060 lm
Lamp luminous efficiency:	127 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	220-240V AC ± 10%, 50-60 Hz
Connection (connector):	M12 S-type encoded
Degree of protection:	IP54
Class of protection:	I
Glare-free	diffuser sheet for scattered light, PMMA
Beam angle (optics):	100°
Operating temperature:	-30... +50 °C
Colour rendering (Ra):	> 80
Lamps lifetime:	> 50,000 h
Housing material:	aluminium, endcaps made of plastics
Cover material:	PMMA, frosted
Height [B] x Width [C]:	29 mm x 40 mm
Length [A]:	540 mm
Weight (net):	690 g
Gross weight:	900 g
Risk group (DIN EN 62471):	free group
Marking:	CE
Mounting accessories:	optional
Made in:	Germany
Feature:	220-240V AC Anschluss, temperaturbeständig

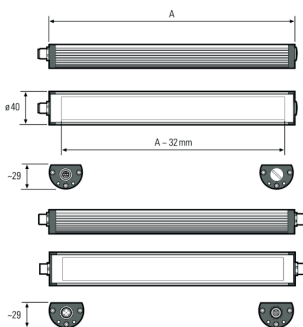

Lamps lifetime in operation hours (L80/B10)