

LED Maschinenleuchte  
 LED machine luminaire


## TUBELED\_40 Element AC, 1540 mm, 220-240V AC

Artikel-Nr.: 119610-03

EAN: 4260556624457

Zolltarifnr.: 94054099

Bestellnr.: 119610-03

Modell: TUBELED\_40 II

Bauform: LED Aufbauleuchte

Leuchtmittel: SMD LED

Lampenleistung: ~51 W

Lampenlichtstrom: 6180 lm

Lampenlichtausbeute: 127 lm/W

Lichtverteilung: direkt

Lichtfarbe: Tageslichtweiß (5200 - 5700K)

 Anschlusswert Leuchte: 220-240V AC  $\pm$  10%, 50-60 Hz

Anschluss Leuchte: M12 S-kodiert

Schutzart: IP54

Schutzklasse: I

Entblendung: Diffusor, PMMA

Abstrahlwinkel: 100°

Betriebstemperatur: -30... +50 °C

Farbwiedergabe (Ra): &gt; 80

Lampenlebensdauer: &gt; 50.000 h

Material Gehäuse: Aluminium, Endkappen Kunststoff

Material Abdeckung: PMMA, gefrostet

Höhe [B] x Breite [C]: 29 mm x 40 mm

Länge [A]: 1540 mm

Gewicht: 1840 g

Bruttogewicht: 2400 g


Risikogruppe: freie Gruppe

Kennzeichnung: CE

Befestigungszubehör: optional

Gefertigt in: Deutschland

Besonderheit: 220-240V AC Anschluss, temperaturbeständig

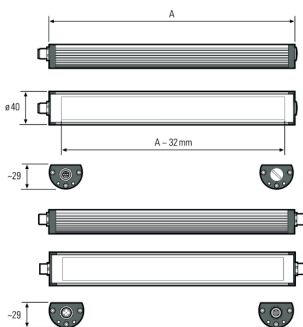

Lampenlebensdauer in Betriebsstunden (L80/B10)


LED Maschinenleuchte  
*LED machine luminaire*



**TUBELED\_40 Element AC, 1540 mm, 220-240V AC**

<b>Item number:</b>	119610-03
<b>EAN:</b>	4260556624457
<b>Customs tariff number:</b>	94054099

<b>Order number:</b>	119610-03
<b>Model:</b>	TUBELED_40 II
<b>Type:</b>	LED surface-mounted luminaire
<b>Illuminant:</b>	SMD LED
<b>Power consumption:</b>	~51 W
<b>Lamp luminous flux:</b>	6180 lm
<b>Lamp luminous efficiency:</b>	127 lm/W
<b>Light distribution:</b>	Light Forming Technology
<b>Light colour:</b>	daylight white (5200 - 5700K)
<b>Connected load:</b>	220-240V AC ± 10%, 50-60 Hz
<b>Connection (connector):</b>	M12 S-type encoded
<b>Degree of protection:</b>	IP54
<b>Class of protection:</b>	I
<b>Glare-free</b>	diffuser sheet for scattered light, PMMA
<b>Beam angle (optics):</b>	100°
<b>Operating temperature:</b>	-30... +50 °C
<b>Colour rendering (Ra):</b>	> 80
<b>Lamps lifetime:</b>	> 50,000 h
<b>Housing material:</b>	aluminium, endcaps made of plastics
<b>Cover material:</b>	PMMA, frosted
<b>Height [B] x Width [C]:</b>	29 mm x 40 mm
<b>Length [A]:</b>	1540 mm
<b>Weight (net):</b>	1840 g
<b>Gross weight:</b>	2400 g
<b>Risk group (DIN EN 62471):</b>	free group
<b>Marking:</b>	CE
<b>Mounting accessories:</b>	optional
<b>Made in:</b>	Germany
<b>Feature:</b>	220-240V AC Anschluss, temperaturbeständig

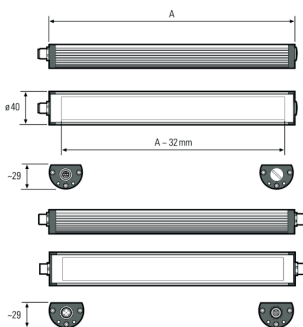

Lamps lifetime in operation hours (L80/B10)