

Technaxx[®] * User Manual

Nostalgia Bluetooth

All-in-One Record Converter TX-103

The manufacturer Technaxx Deutschland GmbH & Co.KG hereby declares that this device, to which this user manual belongs, complies with the essential requirements of the standards referred to the Directive **RED 2014/53/EU**. The Declaration of Conformity you find here: www.technaxx.de/ (in bar at the bottom "Konformitätserklärung"). Before using the device the first time, read the user manual carefully.

Service phone No. for technical support: **01805 012643** (14 cent/minute from German fixed-line and 42 cent/minute from mobile networks).
Free Email: support@technaxx.de

Keep this user manual for future reference or product sharing carefully. Do the same with the original accessories for this product. In case of warranty, please contact the dealer or the store where you bought this product. **Warranty 2 years**



Features

- Digitizing vinyl records/cassette/CD or AUX-IN to USB or SD card up to 32GB
- Music playback & recording via Bluetooth 2.1
- Playback of MP3/WMA music files from USB/CD/SD/Bluetooth devices
- Recording of MP3 music files on USB or SD card up to 32GB
- No computer/notebook required
- RCA output for connection to HiFi systems
- Record player with automatic/manual stop & 3 speeds: 33, 45, 78rpm
- Built-in stereo loudspeakers
- Built-in cassette & CD players
- Built-in FM radio
- 3.5mm AUX-IN & 3.5mm headphone jack
- High quality nostalgia design with functional handling

Contents

Features.....	1
Contents	2
Technical specifications.....	3
Product Overview	5
First start	8
CD Mode	13
USB/SD Mode.....	16
Bluetooth Mode.....	18
Tape Mode	19
AUX Mode.....	20
Radio Mode	21
Stand-by function	22
FAQ's	22


Before usage

- Choose the installation location of your unit carefully. Avoid placing it in direct sunlight or close to a source of heat. Also avoid locations subject to vibrations and excessive dust, heat, cold or moisture.
- Do not install the unit in a inclined position, It is designed to be operated in a horizontal position only.
- If the unit is brought directly from a cold to a warm location, moisture may condense inside the player, and cause damage it. When you first install the unit, or when you move it from a cold to a warm location, wait for 30 minutes before operating the unit.
- The ventilation holes should not be covered. Make sure there is enough space above and beside the amplifier/receiver. Do not place a CD player or other equipment on top of the device.
- Do not open the cabinet. This might cause a damage to circuitry or electrical shock.
- If you are not going to use the player for long time, be sure do disconnect the player from the AC power source. When removing the power plug, never yank the cord.
- To prevent fire or shock hazard, disconnect your unit from the AC power source when cleaning. Use caution when cleaning and wiping the plastic parts. Do not attempt to clean the unit with the chemical solvents as this might damage the finish.

Technical specifications


Bluetooth	V2.1; profil A2DP, EDR & HFP; distance ~8m open areas	
Bluetooth transmitting frequency 2.4GHz		
Radiated output power max. 2.5mW		
Mode	Phono, Cassette, CD, USB, Bluetooth, SD, AUX-IN, FM radio	
Speakers	2x 4W stereo loudspeakers (10x10x2cm), input \leq 60mV/30k Ω , impedance 4 Ω , frequency range 60Hz–16kHz	
Radio	88-108MHz (FM); antenna cable	
CD	Playing & recording function; format: CD-DA/CD-R/CD-RW/ MP3/WMA; frequency 20Hz–20kHz \pm 3dB; S/N >60dB	
Cassette	Playing & recording function; 4 track 2 channel format; 1x playhead; \leq C-90; speed 4.8cm per second; frequency 127Hz–3.6kHz / S/N \geq 25dB	
Phono	Turnable: EP/LP/SP; DC motor; speeds: 33/45/78rpm; S/N \geq 45dB; needel cartridge (402–M208-015); belt-drive & semi-automatic play tone pickup arm	
AUX-IN & Headphone	3.5mm jack	
RCA output	Cinch (Left & Right)	
Input voltage / current	DC 12V / 2A	

Power consumption	Max. 24W
Weight / Dimensions	7kg / (L) 44.5x (W) 33.5 x (H) 23.5cm
USB flash drive & SD card	
Size	max. 32GB
Playing format	MP3, WMA
Recording format	MP3 128kbps
Folders	99 maximum
Files	999 maximum
Recording time	Use of 4GB memory equals max. ~65 hours recording time
SD card memory	SD, SDHC, Micro SD, Micro SDHC, corresponding class 10
Package Contents	
Nostalgia Bluetooth All-in-One LP Converter TX-103, 45rpm single Puck adapter, power adapter, User Manual	

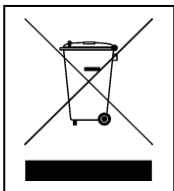

Hints for Environment Protection: Packages materials are raw materials and can be recycled. Do not disposal old devices or batteries into the domestic waste. **Cleaning:** Protect the device from contamination and pollution (use a clean drapery). Avoid using rough, coarse-grained materials or solvents/aggressive cleaner. Wipe the cleaned device accurately. **Distributor:** Technaxx Deutschland GmbH & Co.KG, Kruppstr. 105, 60388 Frankfurt a.M., Germany (**aus dem BT-X32 nehmen**)


Product Overview

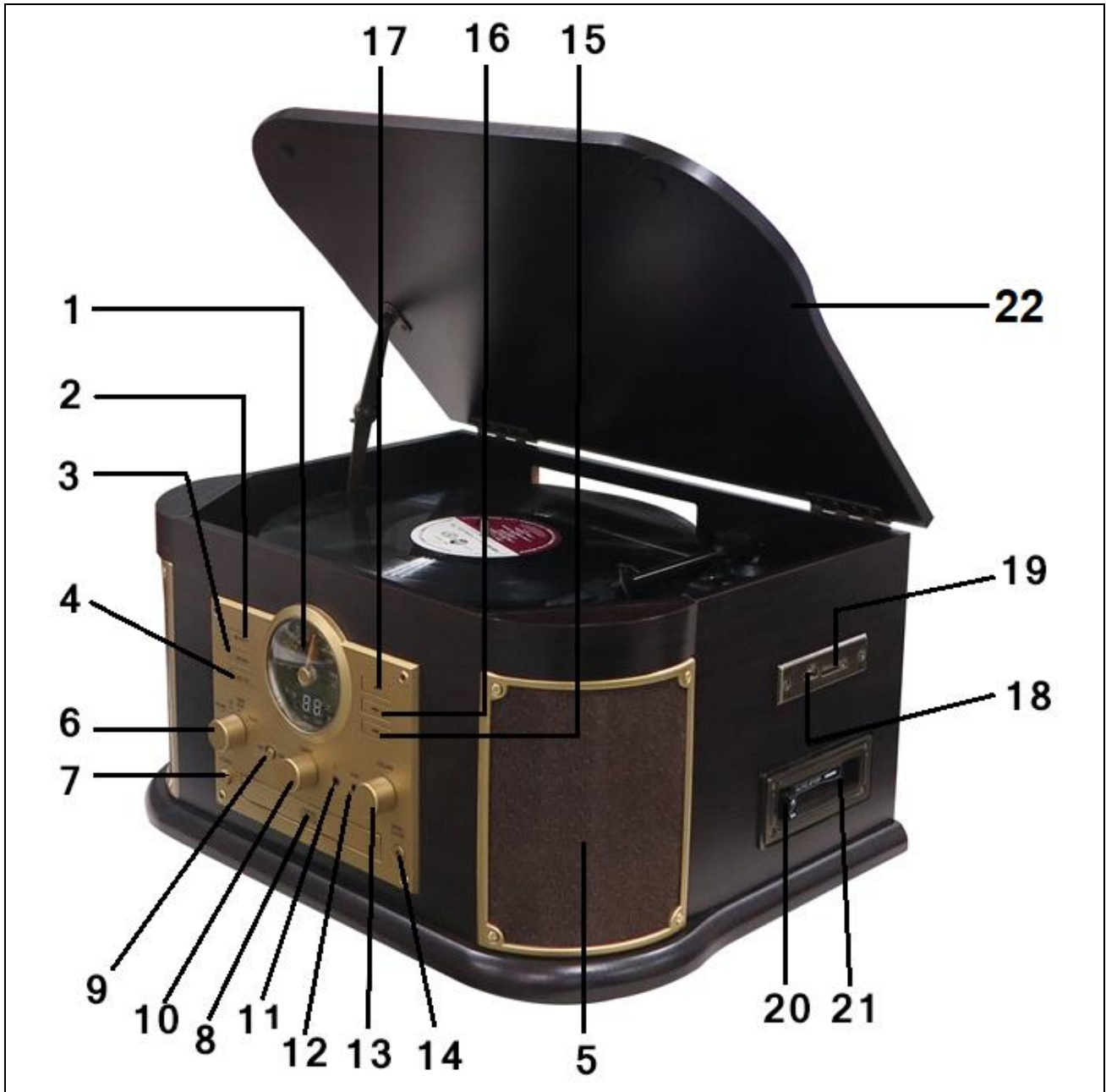


Front View and Top View

1	Display Panel		
2	Stop: Stop playback in CD/USB/SD modes; stop recording. CD/USB/SD: Switch to USB, SD card or CD modes		
3	Record/Delete	4	Repeat/Program
5	Stereo speakers (one on each side, 2x 4W)		

6	Function Knob: Rotate the knob to select Phono, CD (USB/SD), AUX/Tape or Radio/BT		
7	Power	8	Compact Disc Tray
9	Slide switch: Select FM/BT in RADIO mode	10	Tuning Knob: Tune to a radio station in RADIO mode
11	3.5mm Earphone jack	12	3.5mm AUX-IN jack
13	Volume knob	14	Open/Close CD tray
15	“ << ” Press to select previous track or press and hold to fast CD/USB/SD/BT reverse		
16	“ >> ” Press to select next track or press and hold to fast forward in CD/USB/SD/BT modes		
17	Play/Pause: Playback in CD/USB/SD/BT mode. The Play Indicator illuminates during playback of CD/USB/SD		
18	USB port	19	SD card slot
20	Tape operation button (Eject/Fast Forward cassette)		
21	Cassette Tray	22	Dust Cover

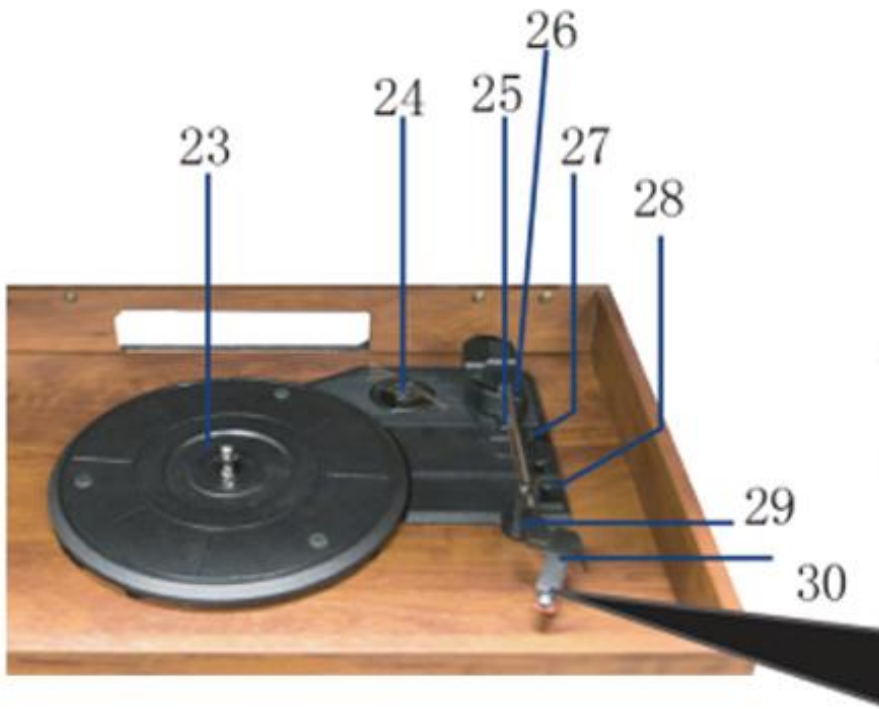


Before use, detach stylus guard (white plastic cover) by pulling it straight off the front of the cartridge in the direction of the arrow.

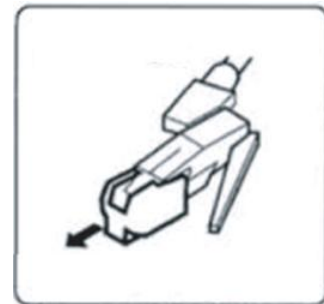

23	Turntable	24	45 RMP adapter
25	Tone arm	26	Cue-Lever: Use this lever to lift the tone arm
27	Auto switch (stopp for records)	28	Speed selector
29	Tone arm lock	30	Cartridge with stylus

Back view

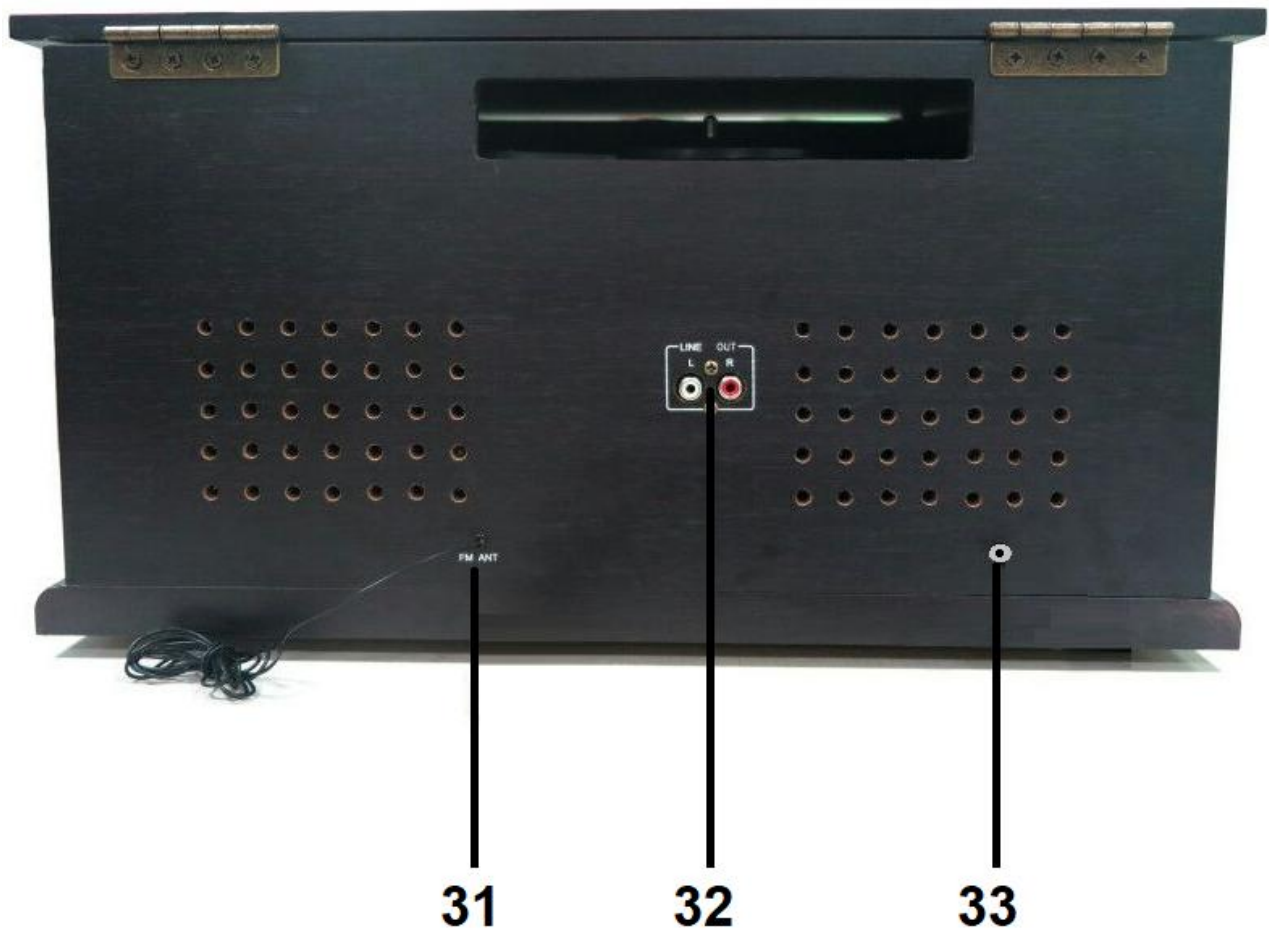

31	FM antenna	32	RCA (left & right) output
33	Hollow plug socket (DC12V/2A)		

First start

Carefully read the manual. Plug the power adapter into a 100-240V AC outlet and the other end into the TX-103 (33). Be reminded: “Non-connected devices always work faulty”. Power on the device by pressing the Power button (7). After that start the mode you like to playback.

Phono mode (Vinyl)

Open the Turntable Cover

- Lift the Turntable cover all the way up until it stops.
- Lower the cover slowly until the latch engages.

If the latch does not engage, pull the lower bar by hand.

- The cover will now stay open.


Close the Turntable Cover

- Lift the cover all the way up until it stops.

- The latch should disengage. Slowly lower the cover.

If the latch does not disengage, push out the lower bar by hand.



- Make sure you hold the cover carefully to avoid pinching your fingers as it closes.

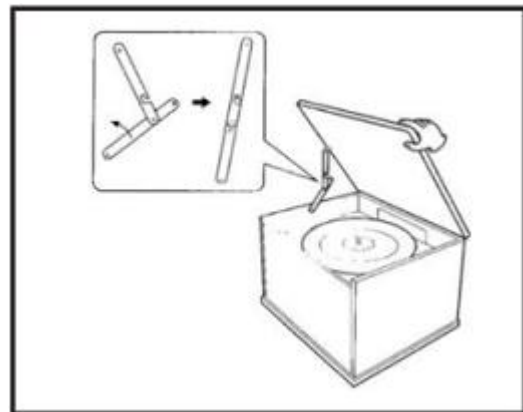

Vinyl records hints


- Do not touch the records grooves. Only handle records by their edges or the label. Ensure that your hands are clean, as skin oil will gradually deteriorate the record
- Keep your records away from dust and store in a dry, cool place.
- Keep your records in sleeves when not in use to avoid dust and scratches.
- Store records upright. Records stored horizontally will bend and warp.
- Do not store records in the trunk of a car.
- Store records in an area with a stable temperature and low humidity.
- To clean, gently wipe the surface in a circular motion using a soft anti-static Cloth.

1 Label / 2 Grooves / 3 Edge

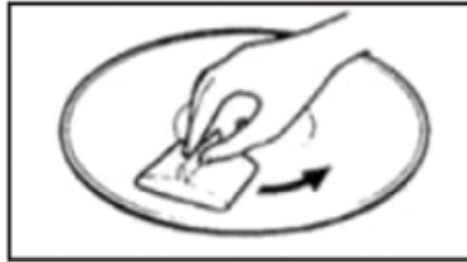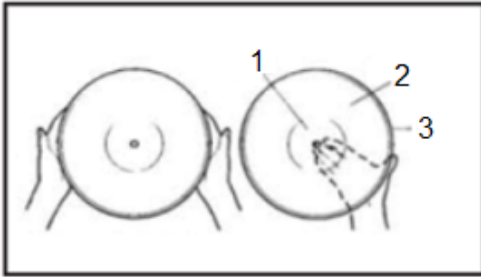

Playing a record (! IMPORTANT !)


When using the turntable, make sure to remove the stylus protector (2). It should easily slide off the cartridge stylus assembly (1). Furthermore make sure to unclip the tone arm lock before use and to secure it again after use.

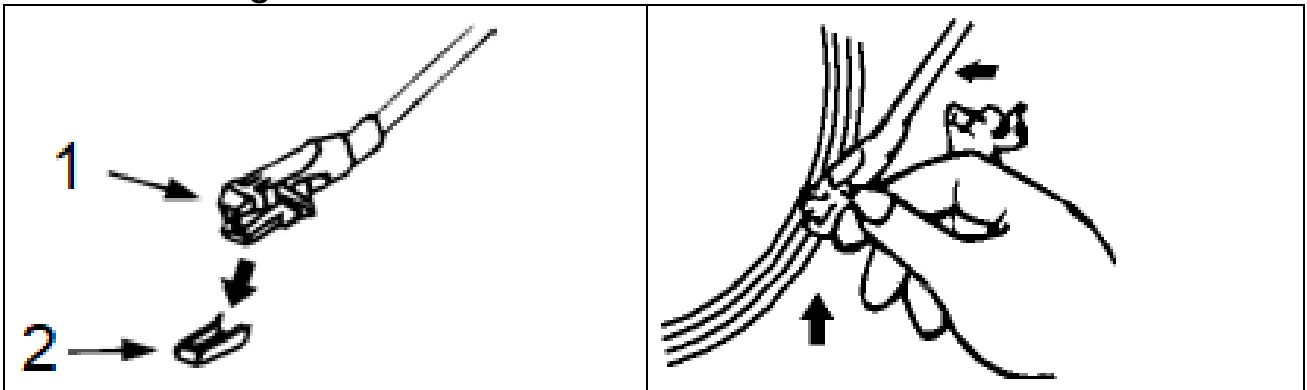

- Turn On the unit and adjust the volume to an appropriate level.
- Turn the Function knob to the PHONO position.
- Place a record on the turntable platter and select the correct player speed: 33/45/78rpm according to the vinyl being played. When playing a 45rpm record, use the included 45 adaptor.



- Set the auto/manual stop control: Set the Auto Stop switch to ON to stop the turntable turning when the record is finished. If the switch is set to OFF, the turntable will continue turning.
- Remove the stylus guard and unlock the tone arm lock.
- Push the lift lever up to raise the tone arm and then gently move the tone arm to the desired position over the record.

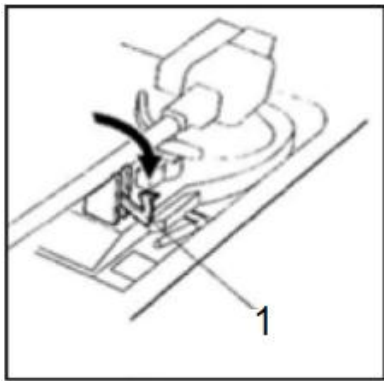



1 = Clamper

The platter will begin to spin when the Tone Arm is moved toward the record. Push the Lift Lever forward to lower the Tone Arm slowly onto the desired position on the record. The record will begin playing.

- If the auto switch is turned to ON, the record will stop playing automatically. If it is set to OFF, the record will not stop automatically.
- When the record is finished, push the Lift Lever backwards to raise the Tone Arm and gently move it back to its rest position.
- When you have finished playing records, engage the Tone Arm lock to protect it from accidental movement. Press the Power button to switch the unit OFF. Unplug it from the power supply if it is not going to be used for a while.

NOTE: Should your record stop before the last track finishes, set the Stop switch to OFF. Your record will now play to the end, but you will have to stop the turntable rotation manually.

1 Tone Arm / 2 Cue Lever

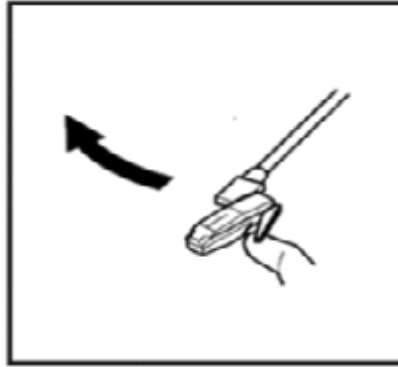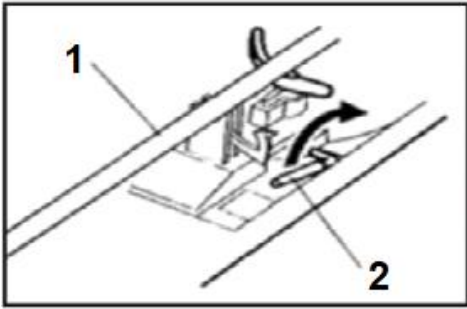

Replacing the Stylus

It is recommended that the stylus is replaced as soon as you notice a change in the sound quality. Prolonged use of a worn-out stylus may damage the record. Wear and tear on the stylus will be accelerated when playing 78 RPM records.


A: Removing the stylus from the cartridge

Place a screwdriver at the tip of the stylus head shell and push downwards in the direction shown in sketch "A". Remove the stylus head shell by pulling it forwards and pushing downwards.

B: Installing the new stylus

Hold the tip of the stylus head shell and insert it by pressing in the direction illustrated by "B". Push the stylus head shell upwards in the direction illustrated by "C" until the stylus locks into the tip position.

(1) Guide pins inside

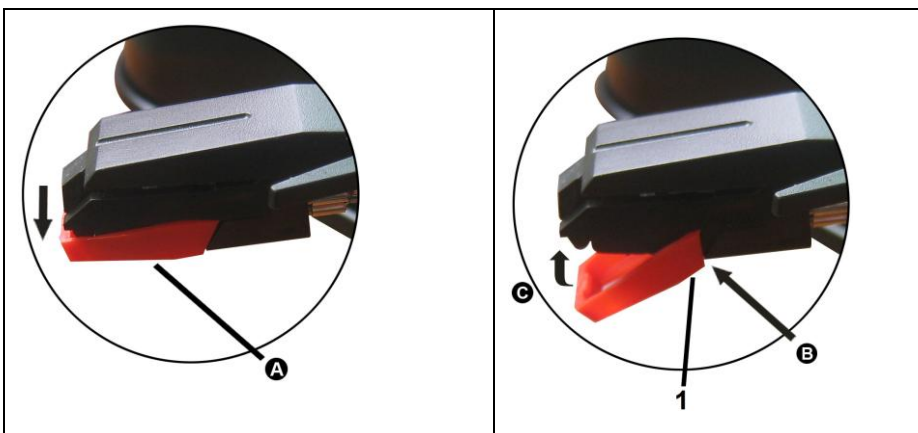


Caution

- Do not bend the stylus.
- To avoid injury, do not touch the needle.
- Turn off the unit's power before you replace the stylus.
- Keep out of reach of children.
- Handle with care as the stylus is delicate. Use of a bent or broken stylus may damage the record and cause malfunction.
- Do not expose the stylus to extreme heat.
- Contact a qualified repair person if you are having difficulties changing

CD Mode


Compact Discs hints

- This Turntable is compatible with conventional audio CDs and properly finalized CD-R and CD-RW discs.
- Always place the disc in the disc tray with the label side facing up. (Compact discs can be played or recorded on one side only.)
- To remove the disc from its storage case, press down on the centre of the case and lift the disc out, holding it carefully by the edges.
- Should the disc become dirty, wipe the surface in a circular motion from the centre whole outwards with a soft, dry cloth.

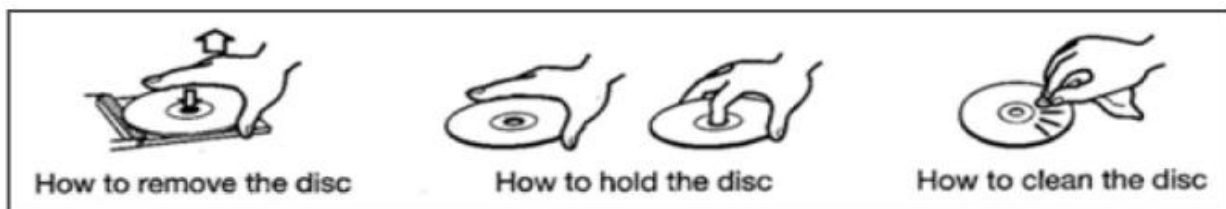

- Never use chemicals such as record sprays, antistatic sprays or fluid, benzene or thinner to clean the disc. Such chemicals will do irreparable damage to the discs plastic surface.
- Place the disc back in its case after use to avoid dust and scratches.
- Do not expose discs to direct sunlight or high temperatures for extended periods of time. Long exposure to high temperatures will warp the disc.
- Playing warped discs may damage the unit.


- Printable discs are not recommended for use with this unit as the label side may be sticky and damage the unit.
- Do not use protective coating spray on the discs.
- Do not write on discs with ball point or hard tipped pens. Only use oil-based felt tipped pens.
- Do not use stabilizers. Using commercially available CD stabilizers may cause damage to this unit.
- Do not use CD's with an irregular shape as they may damage the Unit.

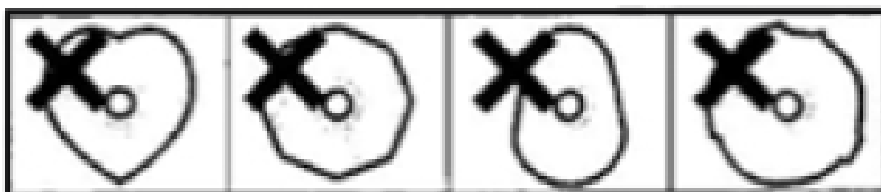

- If you have any doubts about the care and handling of a disc, read the precautions supplied with the disc, or contact the manufacturer directly.

Playing a CD

- Turn the unit ON by pressing the Power button. Set the function knob (PHONO/CD/AUX/RADIO) to CD.
- “- -” will blink for a few seconds. When no disc is loaded “no” will appear on the display screen.

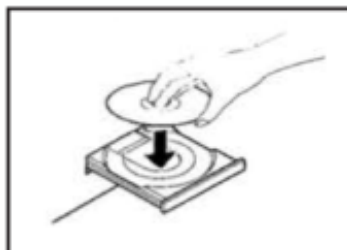

- Place a disc on the tray with the printed label facing up.
- Do not place more than one disc in the tray at a time.
- The disc must be placed in the centre of the disc tray. If the disc is not properly inserted, it may not be possible to get the disc out once it has closed.

- Do not force the tray by hand when it is opening and closing.
- Press the OPEN/CLOSE button (▲) to close the tray.
- The total number of tracks will appear on the display screen.
- The system will start playback automatically after several seconds, or press the PLAY/PAUSE button (▶||) to start playback.
- Disc playback starts from the first track, and the PLAY indicator will illuminate.
- During playback, the number of the track playing will display on the screen.
- Turn the Volume knob to adjust the volume.
- Press the PLAY/PAUSE button (▶||) during playback. Playback will stop at the current position and the track number will blink on the display screen.
- To resume playback, press the PLAY/PAUSE button (▶||) again.
- Press the STOP button (■) to stop playback.

To Skip to the Next or Previous Track

- During playback, repeatedly press the NEXT/PREVIOUS buttons (▶▶/◀◀) until the desired track is found. The selected track will play from the beginning.
- In STOP mode, press the NEXT/PREVIOUS buttons (▶▶/◀◀) repeatedly until the desired track is found. Press the PLAY/PAUSE button (▶||) within 5 seconds to start playback from the selected track.
- When the PREVIOUS (◀◀) button is pressed during playback, the track being played will restart from the beginning. To return to the beginning of the previous track, press the PREVIOUS button (◀◀) twice.

Search for Part of a Track

- During playback, hold down the NEXT or PREVIOUS buttons (▶▶/◀◀) for fast forward/backward, then release when the desired section is found.

Repeat Function

- During playback, press the REPEAT button once to repeat a single track. The “REP” LED indicator light will blink.
- During playback, press the REPEAT button one more time to repeat all tracks. The “REP” LED indicator light will stay lit.

Program Function

- In STOP mode, press the PROGRAM button. The display will show “01”.
- Press (▶▶/◀◀) to select a track and press the PROGRAM button again to save the track.
- Press (▶▶/◀◀) to select another track and press the PROGRAM button again. Repeat this step to continue saving tracks.
- To play back the programmed tracks, press the PLAY/PAUSE(▶||) button.
- To erase the programmed track, press the STOP (■) button twice.

USB/SD Mode

USB/SD Card Playback

- Turn ON the unit and adjust the volume to an appropriate level.
- Insert a USB device into the USB port. Alternatively insert a SD card into the SD card slot, making sure to insert it straight without bending.
- Turn the function knob to CD position.
- To play music from the USB drive, press and hold the “■ /USB/SD” button for 2 seconds until “Ud” flashes on the display and let go of the button. Music playback will start automatically.
- To play music from an SD card, press and hold the “■ /USB/SD” button for 2 seconds again until “Sd” flashes on the display and let go of the button. Music playback will start automatically.

Playback controls

- To pause playback, press the PLAY/PAUSE (▶||) button once to halt playing. Press it again to continue playback.
- To play the previous track, press ◀ once or hold down continuously to rapidly progress through previous tracks.
- To play the next track, press ▶ once or hold down continuously to rapidly advance through tracks.
- To delete a file on your media storage device, while in playback mode, press and hold the REC/DEL button until the “DEL” LED light flashes along with “dL” on the display. Then press REC/ DEL again and the “DEL” LED will flash rapidly and the file will be deleted.
- To delete a file on your media storage device: While in STOP mode, select the track by pressing ▶ or ◀, press and hold the REC/DEL button until the “DEL” LED light flashes along with “dL” on the display. Then press the REC/DEL again and the “DEL” LED will flash rapidly and the file will be deleted.
- To stop playback of the music track, press the ■/USB/SD button.

Recording onto a USB flash drive/SD Card

This equipment has the capacity to encode your traditional music media (vinyl records, cassette tapes or CDs via AUX IN) into digital format and record it onto a USB device or SD card as MP3 file(s).

- Insert a storage device (USB or SD card) into the relevant slot.
- Get your traditional music media ready for playback: Either place a record on the turntable, insert a cassette tape into the cassette slot, insert a CD into a CD player or connect a different recording medium to the AUX IN socket.
- Set the function switch to the appropriate function: PHONO, CD or AUX.

NOTE: If you are recording via Cassette, make sure an AUX IN cable is not connected to AUX socket.

- Press the REC button to start recording. “rE” will appear on the display screen and the “REC” LED will illuminate. A few seconds later the “REC” LED will start flashing and recording will begin.

Then start playing your traditional music media.

- Press the STOP button to stop recording. The music track(s) will be saved directly on the USB flash drive/SD card as MP3 file(s).

NOTE: ● The recording volume level can be adjusted with the Volume control knob. ● The recording speed is 1:1. Recording will take as long as playing the record, cassette tape or CD. ● The recording format is preset at MP3 bit rate 128 kbps.

Bluetooth Mode

Bluetooth playing

Select the function switch to the “FM/Bluetooth” position and slide the slide switch to Bluetooth. The LED of display window will show “bt”.

Then you should turn on your phone or other media device and start the Bluetooth searching function, receive carrier will receive the Bluetooth identification number for: “**Technaxx TX-103**”, when your Bluetooth device is connected, the speaker will beep.


And at the same time, select the ►► or ◀◀ or ►|| or ■, which can make you pause, interrupt or stop the songs. To quit the function, set the slide switch from Bluetooth to FM or simply turn the function switch.

Attention: If you reboot the machine, you should repeat those steps to get the Bluetooth function restarted. Under the Bluetooth function situation, it's not available for the hands-free function. The last connected device connects automatically.

Tape Mode

Cassette Tape hints

- Metal and Chrome (cobalt) tapes have identification holes.
- Use your finger or a pencil to turn the cassette tape's hub and take up any slack tape.
- Avoid touching the tape. Finger prints attract dust and dirt.
- Avoid dropping or subjecting cassettes to excessive shock or force.

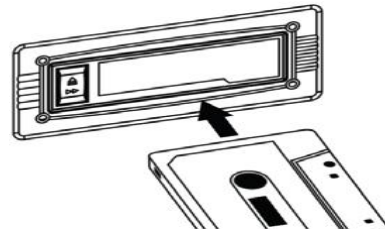


IMPORTANT when using the cassette deck: ● Make sure to insert the cassette in the correct direction.

- To avoid damaging the cassette, we strongly recommend taking it out of the equipment after playing the cassette.

Playing a cassette


- Turn ON the unit and adjust the volume to an appropriate level.
- Turn the Function knob to Cassette/AUX and the display will show "tP"

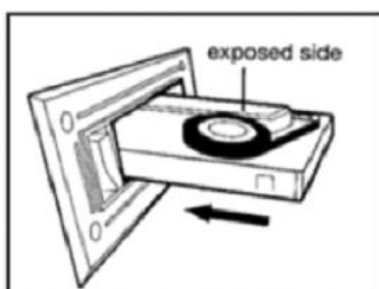

exposed side =

- Insert a pre-recorded tape into the cassette slot with the tape side to the right. By pushing slightly, the tape will slide into place and begin playing automatically.

NOTE: ● To fast forward the cassette tape, press the Tape Operations button halfway down while the cassette is playing. ● To resume normal playback, release the Tape operations button. ● To stop playback, press the Tape Operations button completely. Playback will be stopped and the cassette will be ejected.

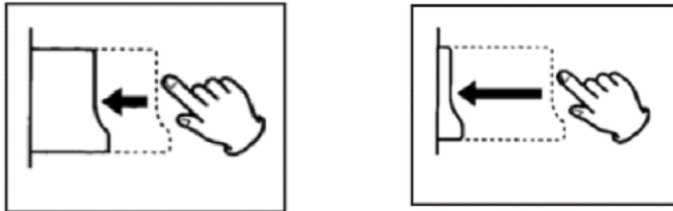


AUX Mode

Playing Music from an AUX input

- Turn the unit ON by pressing the Power button.
- Set the Function knob (PHONO/CD/AUX/RADIO) to the AUX position.
- Connect one end of the 3.5mm AUX-IN cable (not included) into the 3.5mm AUX-IN Jack on the front panel of the unit and the other end to your audio device's (CD player, Tablet, MP3 player, Smartphone etc.).
- Press PLAY on the external audio source.

NOTE: ● The volume output is affected by the volume level on the source. Ensure that the source volume is set to about 70-80% to avoid sound distortion. ● Playback cannot be controlled from the front panel when using AUX IN mode. Playback must be controlled from your connected audio device.

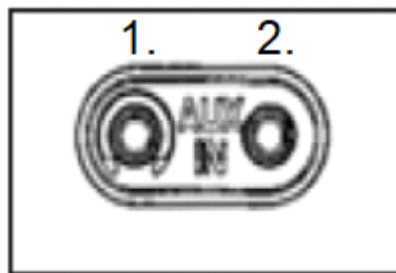

1. Headphone

2. AUX-IN

Connecting to headphones

- Adjust the volume to an appropriate level before you put on your headphones.
- Plug in your 3.5mm headphone jack to the headphone socket.

Connecting to an external amplifier

- This feature enables you to play turntable music through amplifier or external speakers. You will need an RCA cable to make this connection (not included).
- Plug one end of the Red and White RCA jacks into the LINE OUT ports at the back of the TX-103 and the other end into R (red) and L (white) sockets at the back of the amplifier or external speakers.

Radio Mode


FM Antenna

While in FM mode, tune in to an FM station and extend the antenna to find a position that provides the best reception. The antenna may need to be repositioned if you move the unit to a new location.

Playing the Radio

- Turn ON the unit and adjust the volume to an appropriate level.
- Turn the Function knob to the RADIO position.
- Extend the antenna to obtain the best reception.
- Set the slide switch (9) to FM
- Turn the Tuning knob to your desired radio station.

If reception is poor: *FM Broadcast:* Extend and move the FM antenna until you receive the station clearly.

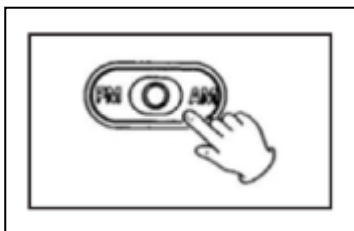

Stand-by function

- When the device is not playing music on Phono, CD, USB, SD, AUX, Tape, long press “REP/PROG/STBY” button for 4 seconds, the unit will enter into standby mode. Then short press “▶||” button, it will work again.
- The Unit will enter into standby mode automatically after approx. 15 minutes when it is not playing music. Then short press “▶||” button, it will work again.

FAQ's

Device will not power on → Make sure that the unit's power cord is connected to an appropriate electrical outlet and the wall socket is switched on.

There is no sound → Rotate the power/volume knob clockwise to increase the volume.

The cassette tape will not play → Make sure the function knob is set to your desired function. Make sure it is properly inserted.

The vinyl record will not play → Make sure the function knob is set to your desired function. Make sure you have selected the right speed (33, 45 or 78 RPM).

Nothing will play via the AUX IN connection → Make sure the cable is firmly connected and check if external device is clean and undamaged. Check the function knob is set to your desired function. Check that volume of external device is at 70-80%.

Nothing will play via the USB device or SD card → Make sure the memory device is properly inserted in the USB port (or SD card slot) and the correct function is selected. The media may need to be formatted.

NOTE: If normal operation cannot be obtained, unplug the power cord from the power outlet and plug it in again.

Important Hints

- **Unpacking and handling:** Open the carton carefully and remove the

packing. Remove the poly-bag and retain all packaging for future use. Keep all packaging away from small children and animals.

- **Positioning the music centre:** Place the equipment on a stable surface, away from any heat sources, and ensuring adequate ventilation around the music centre.

- **Ventilation and heat sources:** Do not place material over any ventilation slots during use, this will cause the device to overheat and fail. Do not place the device in direct sunlight or near heat sources such as radiators or fires.

- **Candles and open flames:** Do not place lighted candles or tea lights on top of, or at the sides of the music centre. Do not allow any naked flames near the cabinet.

- **Connections:** When connecting the music centre to the mains supply, do not place wires that can be tripped over. Do not trap or place heavy objects on the mains lead.

- **Moisture:** Do not place the equipment in wet or damp conditions, such as steamy kitchens, bathrooms or basements. Do not allow water or other fluids to enter the equipment. Do not touch the mains plug or adaptor with wet hands. Should moisture enter the music centre, disconnect from the power supply.

- **Cleaning and care:** Disconnect the music centre from the mains power supply. Use a soft dry cloth, or for stubborn stains use a soft cloth with a dilute mild detergent. Do not use alcohol-based fluids or abrasive materials.

DO NOT

- Do not use this unit for anything other than its intended to use.
- Do not drop/ bump/shake the device
- Do not use the unit if it has been damaged in any way.
- Do not open/repair/disassemble the device
- Do not store the device in high temperature environment/close to open fire/in humid, damp or erosive environments/into water.
- **Stop using** when unusual smell/heating distortion/color-change of the shell material or other abnormal situation happens.
- **Keep away from** children/persons without enough mental ability/persons without enough knowledge to use this product.