

TECHNAXX<sup>®</sup>  
GERMANY

# DigiScan DS-02



TECHNAXX<sup>®</sup>  
GERMANY


# DigiScan DS-02



Negative films & slide films scanner with 2.4" TFT display



Portable scanner with 5 mega pixel CMOS sensor

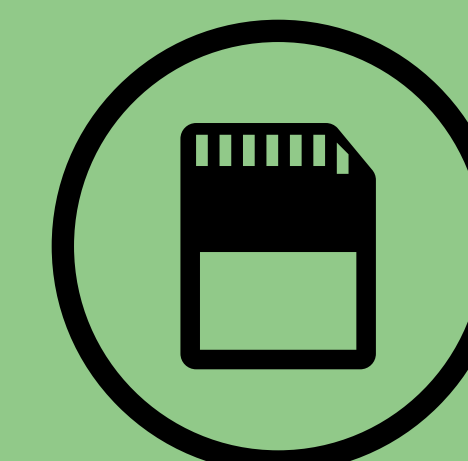

Built-in SD / SDHC card slot (up to 32GB)



Supports USB 2.0 MSDC interface (high speed)



High brilliance of colour



Usable as stand alone device



Small, light-weight, handy and easy to use

## Package Contents:

- DigiScan DS-02
- USB cable
- Video cable
- Rapid slide feeder
- Cleaning brush
- Holder for 135-negative films
- Holder for slide films
- Power adapter DC 5V
- User Manual





### Film to JPEG in Seconds

Powerful CMOS 1/3,2" 5 mega pixels sensor. Film scanner converts old 135mm, 126, 110, super 8 & 8mm negatives & slides to JPEG digital files. High brilliance of colour (white balance & exposure compensation automatically).



### Large & Bright 2.4" TFT LCD

High definition built-in color display features adjustable brightness & convenient tilt for easy operation & image viewing.



### Adapter for Everything

Unit arrives with multiple film inserts & adapters for fast, flexible operation, big one-touch buttons allow for one-step scan and save. Also it supports USB 2.0 MSDC interface (high speed).



### Intuitive User Interface

Includes helpful tray, insert directory, easily edit image. Extras included – USB cable, video cable, holder for 135-negative films, holder for slide films, rapid slide feeder, power adapter DC 5V, cleaning brush, user manual.



- Sensor - 1/3.2" 5 mega pixels CMOS
- Resolution - 5 Mega pixels
- Lens - Fixed focus F/6.0, F=6.34mm
- Focus range - 5.6 cm
- Still image - JPEG, Resolution: 5M, 10M (interpolated)
- TV output format - NTSC / PAL