


DigiScan DS-02 Digitize your Negative and Slide Films (Transmission on SD- / SDHC card directy)

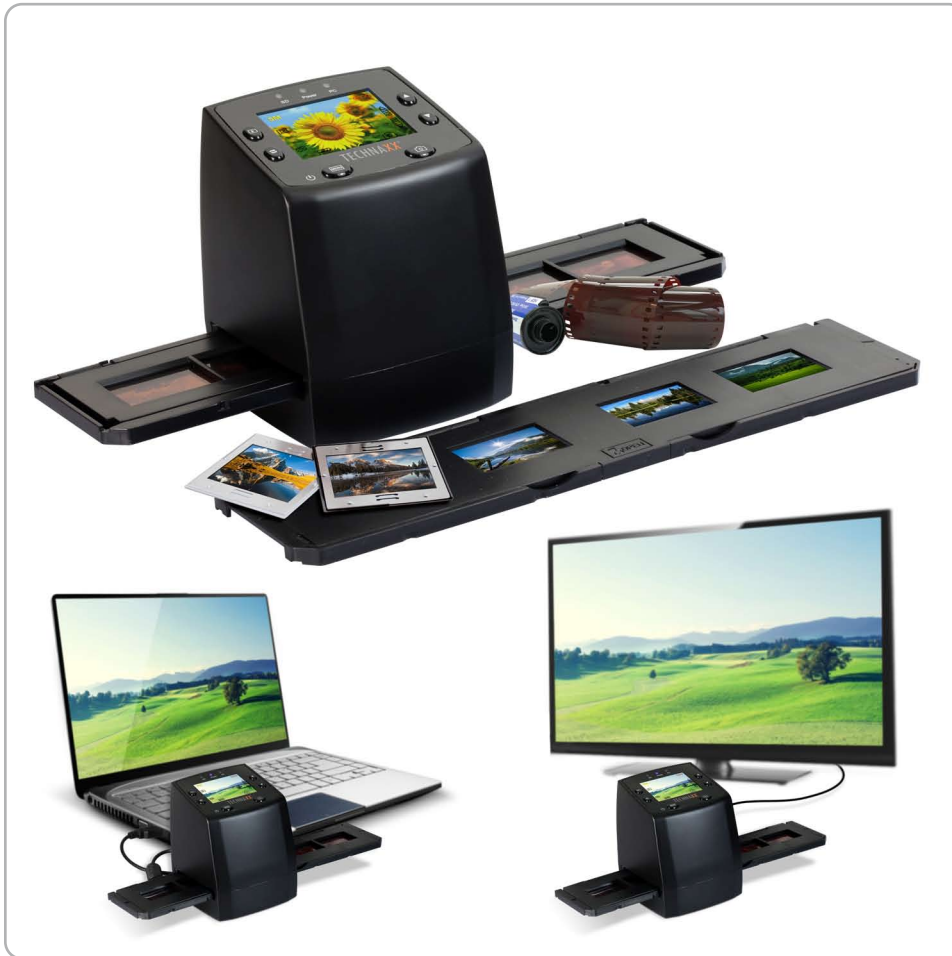

- Negative films & slide films scanner with 2.4" TFT display
- Portable scanner with 5 mega pixel CMOS sensor
- Built-in SD / SDHC card slot (up to 32GB)
- Supports USB 2.0 MSC interface (high speed)
- High brilliance of colour (white balance & exposure compensation automatically)
- Usable as stand alone device
- Small, light-weight, handy and easy to use

T Technical Specifications:

- Sensor: CMOS 1/3,2" 5 mega pixels
- Sensitivity: Automatically
- Lens: Fixed focus F/6.0, F=6.34mm
- Focus range: 5,6cm
- Still image: JPEG, Resolution: 5M, 10M (interpolation)
- TV output format: NTSC / PAL
- Light source: Backlight compensation
- Power: DC 5V
- CPU: Intel Pentium 4/2.8 GHz or above
- Memory: 512 MB or above
- Video card: 64 MB or high top video card
- Transmission connection: Standard USB 2.0 or above
- Hard disk capacity: 200 MB minimum

S System Requirements:

Windows XP + Windows Vista, Win7 (32/64 bit), Win8 (32/64 bit)

A Meas and Weight:

- Dimension device: 8.8 (L) x 8.6 (W) x 11 (H) cm
- Weight device: 300g

P Package Contents:

- DigiScan DS-02
- USB cable
- Video cable
- Holder for 135-negative films
- Holder for slide films
- Rapid slide feeder
- Power adapter DC 5V
- Cleaning brush
- User Manual

E EAN:

4260101736437