



**SPECIFICATION:**

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	6.5 mm
Strands Cross Section:	0.75 mm <sup>2</sup>
Strands Layout:	42 x 0.148 mm
Core Diameter:	2.3 mm

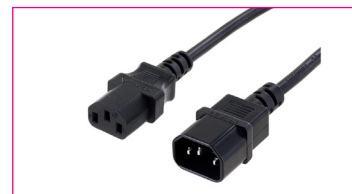

**MATERIAL:**

Type: H05VV-F3G

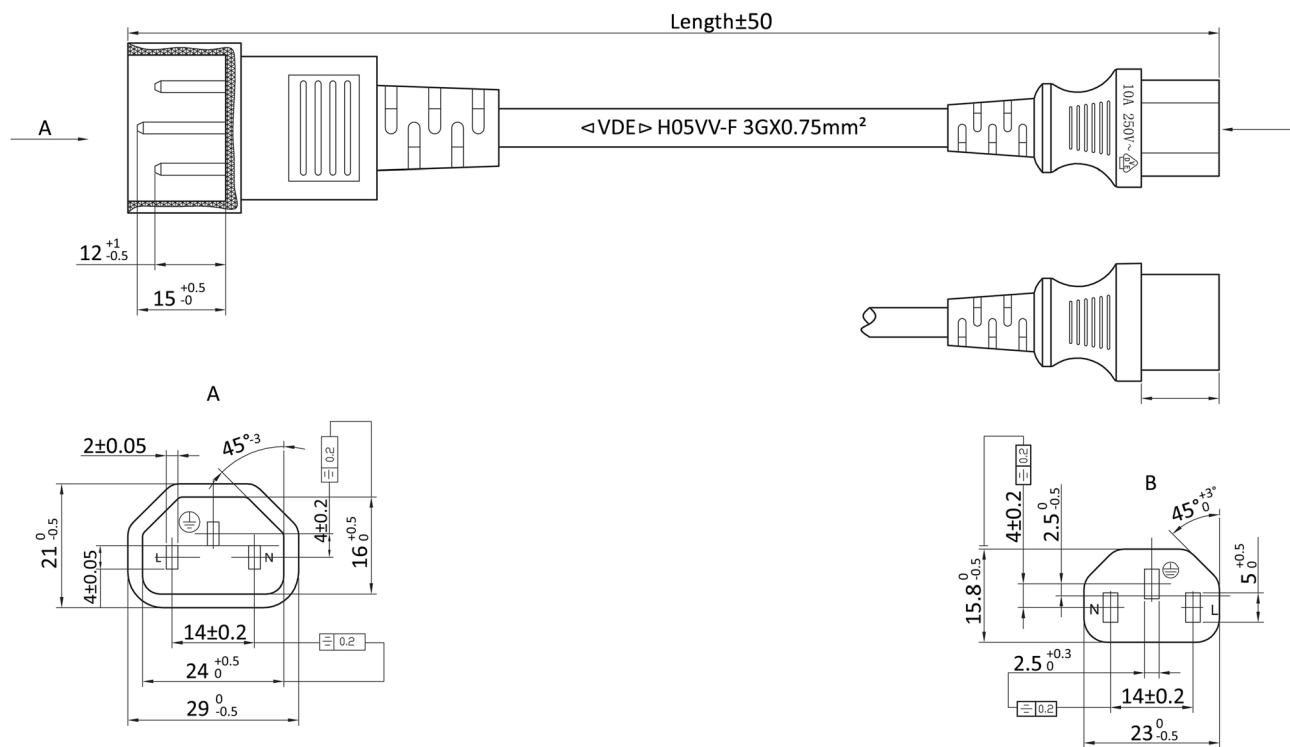

**Order Information**

Identifier:	Length:	Colour:
NKVK	2	#
Extension IEC plug straight to IEC socket straight	2.0 m	SW: black WS: white