



SPECIFICATION:

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	3.5 mm x 5.7 mm
Strands Cross Section:	0.75 mm ²
Strands Layout:	42 x 0.148 mm
Core Diameter:	2.2 mm

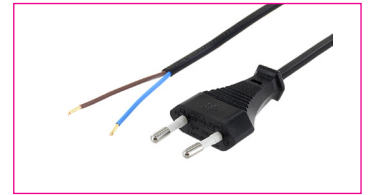

MATERIAL:

Type: H03-VVH2-F

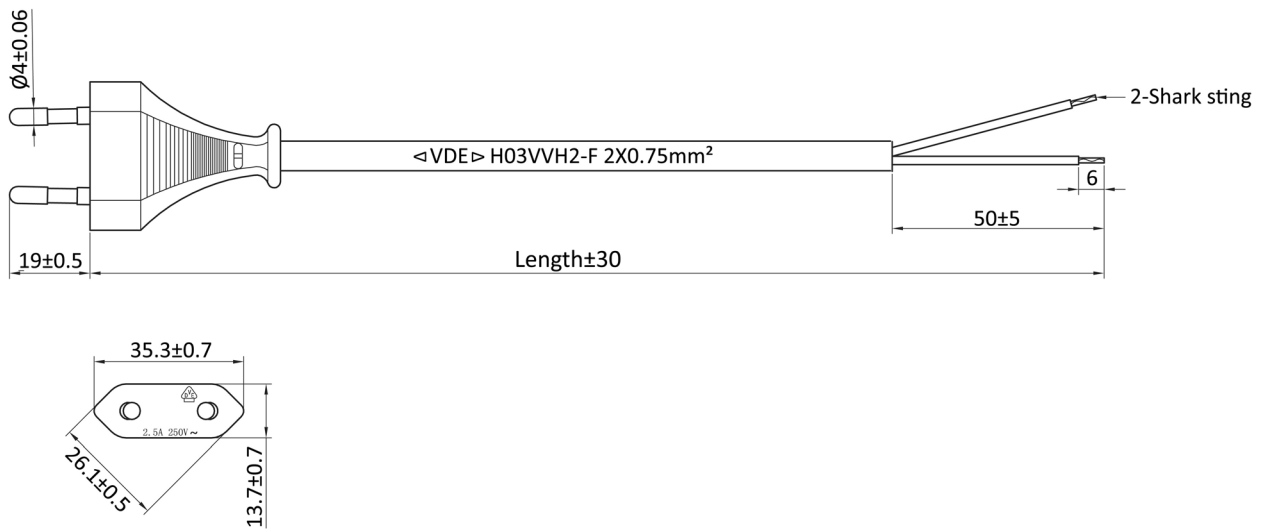

Order Information

Identifier:	Length:	Colour:
NKEO	#	SW
Power cable open end	1,5: 1.5 m	black
	2: 2.0 m	