


**Power Cables  
IEC C13**

**Right Angle Plug CEE 7/7 to Straight  
IEC Socket C13, 0.75 mm<sup>2</sup>**




**SPECIFICATION:**

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	6.5 mm
Strands Cross Section:	0.75 mm <sup>2</sup>
Strands Layout:	42 x 0.148 mm
Core Diameter:	2.3 mm

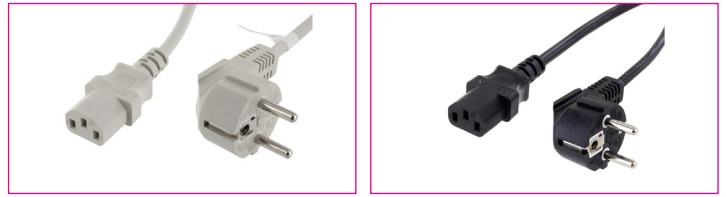

**MATERIAL:**

Type: H05VV-F3G

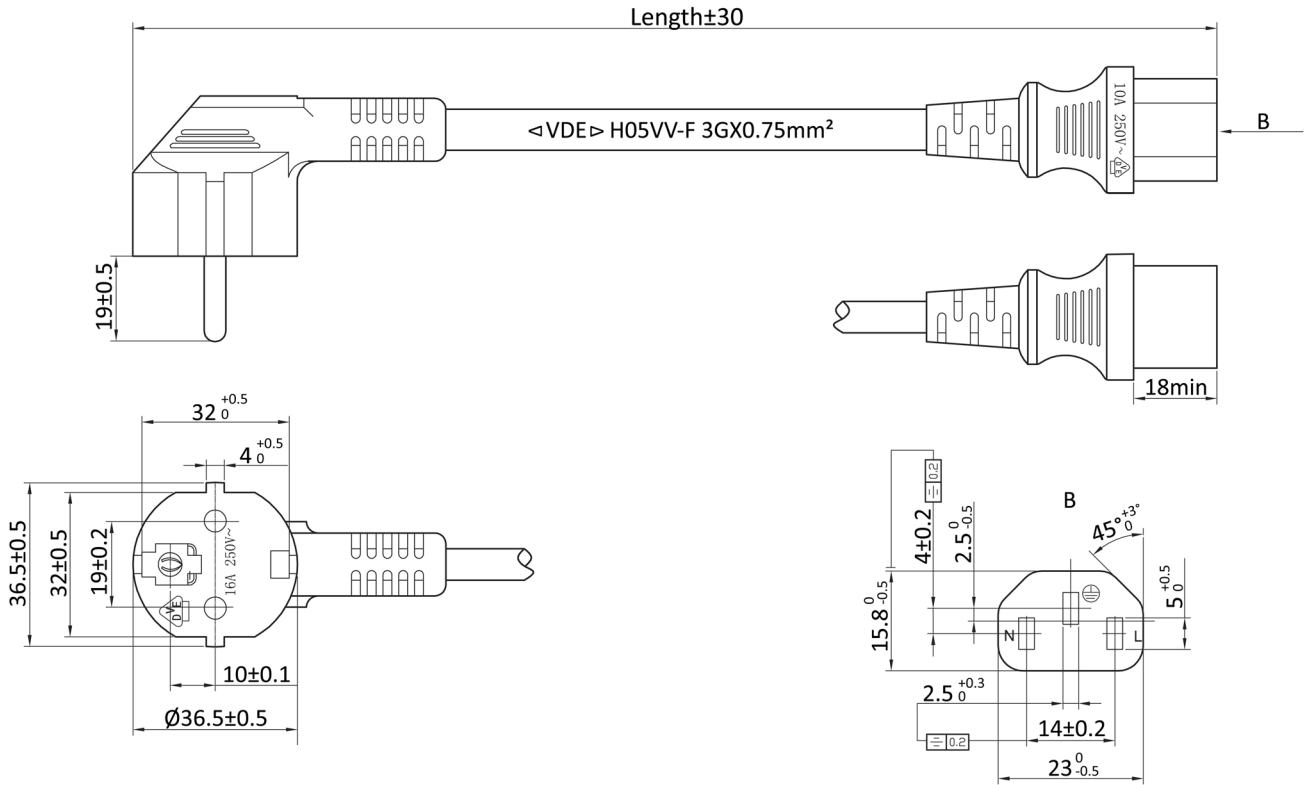

**Order Information**

Identifier:	Length:	Colour:
NKW	2	#
Power cable angled to straight IEC socket	2.0 m	GR: grey SW: black