


## Power Cables IEC C13

Right Angle Plug CEE 7/7 to Straight  
IEC Socket C13, 1.0 mm<sup>2</sup>




### SPECIFICATION:

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	7 mm
Strands Cross Section:	1 mm <sup>2</sup>
Strands Layout:	32 x 0.198 mm
Core Diameter:	2.5 mm

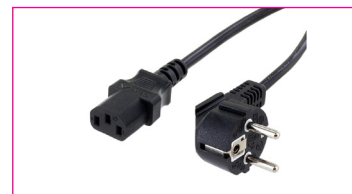

### MATERIAL:

Type: H05VV-F3G

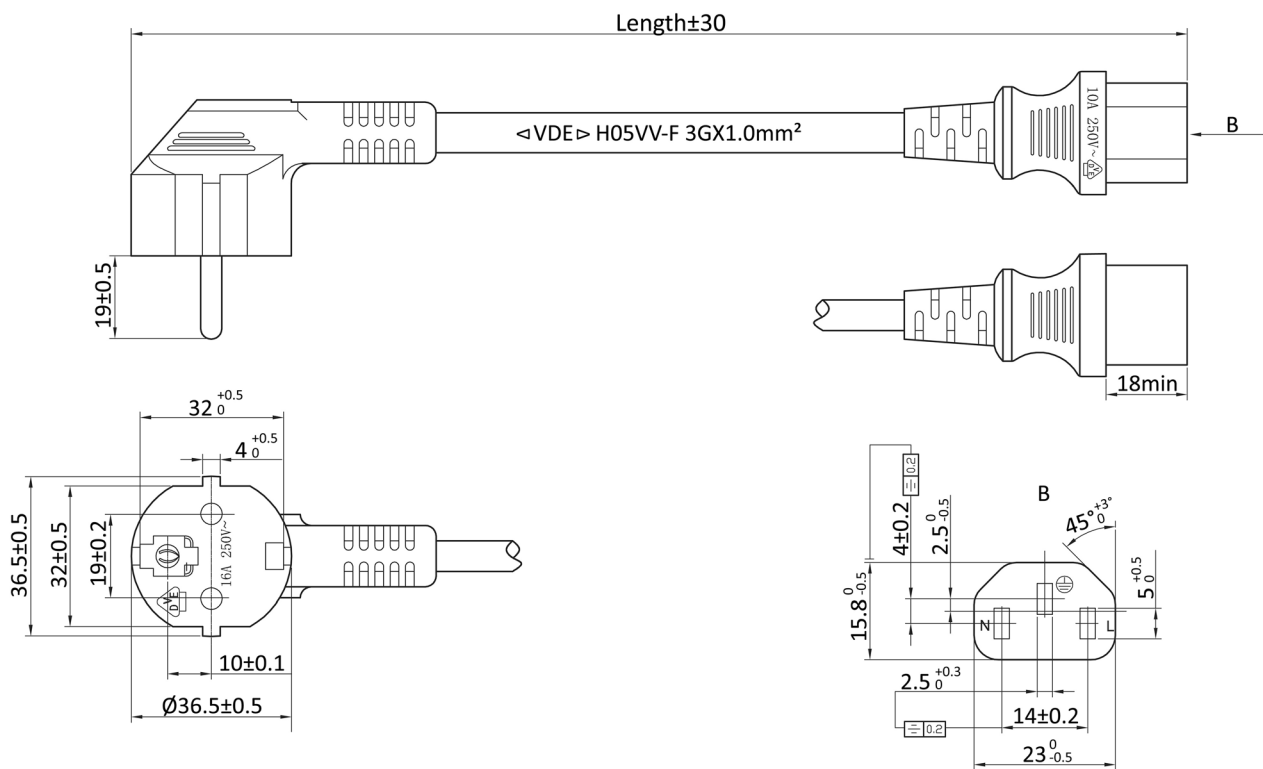

### Order Information

Identifier:	Length:	Colour:	Version:
NKW	3	SW	1
Power cable angled to straight IEC socket	3.0 m	black	cross section 1.0 mm <sup>2</sup>