



**SPECIFICATION:**

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	7 mm
Strands Cross Section:	1 mm <sup>2</sup>
Strands Layout:	32 x 0.198 mm
Core Diameter:	2.5 mm

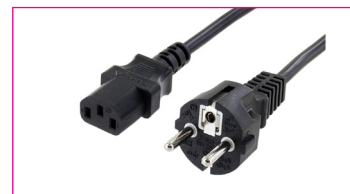

**MATERIAL:**

Type: H05VV-F3G

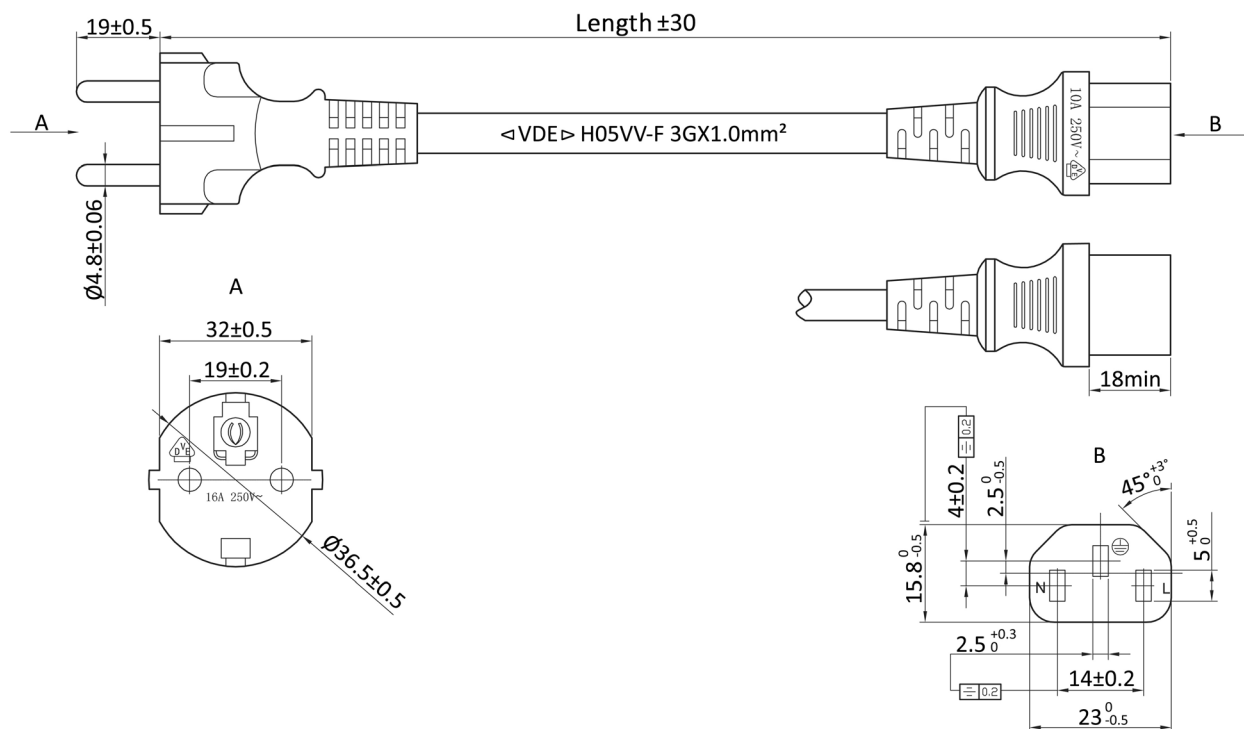

**Order Information**

Identifier:	Length:	Colour:	Version:
<b>NKG</b>	<b>2</b>	<b>#</b>	<b>1</b>
Power cable straight to straight IEC socket	2.0 m	SW: black WS: white	cross section 1.0 mm <sup>2</sup>