


**Power Cables
Protective contact CEE 7/7**

**Straight Plug CEE 7/7 to open end,
stripped and tinned**




SPECIFICATION:

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	7 mm
Strands Cross Section:	1 mm ²
Strands Layout:	32 x 0.198 mm
Core Diameter:	2.5 mm

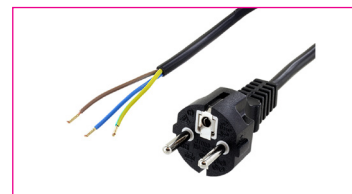

MATERIAL:

Type: H05VV-F3G

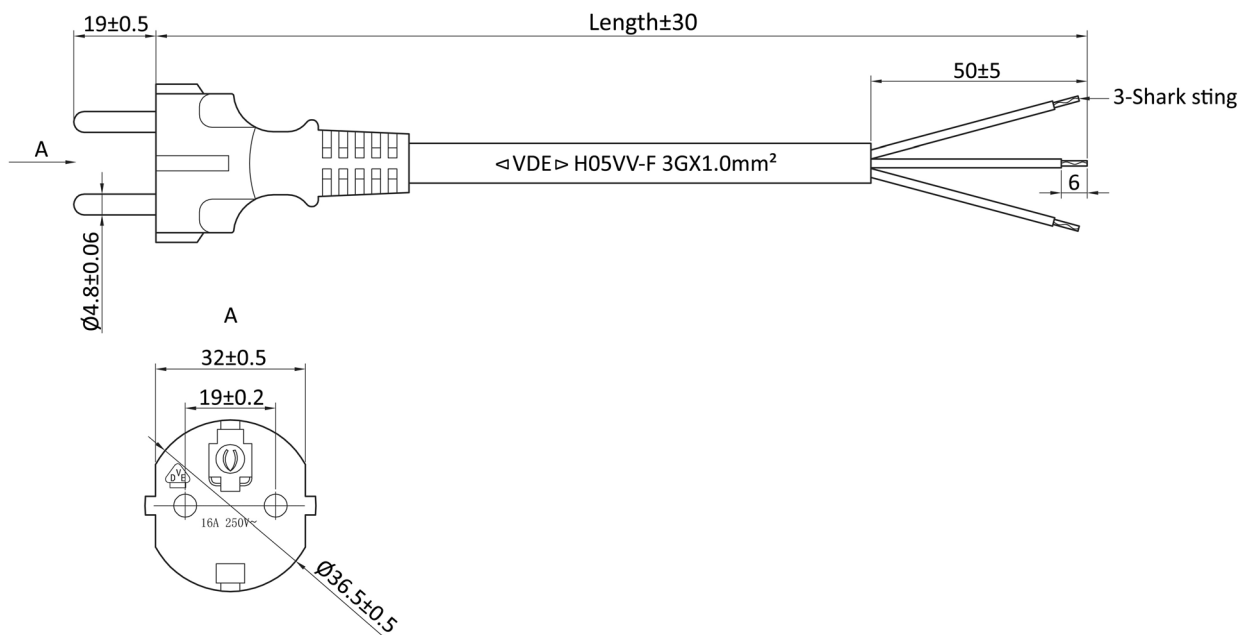

Order Information

Identifier: NKGO	Length: 2	Colour: SW	Version: 1E
Power cable straight to open end	2.0 m	black	cross section 1.0 mm ²