


**Power Cables
Protective contact CEE 7/7**

**Right Angle Plug CEE 7/7 to open end,
stripped and tinned 1.0 mm²**




SPECIFICATION:

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	7 mm
Strands Cross Section:	1 mm ²
Strands Layout:	32 x 0.198 mm
Core Diameter:	2.5 mm

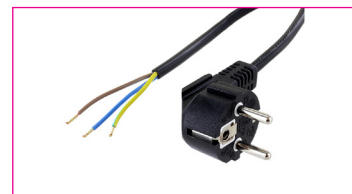

MATERIAL:

Type: H05VV-F3G

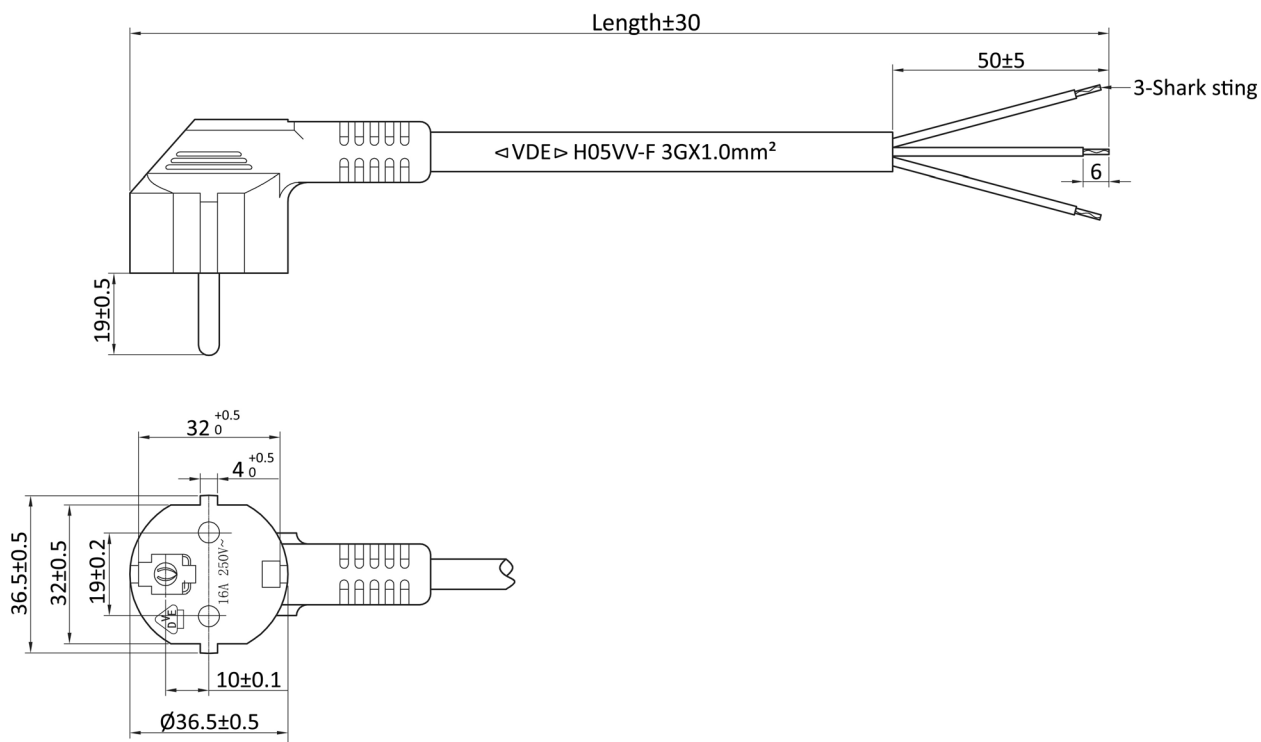

Order Information

Identifier:	Length:	Colour:	Version:
NKWO	#	#	1E
Power cable angled to open end	2: 2.0 m (only white) 3: 3.0 m (only black)	WS: white SW: black	cross section 1.0 mm ²