


## Power Cables IEC C13

Right Angle Plug CEE 7/7 to Right  
Angled IEC Socket C13




### SPECIFICATION:

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	6.5 mm
Strands Cross Section:	0.75 mm <sup>2</sup>
Strands Layout:	42 x 0.148 mm
Core Diameter:	2.3 mm

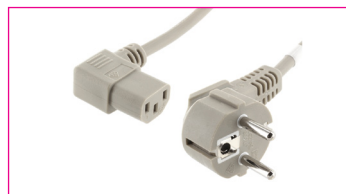

### MATERIAL:

Type: H05VV-F3G

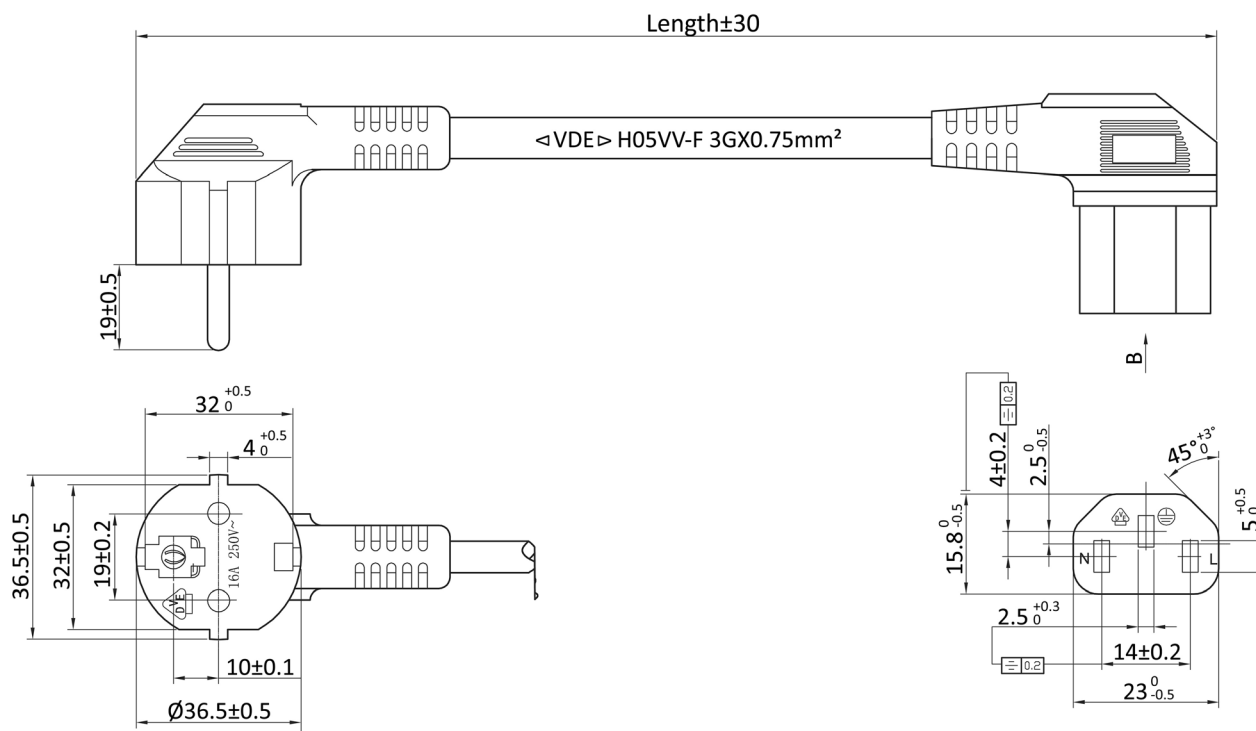

### Order Information

Identifier:  
NKWW

Length:  
2

Colour:  
#

Power cable angled to angled IEC socket

2.0 m

GR: grey  
SW: black