

SPECIFICATION:

Operating Current (Nom.):	1.5 A
Operating Temperature:	-55°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	500 Vac

MATERIAL:







Material (Terminal):	brass, tin plated
Material (Housing):	steel, nickel plated
Flammability Class:	UL 94 V-0
Material (Contact Area):	brass, selective gold plated

HANDLING:

Processing:	wave soldering
Packaging:	tray

TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

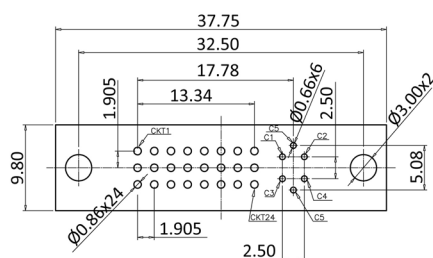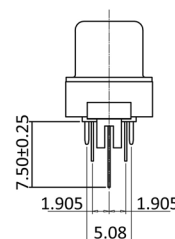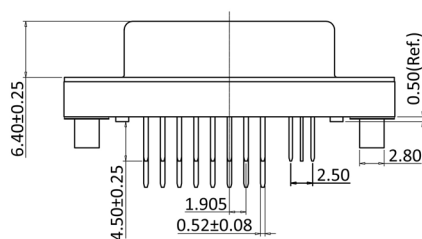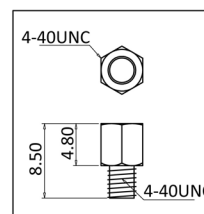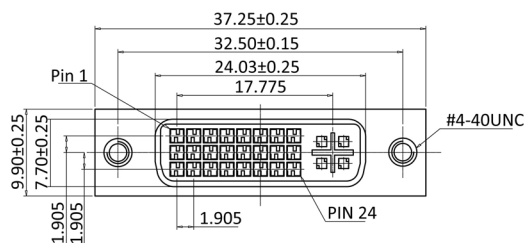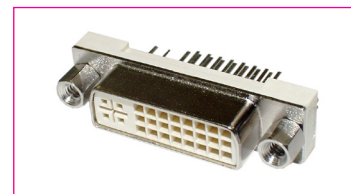

Order Information

Identifier:

DADB29

Version:

MC

Panel jack straight, analogue/digital, print

incl. threaded bolts UNC4/40