

**Pin Headers
Jumper Pitch 2.54 mm**

Multi Jumper



SPECIFICATION:

Operating Current (Nom.): 3 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 5000 MΩ
 Contact Resistance (Max.): 10 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:



Material (Terminal): brass
 Material (Housing): PBT
 Flammability Class: UL 94 V-0
 Material (Contact Area): brass

HANDLING:

Packaging: bulk

TOLERANCE:

.X: ± 0.35
 .XX: ± 0.25

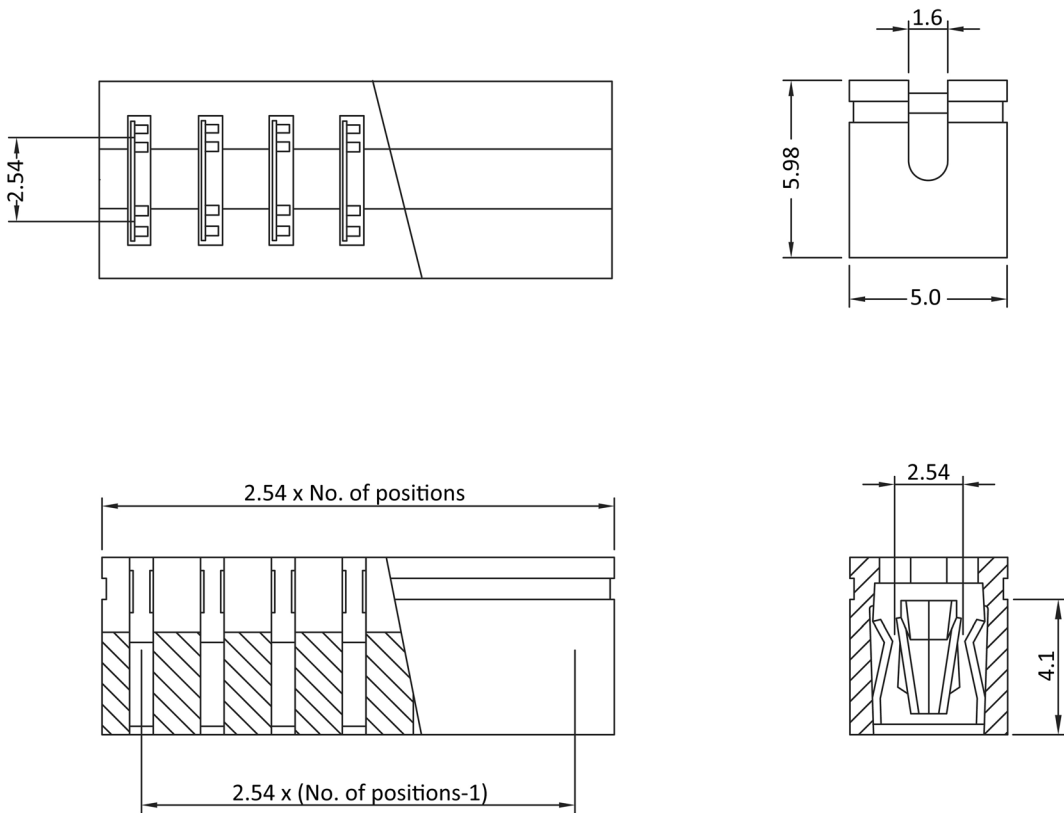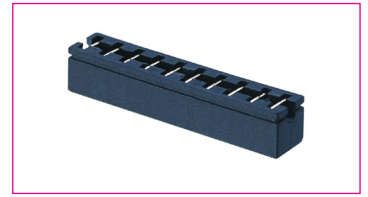

Order Information

Identifier:	No. of Contacts:	Contact Plating:	Colour:
MSH	#	G	B
Multi Jumper Pitch 2.54 mm	4: 2 x 2	gold plated	black
	6: 2 x 3		
	8: 2 x 4		
	:		
	26: 2 x 13		