


Data Sheet

Electronic Dual Siren 115 dB, 12V/DC 30W

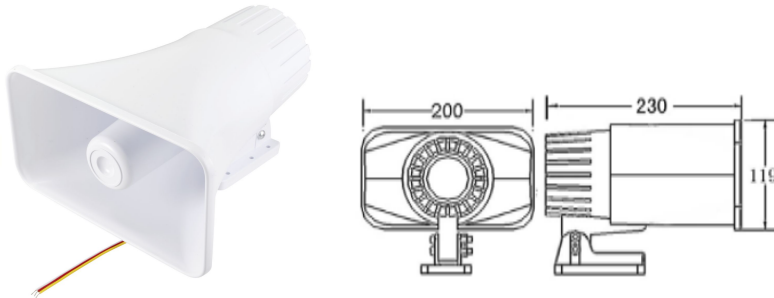

Technical data:

Rated power: 30 W

Voltage: 12 V/DC

Impedance: 6 Ω

Frequency response: 500~8K Hz

Key: 2 tones

Red wire: Siren

Yellow wire: Continuous

S.P.L.:102dB (1m/1w)

Housing material: ABS/ white

Open end wire: Black/ Red/ Yellow, 22 AWG, length: appx. 40 cm

Mounting type: Screw fastening

Operating temperature: -20°C to 70°C

Storage temperature: -30°C to 85°C

Operating and storage humidity: 90%