


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0532617004](#)
Status: **Active**
Overview: [PicoBlade Connector System](#)
Description: 1.25mm Pitch, PicoBlade PCB Header, Single Row, Right-Angle, Surface Mount, Gold (Au) Plating, Friction Lock, 4 Circuits, Tape and Reel

Documents:

3D Model	Product Specification 510211001-PS-000 (PDF)
3D Model (PDF)	Application Specification 510210000-AS-000 (PDF)
Drawing (PDF)	Packaging Specification SPK-53261-002-001 (PDF)
Product Specification 510210001-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)

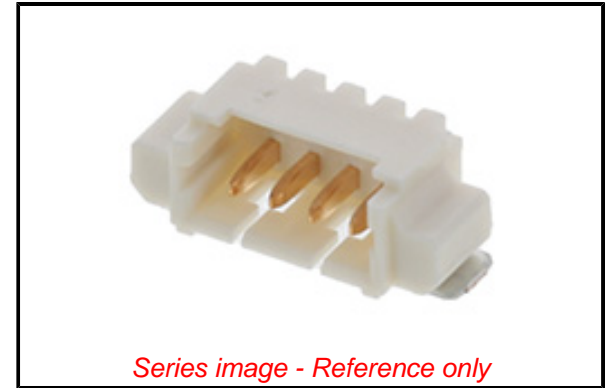

Agency Certification

UL E29179

General

Product Family	PCB Headers
Series	53261
Application	Signal, Wire-to-Board
Overview	PicoBlade Connector System
Product Name	PicoBlade
UPC	191128467629

Physical

Breakaway	No
Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Natural
Durability (mating cycles max)	30
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Mated Height	3.40mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Matte Tin
Material - Resin	Polyamide
Net Weight	158.698/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.380µm
Plating min - Termination	1.000µm
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V AC (RMS)/DC

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[53261](#) Series

Mates With

PicoBlade Housing [51021](#)

Material Info

Reference - Drawing Numbers

Application Specification	510210000-AS-000
Packaging Specification	SPK-53261-002-001
Product Specification	510210001-PS-000, 510211001-PS-000
Sales Drawing	532610000-SD-000

This document was generated on 02/04/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION