

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200790263

Status:


Active

Overview:

Brad Ultra-Lock Connection System

Description:

Ultra-Lock (M12) Single-Ended Cordset, 4 Poles, Male (Straight) to Pigtail, 22 AWG, Black PVC Cable, 2.0m (6.56') Length

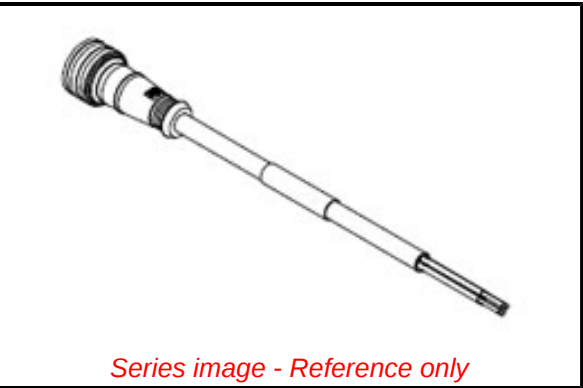

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Industrial Cordsets
Series	120079
Connector End A	Ultra-Lock (M12)
Connector End B	Pigtail
IP Rating	IP69K
Material - Contact	Copper Alloy
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Protocol	EtherNet
Region	Europe
Type	Single Ended
UPC	78172507806
Physical	
Cable Diameter	5.40mm (.213")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Push to Lock
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	99.000/g
Orientation	Straight to Pigtail
Poles	4
Temperature Range - Operating	-30° TO +80°C
Wire Size AWG	22
Wire/Cable Type	UL 2464
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	60V
Material Info	
Engineering Number	W04006E03M020
Reference - Drawing Numbers	
Sales Drawing	1200790273-000

EU ELV

Compliant with
Exemption 3

EU RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant with
Exemption 3

Not Contained

Search Parts in this Series

120079 Series

This document was generated on 01/07/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION