


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:	1202470040
Status:	Active
Overview:	Brad Passive-Signal and Safety MPIS Boxes
Description:	MPIS Nano-Change (M8) Passive Junction Box, Top-Mount, 6 Ports, LED for PNP Sensor, WSOR Cable, 5.0m Length
Replacement Part Number :	http://www.molex.com/molex/search/partSearch?pQuery=&sType=p&query=12011300111201130011

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E152210
General	
Product Family	Passive Distribution Boxes
Series	120247
IP Rating	IP67, IP68
Overview	Brad Passive-Signal and Safety MPIS Boxes
Product Name	MPIS
Replacement Part Number	1201130011
UPC	889056140560
Physical	
Bus I/O	N/A
Cable Connector Orientation	Straight
Cable Length	5.0m
Home Run Cable Length	5.0m
Home Run Connector	N/A
Home Run Interface	Pigtail
Keyway	A-coded
LED Indicator	PNP Sensors
Material - Cable Jacket	TPU
Material - Housing	PBT
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Net Weight	962.026/g
Orientation	Top-Mount
Poles	3
Poles (wired)	3
Ports	6
Temperature Range - Operating	-25°C to +85°C
Wire/Cable Type	WSOR
Wiring Configuration	Single I/O per Port
Electrical	
Current - Maximum per Contact	12.0A per module, 4.0A per port
Functional Wiring	PNP
Voltage - Maximum	10-30V DC
Material Info	
Engineering Number	BEB601P-FBW-05
Reference - Drawing Numbers	
Sales Drawing	1202470031-000

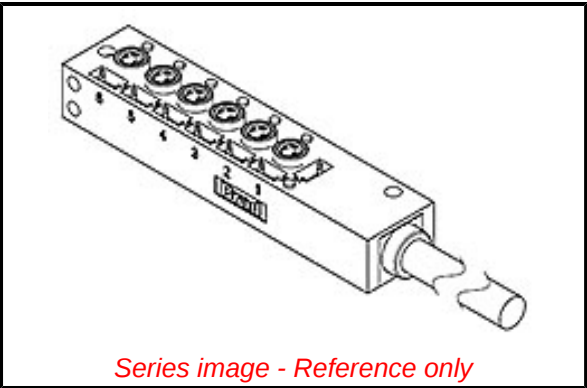

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Contained Per - ED/21/2016 (20 June 2016)	
Halogen-Free Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[120247 Series](#)

This document was generated on 08/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION