

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1210401282](#)  
**Status:** **Active**  
**Overview:** mPm DIN Valve Connectors  
**Description:** mPm DIN Valve Connector, Form A - 18mm 2 Pole to 5.0m Black PUR UL Cable Pigtail, Black Integrated Gasket

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">121040</a>
Connector End A	Brad mPm DIN A - 18mm
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Brass
Overview	<a href="#">mPm DIN Valve Connectors</a>
Product Name	mPm
Protocol	EtherNet
Region	America, Europe
Type	Single Ended
UPC	78172554436

**Physical**

Cable Diameter	6.50mm (.256")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	None
LED Indicator	No
Material - Cable Jacket	PUR UL
Material - Connector Body	Polypropylene
Material - Coupling Nut	N/A
Material - Plating Mating	N/A
Net Weight	542.000/g
Orientation	90° to Pigtail
Poles	2
Temperature Range - Operating	-40° to +90°C
Wire Size AWG	18
Wire/Cable Type	PUR

**Electrical**


Current - Maximum per Contact	5.0A
Voltage - Maximum	250V

**Material Info**

Engineering Number	E152B3A5001P
--------------------	--------------

**Reference - Drawing Numbers**

Sales Drawing	1210400050-000
---------------	----------------

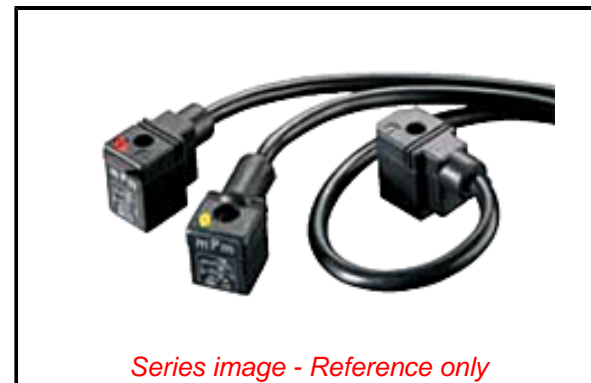

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Not Relevant

Compliant

Not Contained

**Search Parts in this Series**

[121040 Series](#)