

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210500554](#)

Status: **Active**

Overview: mPm DIN Valve Connectors

Description: mPm DIN Valve Connector, Form A - 18mm, 2 Pole Plus Ground Position H6/H12 with C4 Circuit, to 1.0m (3.28') PVC Cable Pigtail, Yellow LED, Black Nitrile Gasket, 24V

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E218123

General

Product Family Industrial Cordsets
 Series [121050](#)
 Connector End A Brad mPm DIN A - 18mm
 Connector End B Pigtail
 IP Rating IP65
 Material - Contact Brass
 Overview [mPm DIN Valve Connectors](#)
 Product Name mPm
 Protocol N/A
 Region America, Europe
 Type Single Ended
 UPC 883906589769

Physical

Cable Diameter 5.72mm (.225")
 Cable Length 1.0m (3.28')
 Color - Cable Jacket Black
 Coupling Style Threaded
 Gender Male-Pigtail
 Keyway None
 LED Indicator Yellow
 Material - Cable Jacket PVC
 Material - Connector Body Polypropylene
 Material - Coupling Nut N/A
 Material - Plating Mating Gold
 Net Weight 90.014/g
 Orientation 90° to Pigtail
 Poles 2
 Temperature Range - Operating -40° to +90°C
 Wire Size AWG N/A
 Wire/Cable Type N/A

Electrical


Current - Maximum per Contact 5.0A
 Voltage - Maximum 24V

Material Info

Engineering Number E452N3N10011C4H

Reference - Drawing Numbers

Sales Drawing 1210502000-000, SD-121050-001-001

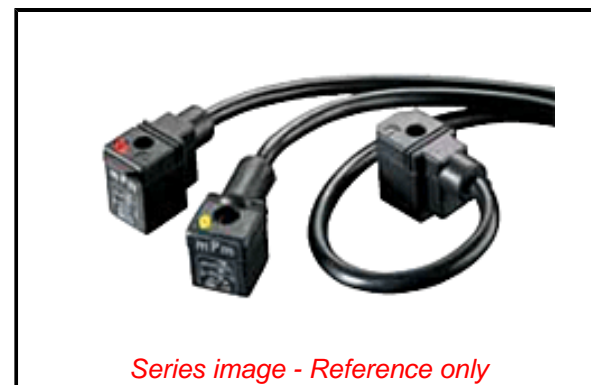

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2021)4569-DC (8
 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[121050 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION