

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0354648000

Status:

Active

Overview:

Automotive Bulb Sockets

Description:

Positive Terminal for PT Bulb Socket, AVSS 0.50~0.85mm²

Documents:

Drawing (PDF)

Packaging Specification PK-35464-8000-001 (PDF)

Packaging Specification PK-35903-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Application

Crimp Quality Equipment

Overview

Product Name

UPC

Crimp Terminals

35464

Power

Yes

Automotive Bulb Sockets

PT Bulb Socket

800754777261

Physical

Gender

Material - Metal

Material - Plating Mating

Net Weight

Packaging Type

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Female

Phosphor Bronze

Unplated

0.720/g

Reel

Crimp or Compression

1.60-2.30mm

N/A

AVS 0.50-0.85

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Reference - Drawing Numbers

Crimp Specification


Packaging Specification

Sales Drawing

CS-35464-001-001, CS-35464-8000-001

PK-35464-8000-001, PK-35903-001-001

SD-35464-001-001

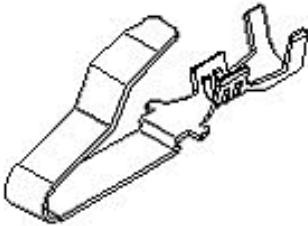

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

35464 Series

Use With

35842 , 35843

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extraction Tool for MX150L, MX150, PT Bulb Socket, iGrid, SPOX, and Wire-to-Motor Terminals	638131500
Hand Crimp Tool for Bulb Socket Positive Terminal	638195000

This document was generated on 02/04/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION