

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5031541690

Status:

Active

Overview:

CLIK-Mate Wire-to-Board Connectors

Description:

1.50mm Pitch, CLIK-Mate PCB Receptacle, Dual Row, Surface Mount, Vertical, Tin Plating, Positive Lock, 16 Circuits, Natural

Documents:

- 3D Model

Product Specification 5031491003-PS-000 (PDF)
- 3D Model (PDF)

Application Specification AS-503149-001-001 (PDF)
- Drawing (PDF)

Packaging Specification SPK-503154-001-001 (PDF)
- Product Specification 5031490000-PS-000 (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification 5031491000-PS-000 (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

PCB Receptacles

503154

Signal, Wire-to-Board

CLIK-Mate Wire-to-Board Connectors

CLIK-Mate

883906426736

Physical

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Durability (mating cycles max)

Glow-Wire Capable

Keying to Mating Part

Lock to Mating Part

Mated Height

Material - Metal

Material - Plating Mating

Material - Plating Termination

Net Weight

Number of Rows

Orientation

PCB Locator

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Polarized to PCB

Stackable

Temperature Range - Operating

Termination Interface: Style

16

16

Beige

30

No

None

Yes

11.20mm

Copper Alloy

Tin

Tin

1456.001/mg

2

Vertical

No

Yes

1.20mm, 1.70mm

Embossed Tape on Reel

1.50mm

1.50mm

Yes

No

No

-40° to +105°C

Surface Mount

Electrical

Current - Maximum per Contact


Voltage - Maximum

2.0A

100V

Material Info

Reference - Drawing Numbers

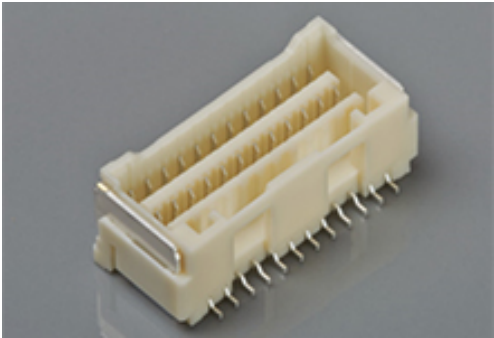

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

503154 Series

Mates With

503149 Crimp Housing

Application Specification	AS-503149-001-001
Packaging Specification	SPK-503154-001-001
Product Specification	5031490000-PS-000, 5031491000-PS-000, 5031491003-PS-000
Sales Drawing	5031540000-SD-000

This document was generated on 02/02/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION