

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0510150800

Status:


Active

Overview:

Board-in Connectors

Description:

2.00mm Pitch, Board-In Crimp Housing, Vertical, 8 Circuits, Natural

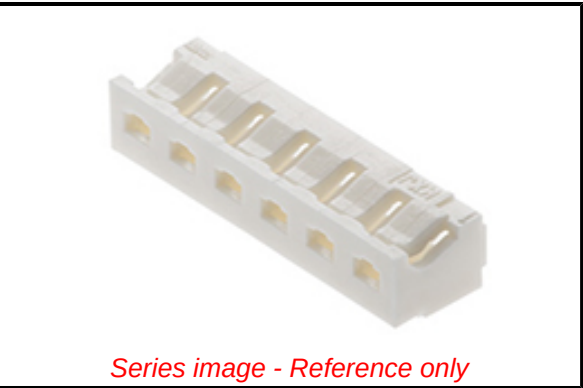

Documents:	
3D Model	Packaging Specification 510159100-EPK-100 (PDF)
Drawing (PDF)	Packaging Specification 510159200-SPK-200 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 510151002-PS-000 (PDF)	

General	
Product Family	Crimp Housings
Series	51015
Application	Signal, Wire-to-Board
Overview	Board-in Connectors
Product Name	Board-in
UPC	800753749269
Physical	
Circuits (maximum)	8
Color - Resin	Natural
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	151.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	510159100-EPK-100, 510159200-SPK-200
Product Specification	510151002-PS-000
Sales Drawing	SD-51015-XX00-020

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
51015 Series
Use With
50034

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION