


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5601230801](#)
Status: **Active**
Overview: [DuraClik Connector System](#)
Description: DuraClik ISL Wire-to-Board Receptacle Housing, Single Row, Black, 8 Circuits

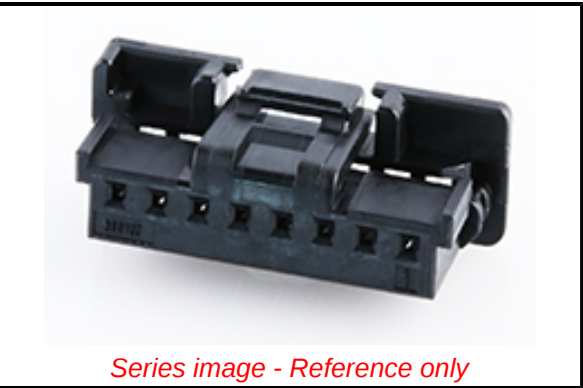

Series image - Reference only

Documents:	
3D Model	Application Specification AS-560123-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-560123-001-001 (PDF)
Drawing (PDF)	Test Summary 5601230600-TS (PDF)
Product Specification PS-560123-001-001 (PDF)	Datasheet (PDF)
Product Specification PS-560123-003-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	560123
Application	Automotive, Signal, Wire-to-Board
Overview	DuraClik Connector System
Product Name	DuraClik
UPC	889056288262

Physical	
Circuits (maximum)	8
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	0.455/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +130°C

Material Info

Reference - Drawing Numbers

Application Specification	AS-560123-001-001
Packaging Specification	PK-560123-001-001
Product Specification	PS-560123-001-001, PS-560123-003-001
Sales Drawing	SD-560123-005-001
Test Summary	5601230600-TS

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Not Low-Halogen

China RoHS

China ROHS
ELV
RoHS Phthalates

Green Image
Compliant
Not Contained

Search Parts in this Series
[560123](#) Series

Mates With
DuraClik Right-Angle Header [502352](#)

DuraClik Vertical Header [560020](#)

Use With
DuraClik ISL Terminal [560124](#)
DuraClik
ISL Retainer [5601250800](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION