

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901430106](#)
Status: **Active**
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Modular Crimp Housing, Dual Row, 4 Polarizing Buttons, 6 Circuits, Black

Documents:

3D Model	Product Specification PS-99020-0001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

Agency Certification

UL	E29179
----	--------

General

Product Family	Crimp Housings
Series	90143
Application	Signal, Wire-to-Board
Comments	4 Polarizing Buttons
Overview	C-Grid III Interconnects
Product Name	C-Grid III
UPC	800753538887


Physical

Breakaway	No
Circuits (maximum)	6
Circuits Detail	No Voided Circuits
Color - Resin	Black
Flammability	94V-1
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	PPO
Net Weight	0.342/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	No
Ports	1
Stackable	Yes
Temperature Range - Operating	-55° to +105°C

Material Info

Reference - Drawing Numbers

Product Specification	PS-99020-0001-001
Sales Drawing	SD-90143-001

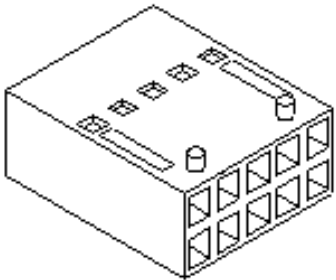

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[90143](#) Series

Mates With

C-Grid III Header, Dual Row [90122](#) , [90130](#) ,
[90131](#)

Use With

C-Grid III Crimp Terminal [90119](#)
 C-
Grid III Pre-Crimped Lead [797582022](#) ,
[797582023](#)