

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190030040

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm²), Bag, Tab 6.35 x 0.81mm, Blue

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

3D Model (PDF)

Product Specification PS-19902-013-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-19902-008-001 (PDF)

Agency Certification

CSA	LR18689
UL	E79133

General

Product Family	Quick Disconnects
Series	19003
Comments	Funnel Entry
Crimp Quality Equipment	Yes
Insulated	Fully
Overview	Standard Quick-Disconnect Terminals
Product Name	InsulKrimp
Type	Quick Disconnect
UPC	800753029057

Physical


Barrel Type	Closed
Color - Resin	Blue
Flammability	94V-2
Gender	Female
Glow-Wire Capable	No
Insulation	Nylon (PA)
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	0.800/g
Orientation	Straight
Packaging Type	Bag
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Polarized to Mating Part	No
Tab Thickness	0.81mm
Tab Width	6.35mm
Temperature Range - Operating	-65° to +105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.68mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00

Electrical

Voltage - Maximum	600V
-------------------	------

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

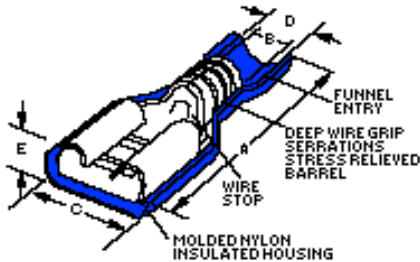

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

19003 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade	640010400
Hand Crimp Tool for InsulKrimp Quick Disconnect Terminals, 10-22 AWG	
Crimp Head for the AT-200 Pneumatic Hand Tool	640050400

Material Info

Engineering Number BB-2206

Reference - Drawing Numbers

Product Specification PS-19902-008-001, PS-19902-011-001,
PS-19902-013-001
Sales Drawing SD-19003-005-001

This document was generated on 02/07/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION