

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210360194](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: Micro-Change (M12) to Brad mPm DIN Form A - 18mm Cordset, 5 Poles, Male (Straight), Black PUR Cable, 1.50m (4.92') Length, 24V

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Industrial Cordsets
Series [121036](#)
Connector End A Brad mPm DIN A - 18mm
Connector End B Micro-Change (M12)
IP Rating IP65
Material - Contact Copper Alloy
Overview [mPm DIN Valve Connectors](#)
Product Name Micro-Change (M12), mPm
Protocol N/A
Region America, Europe
Type Double Ended
UPC 883906334789

Physical

Cable Diameter 5.72mm (.225")
Cable Length 1.50m (4.92')
Color - Cable Jacket Black
Coupling Style Threaded
Gender Male-Male
Keyway Single
LED Indicator No
Material - Cable Jacket PUR
Material - Connector Body Polypropylene
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Net Weight 120.000/g
Orientation 90° to Straight
Poles 5
Temperature Range - Operating -25° to +75°C
Wire Size AWG 20
Wire/Cable Type PUR

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 24V

Material Info

Engineering Number E850B0P12M015

Reference - Drawing Numbers

Sales Drawing SD-121036-001-001

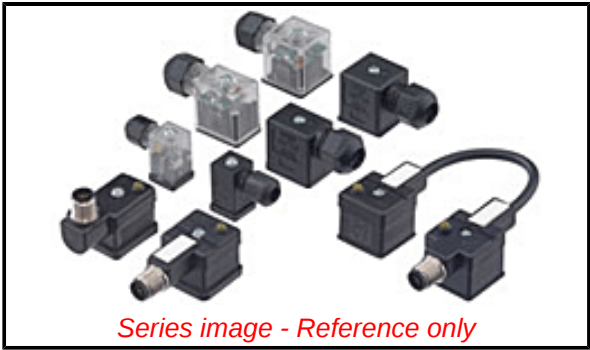

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)
REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

Halogen-Free
Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[121036](#) Series