

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200798045

Status:


Active

Overview:

Brad Ultra-Lock Connection System

Description:

Ultra-Lock (M12) Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 22 AWG, Black PUR LSOH Cable, 2.0m (6.56') Length

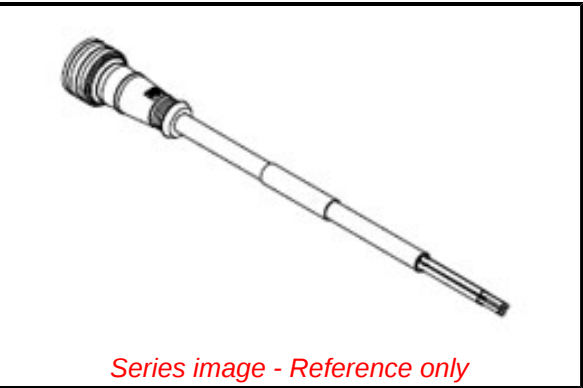

Series image - Reference only

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
General	
Product Family	Industrial Cordsets
Series	120079
Connector End A	Ultra-Lock (M12)
Connector End B	Pigtail
IP Rating	IP69K
Material - Contact	Copper Alloy
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Protocol	EtherNet
Region	Europe
Type	Single Ended
UPC	78172533021
Physical	
Cable Diameter	5.00mm (.197")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Push to Lock
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	TPE
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	1.000/g
Orientation	Straight to Pigtail
Poles	5
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	22
Wire/Cable Type	UL 21198
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	60V
Material Info	
Engineering Number	W05000H09M020
Reference - Drawing Numbers	
Sales Drawing	1200795043-000

EU ELV

Not Relevant

EU RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120079 Series

This document was generated on 02/02/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION