

# LogiLink®

## Heart-Shaped LED Ring Light with Tripod

Art. No.: AA0155



Vlogging Kit

## SHOW YOUR COLORS

The Heart-shaped LED Ring Light has the ability to change between 15 colors and has unique moods with the 17 dynamic light effects. Great for creating the perfect vibe with your favorite colors.



15 RGB  
Color Modes



17 Dynamic  
Light Effects



3 Color  
Temperatures



Adjustable  
Brightness



USB  
Powered



360°  
Rotation



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



Natural



Warm



Cool



### Create Your Best Selfie

The LED ring light is perfect for capturing flattering light. Lighting controls allows you to dim the brightness of the light and change the color temperature easily. It turns a dim room into a professional-looking environment with little effort.

### Level Up Your Live Streaming

Design your own personalized photos or videos on social media by switching between 15 RGB color modes and 17 dynamic light effects. It's easy to create the best lighting environments.





## Make Video Look Professional


The heart-shaped LED ring light delivers shadow-free lighting and striking heart catchlights in the eyes. It is an excellent tool when shooting video or portraits. Ideal for vloggers, makeup artists, and social influencers.

## Capture the Best Angle

Equipped with a 360° rotatable metal ballhead; easily adjust the ring light vertically or horizontally. Create the best angle while streaming live.

## Light Up Anytime, Anywhere

Attached the tripod to work as a table lamp for makeup or live streaming anywhere. Powered by USB from your laptop, computer, power bank or USB charger.

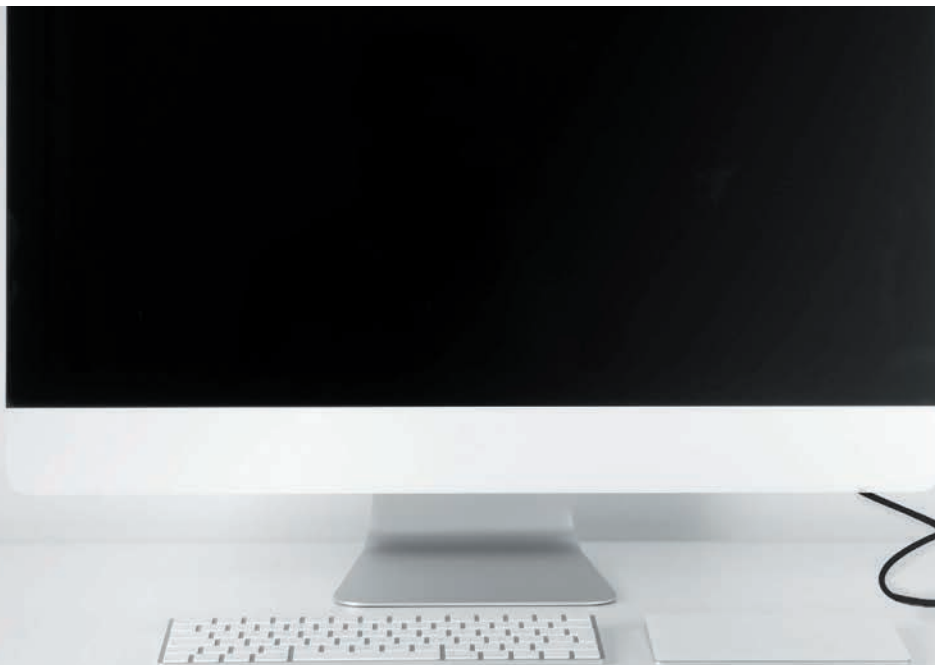

## Specifications:

USB Input	DC 5 V/2 A 10 W max.
LED Type	SMD LED
LED Quantity	9 W/96 PCS
Energy Usage Consumption	7 kwh/1000 h
EEK (Energy Efficiency Class)	E
Total Lumen	1500 lm
Correlated Colour Temperature	3200 K/4500 K/6500 K
CRI (Color Rendering Index)	80,2 Ra
Flicker Metric	0,01 W
Stroboscopic Effect Metric	0,009 W
Power Usage	7 W
Standby Power	0,001 W
Lifetime	3000 hours
In-line Controls	Yes, color mode, brightness, light effect, temperature modes, On/Off switch
Dimmable	15 RGB color mode
3 Color Temperature Modes	Natural, Warm, Cool
Light Effects	17 Dynamic
Power By	USB powered
Operating Temperature	-15–35 °C
Operating Humidity	10–95% RH (no condensation)
Storage Temperature	20–30 °C
Storage Humidity	10–50% RH (no condensation)
Material	ABS
Dimensions	38,5x15,8x3 cm (tripod included)
Weight	0,295 kg (tripod included)
Cable Length	1,98 m
With Tripod	Yes

## Package Contents:

- » 1x Heart-Shaped LED Ring Light
- » 1x Metal Ballhead
- » 1x Tripod
- » 1x User Manual

## Package Information:

- » Packing Dimension: 227x205x35 mm
- » Packing Weight: 0,39 kg
- » Carton Dimension: 480x430x370 mm
- » Carton Q'ty: 40 pcs
- » Carton Weight: 16 kg



Logilink  
AA0155



12  
kWh/1000h



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



Made in China