

**SPECIFICATION:**

Operating Voltage (Max.): 60 Vdc  
 Operating Current (Nom.): 10 A  
 Operating Temperature: -20°C to 90°C  
 Insulation Resistance (Min.): 500 MΩ  
 Contact Resistance (Max.): 5 mΩ




**MATERIAL:**

Material (Terminal): brass, nickel plated  
 Material (Housing): ABS  
 Material (Contact Area): brass, nickel plated



**HANDLING:**

Terminal: screw  
 Packaging: bulk  
 PU: 100 piece(s)

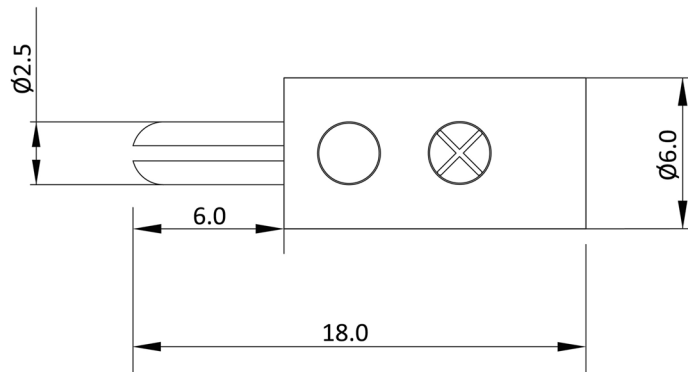

**Order Information**

Identifier:	Colour:
HOS25	#
HO plug 2.5 mm	SW: black
	RT: red
	BL: blue
	GE: yellow
	GN: green
	WS: white