




NEEDED TO START (EXCL.)

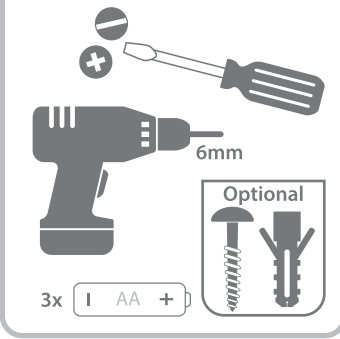


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

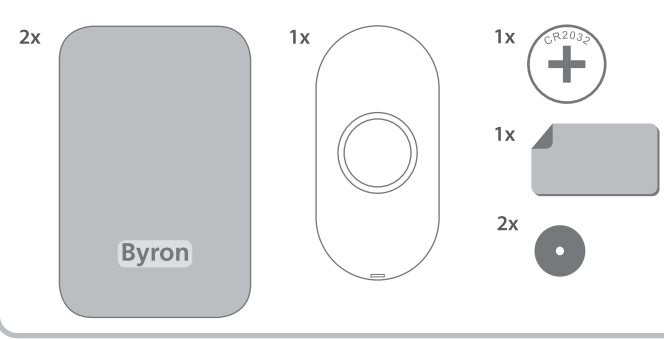


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

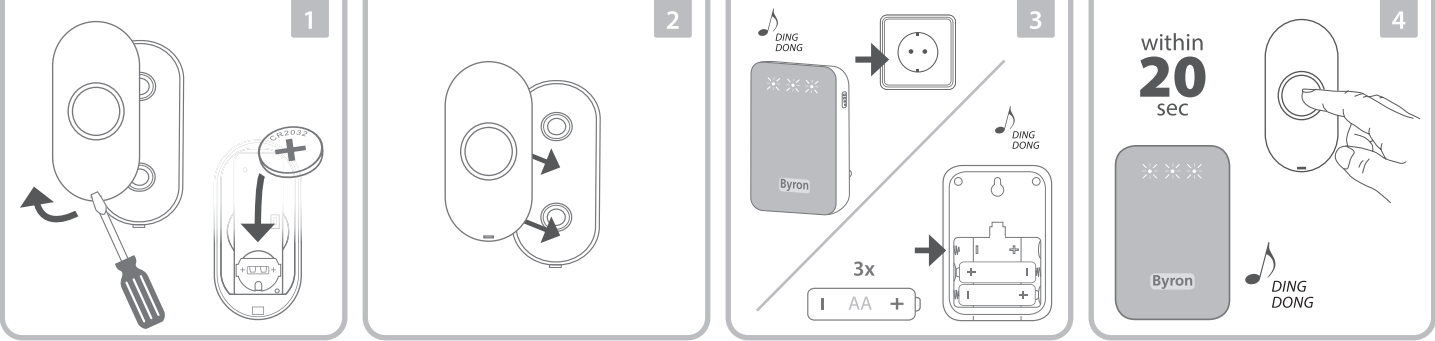

INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

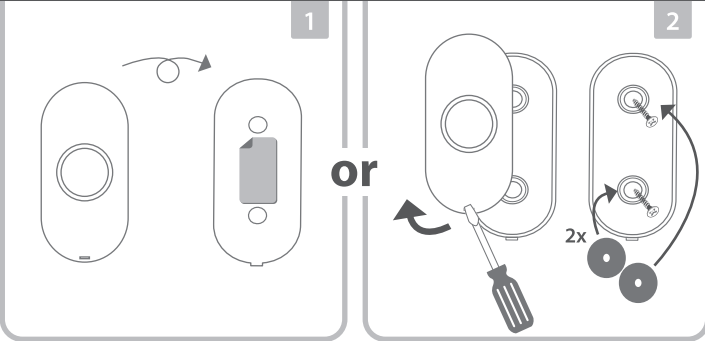

PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPLO | EMPAREJANDO MÚLTIPLES TIMBRES

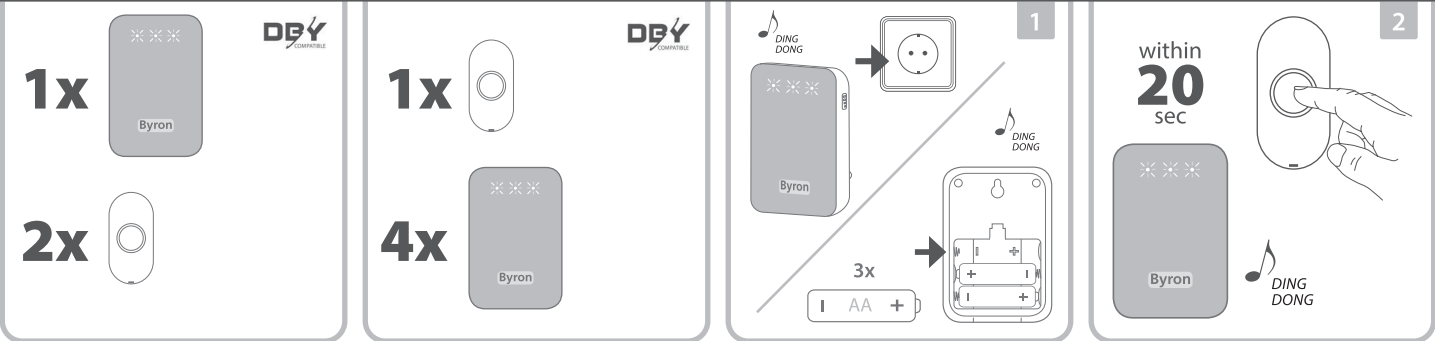


FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS

	<p>1</p>	<p>2</p>
<p>16</p>	<p>1</p>	<p>2</p>

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEEM OPLOSSEN | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

<p>RESET</p> <p>1</p> <p>DING DONG</p> <p>DING DONG</p>	<p>2</p> <p>within 20 sec.</p> <p>DING DONG</p> <p>Byron</p>	<p>3</p> <p>FIRST SET-UP ERSTEINRICHTUNG PREMIÈRE CONFIGURATION EERSTE INSTALLATIE PRIMO SET-UP PRIMERA CONFIGURACIÓN</p> <p>3 and 4</p>	
--	--	--	--

WWW.CHBYRON.EU

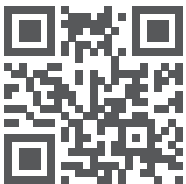

Find us on



Or contact us directly:

smartwares[™]
Europe
Jules Verneweg 87
5015 BH Tilburg
The Netherlands
www.chbyron.eu



Conforms to all relevant European Directives.

Frequency band: 433.92MHz (433.050 - 434.790 MHz)
Maximum radio-frequency power: +5.92dB
Range: 150 meters

Wireless Doorbell DBY-22324
Power: 220-240V~ 50 Hz
3 x 'AA'/LR6 1.5V: Total 4.5V
Indoor Use Only

Push button - DBY-23510
Power supply: 1 x CR2032 3V
IP44 Weather Resistant

