



DBY-23412 | WIRELESS DOORBELL SET


NEEDED TO START (OPTIONAL) (EXCL.)

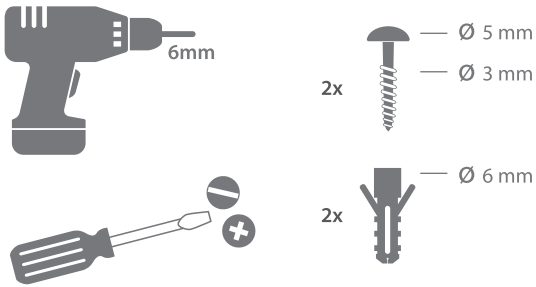


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

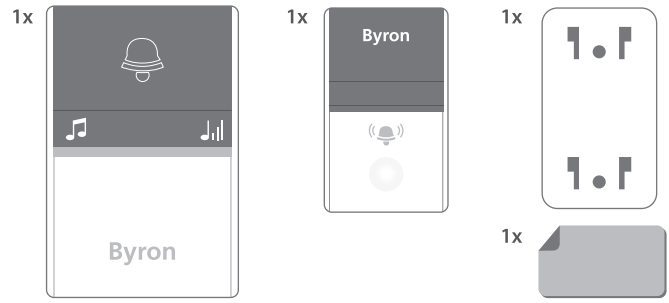


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

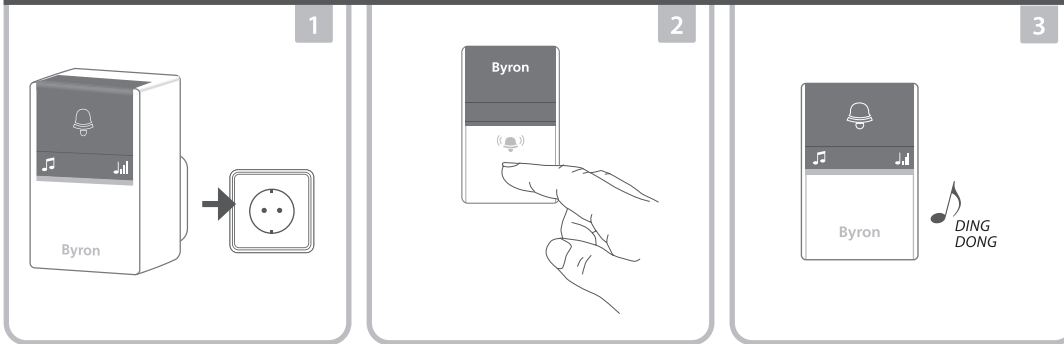

INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

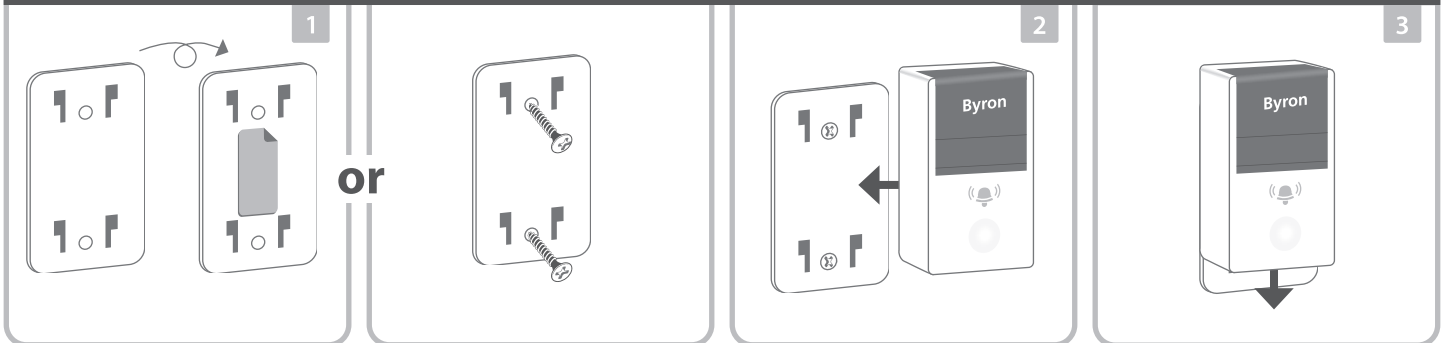

PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPLO | EMPAREJANDO MÚLTIPLES TIMBRES

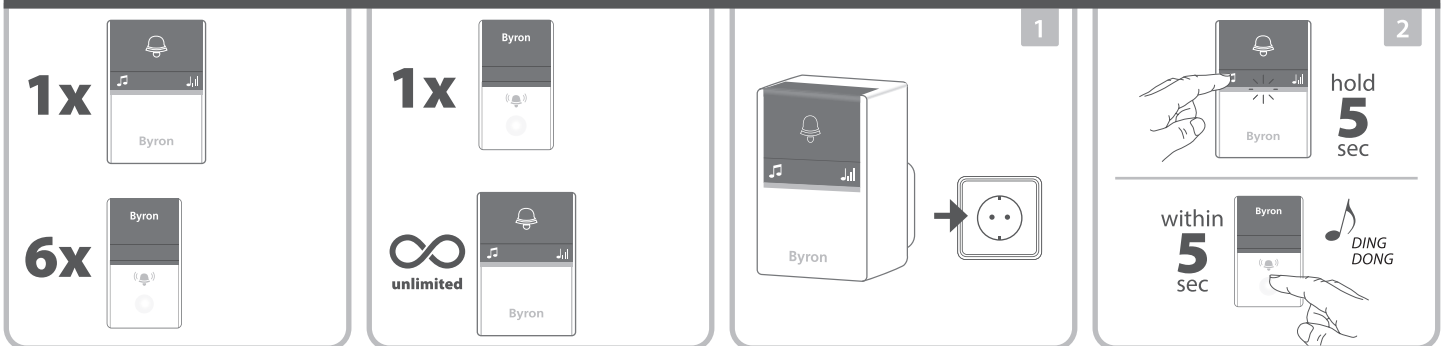

FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS


	<p>1</p>	<p>2</p>
<p>16</p>	<p>1</p>	<p>2</p>

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPLOSSEN | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

RESET

<p>1</p>	<p>2</p> <p>hold 20 sec</p>	<p>3</p> <p>hold 5 sec</p> <p>within 5 sec</p> <p>DING DONG</p>
----------	------------------------------------	--

WWW.CHBYRON.EU

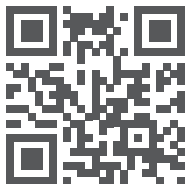

Find us on



Or contact us directly:

smartwares[™]
Europe
Jules Verneweg 87
5015 BH Tilburg
The Netherlands
www.chbyron.eu



Conforms to all relevant European Directives.

Frequency band: 433.92MHz (433.050 - 434.790 MHz)
Maximum radio frequency power <+10dBm
Range: 100 meters

Wireless Doorbell DBY-23412
Power: 220-240V~/ 15mA 50Hz
Indoor Use Only

Push button - DBY-23410
Power supply: kinetic technology
IP44 Weather Resistant

