



DIC-23430 | TOUCH FREE BUTTON


NEEDED TO START (OPTIONAL) (EXCL.)

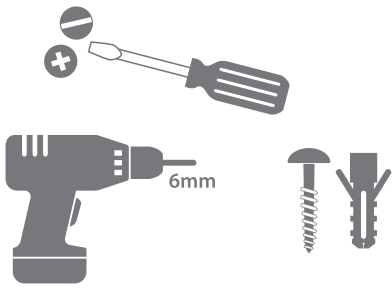


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

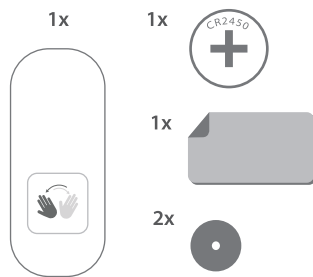


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

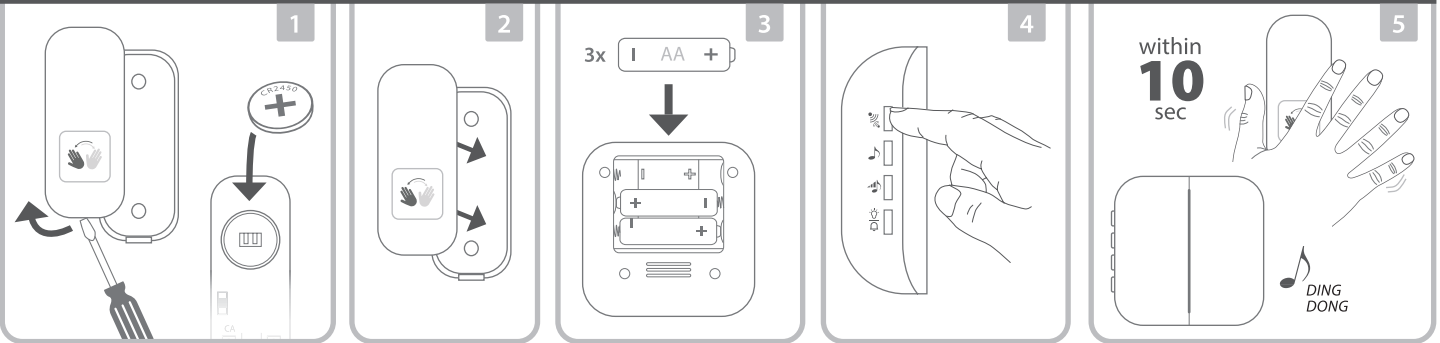


INSTALLATION WITH WIRED DOORBELL | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

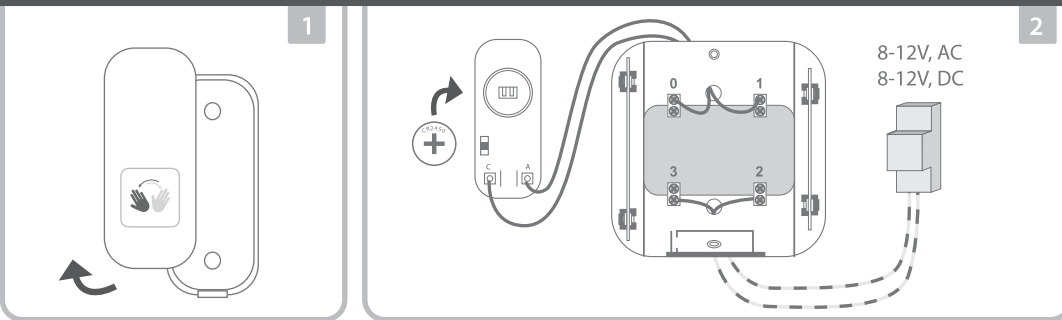

INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

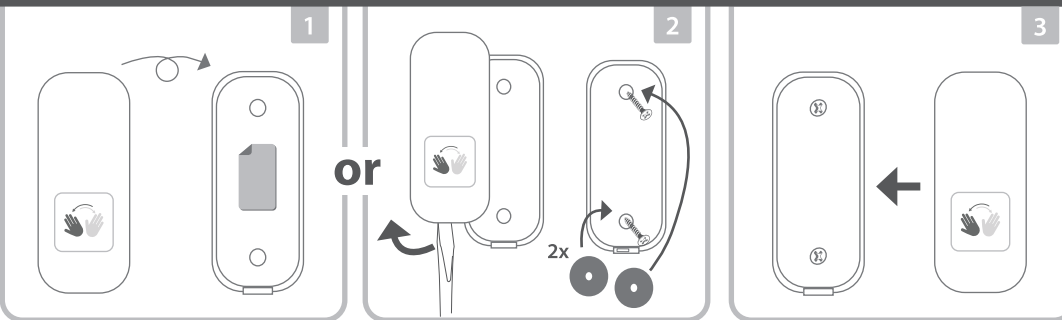


PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPLO | EMPAREJANDO MÚLTIPLES TIMBRES

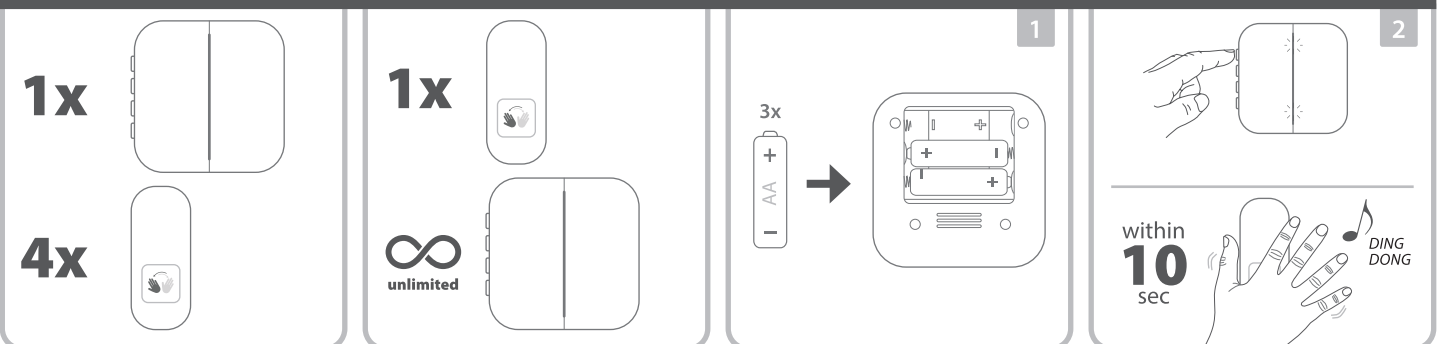

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPLOSSEN | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

RESET


1

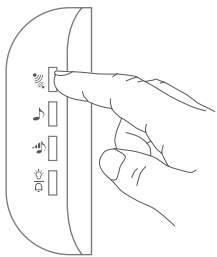

hold
5
sec

2


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE
CONFIGURATION | EERSTE INSTALLATIE | PRIMO
SET-UP | PRIMERA CONFIGURACIÓN

 

4 and 5



WWW.CHBYRON.EU

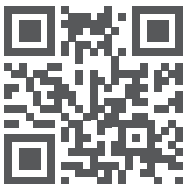

Or contact us directly:

EU address:	UK address:
smartwares Europe	smartwares Safety and Lighting Ltd.
Jules Verneweg 87 5015 BH Tilburg The Netherlands	Meriden House, 6 Great Combow Halesowen, West Midlands, B63 3AB
www.chbyron.eu	United Kingdom

Frequency band: 433.92MHz (433.050 - 434.790 MHz)
Maximum radio frequency power <+10dBm
Range: 100 meters

Touch free button DBY-23430
Power supply: 1x CR2450 (included)
IP44 Weather Resistant



Find us on



UK
CA

CE Conforms to all relevant
European Directives.