

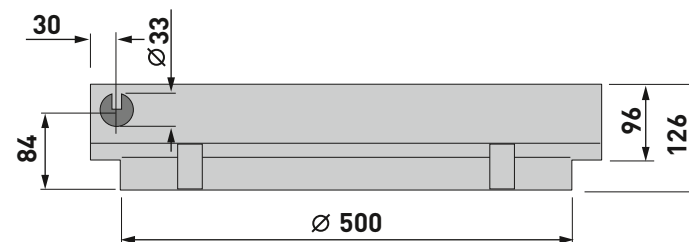
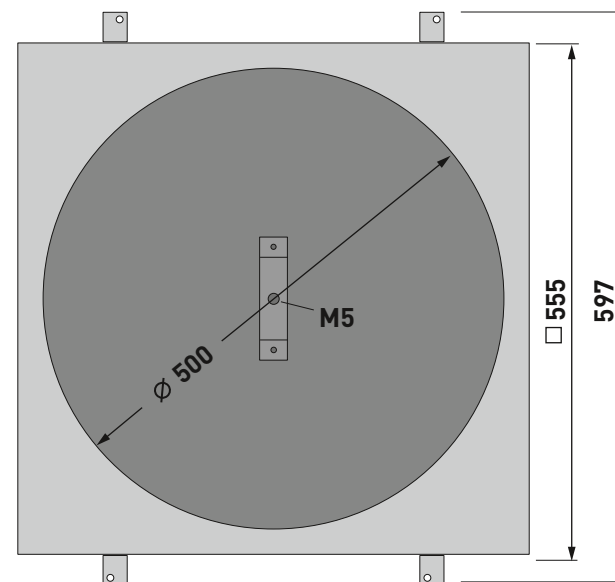


- de **Montageanleitung**
- en **Mounting instructions**
- fr **Instructions de montage**
- it **Istruzioni di montaggio**
- es **Instrucciones de montaje**
- nl **Montagehandleiding**

# PolaronIQ WD2 BE

10125433 / XI 17

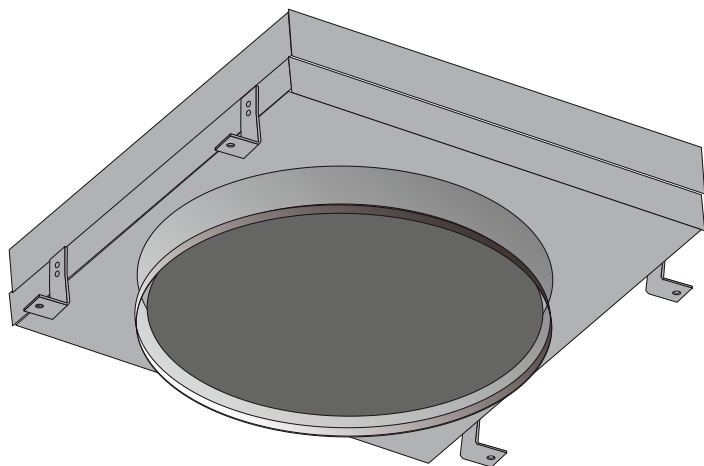

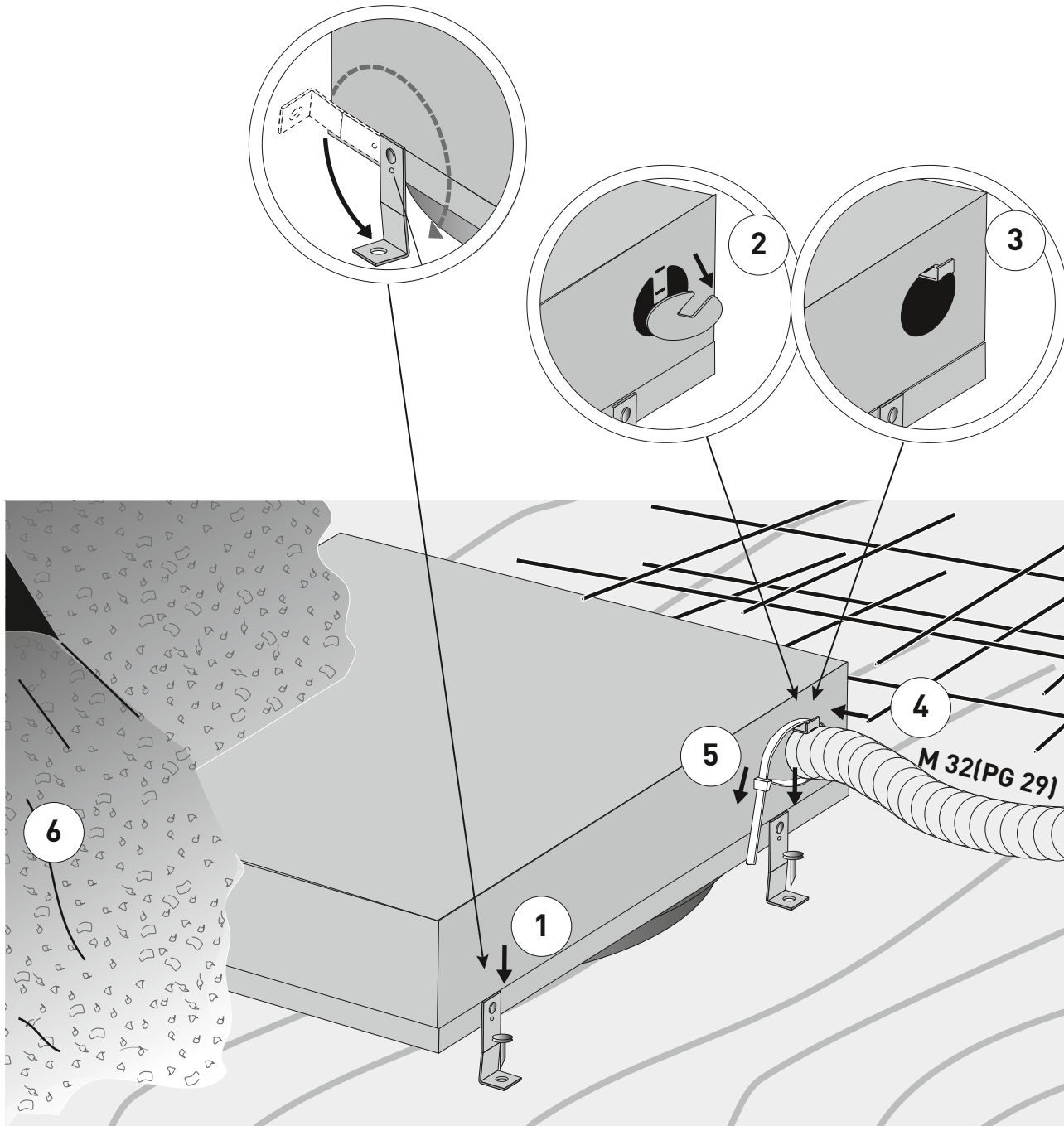

- de Maximale Schichtdicke 10 mm
- en Maximum thickness 10 mm
- fr Epaisseur de la couche maximale 10 mm
- it Spessore massimo 10 mm
- es Espesor de capa máximo 10 mm
- nl Maximale laagdikte 10 mm

