




## Spare Part List – Engine

FN 960189c02

BN 2612922

RE: TOOLCRAFT Inverter Power Generator 3.4KW 69dB

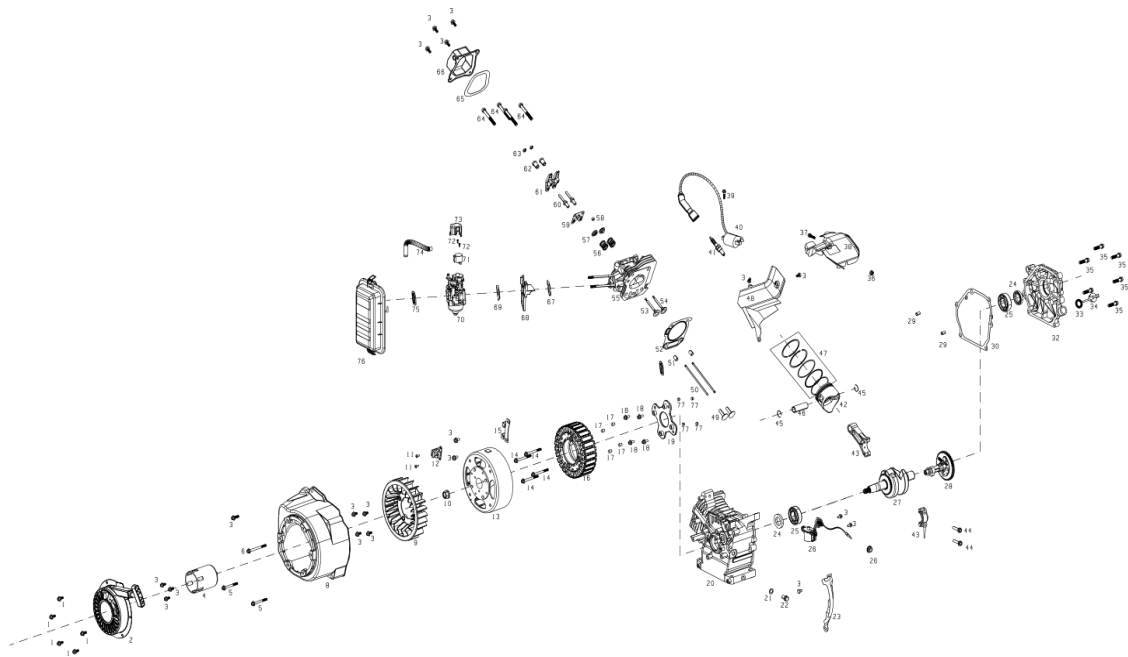

REF.NO.	CUSTOMER PART NO.	DESCRIPTION
1	3500ig.e1	Flange Bolt M6
2	3500ig.e2	Recoil Srarter Ass'Y
3	3500ig.e3	Flange Bolt M6
4	3500ig.e4	Starting Pulley
5	3500ig.e5	Flange Bolt M6
6	3500ig.e6	Flange Bolt M6
8	3500ig.e8	Engine Air Scooper
9	3500ig.e9	Engine Impeller
10	3500ig.e10	Flange Nut M14
11	3500ig.e11	Cr Bolt M4
12	3500ig.e12	Ignition Trigger
13	3500ig.e13	Rotor Ass'Y
14	3500ig.e14	Flange Bolt M6



## Spare Part List – Engine

---

15	3500ig.e15	Ignition Trigger Bracket
16	3500ig.e16	Stator Ass'Y (3500lg)
17	3500ig.e17	Pin
18	3500ig.e18	Bolt 8*32
19	3500ig.e19	Stator Placing Board
20	3500ig.e20	Crankcase
21	3500ig.e21	Aluminium Washer
22	3500ig.e22	Oil Draining Bolt M10
23	3500ig.e23	Engine Windshield Side
24	3500ig.e24	Oil Seal 25X41.5X6
25	3500ig.e25	Bearing Ball Radial 6205
26	3500ig.e26	Oil Level Sensor
26-1	3500ig.e26-1	Nut M10
27	3500ig.e27	Crankshaft
28	3500ig.e28	Camshaft
29	3500ig.e29	Pin 9X14
30	3500ig.e30	Crank Case Gasket
32	3500ig.e32	Crank Case Cover
33	3500ig.e33	Dipstick Seal Rubber
34	3500ig.e34	Oil Dipstick
35	3500ig.e35	Flange Bolt M8
36	3500ig.e36	Flange Nut M6
37	3500ig.e37	Flange Bolt M6
38	3500ig.e38	Engine Windshield Top
39	3500ig.e39	Flange Bolt M6
40	3500ig.e40	Ignition Coil
41	3500ig.e41	Spark Plug
42	3500ig.e42	Piston
43	3500ig.e43	Connecting Rod
44	3500ig.e44	Connecting Rod Nut
45	3500ig.e45	Piston Circlip
46	3500ig.e46	Pinson Pin
47	3500ig.e47	Piston Ring Set



## Spare Part List – Engine

---

48	3500ig.e48	Engine Windshield Bottom
49	3500ig.e49	Tappet
50	3500ig.e50	Push-Rod
51	3500ig.e51	Pin 10X114
52	3500ig.e52	Cylinder Head Gasket
53	3500ig.e53	Intake Valve
54	3500ig.e54	Exhaust Valve
55	3500ig.e55	Cylinder Head
56	3500ig.e56	Valve Spring
57	3500ig.e57	Valve Spring Retainer
58	3500ig.e58	Valve Cover
59	3500ig.e59	Push-Rod Mounting Plate
60	3500ig.e60	Rocker Combination 2
61	3500ig.e61	Rocker Combination 3
62	3500ig.e62	Rocker Combination 1
63	3500ig.e63	Rocker Combination 4
64	3500ig.e64	Flange Bolt M8
65	3500ig.e65	Cylinder Head Cover Gasket
66	3500ig.e66	Cylinder Head Cover
67	3500ig.e67	Carburettor Gasket 1
68	3500ig.e68	Carburettor Insulation Pad
69	3500ig.e69	Carburettor Gasket 2
70	3500ig.e70	Carburettor
71	3500ig.e71	Stepper Motor
72	3500ig.e72	Cr Bolt Set M4
73	3500ig.e73	Stepper Motor Rubber Cover
74	3500ig.e74	Air Tube
75	3500ig.e75	Air Filter Gasket
76	3500ig.e76	Air Filter Ass'Y
77	3500ig.e77	Pin