


# StylePro

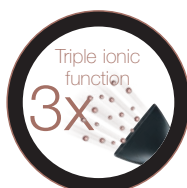

## HC 50 Haartrockner

- Triple Ionic Funktion - zuschaltbare Ionen-Funktion in 3 Stufen zur individuellen Anpassung an jeden Haartyp
- Ionen-Technologie für geschmeidiges und glänzendes Haar
- Protection Funktion schützt das Haar und bewahrt die Farbbrillanz
- Arretierbare Kaltstufe - zur Fixierung des Stylings
- 3 Heizstufen und 2 Gebläsestufen
- Schmale Profidüse und Volumen-Diffusor
- Soft Touch Oberfläche
- Abnehmbarer Sicherheitsfilter - für leichte Reinigung
- Automatischer Überhitzungsschutz
- Aufhängeöse - zum einfachen Aufbewahren
- Leistungsstarke 2200 W - für schnelles Trocknen
- 220 - 240V ~ 50/60Hz max. 2200 W
- Produktmaße (LxBxH): 28 x 30 x 8,6 cm
- Produktgewicht: ca. 686 g
- 3 Jahre Garantie
- VE: 4 / Transportkarton: -
- EAN-Nr.: 4211125 59114 4
- Art.-Nr.: 591.14

## HC 50 Hair Dryer

- Triple Ionic Function - optional 3-stage ion function for personalised use with every hair type
- Ion technology for sleek and shiny hair
- The protection function protects your hair and retain the colour brilliance
- Lockable cold air setting - for long lasting styling
- 3 heat levels and 2 fan speeds
- Narrow professional nozzle and volume diffuser
- Soft Touch Surface
- Removable Safety Filter for easy cleaning
- Automatic overheat protection
- Loop for hanging - for easy storage
- Powerful 2200 W - for fast drying
- 220 - 240V ~ 50/60Hz max. 2200 W
- Product measurements (LxWxH): 28 x 30 x 8.6 cm
- Product weight: approx. 686 g
- 3 year guarantee
- Sales unit: 4 / Shipping carton: -
- EAN no.: 4211125 59114 4
- Item no.: 591.14