
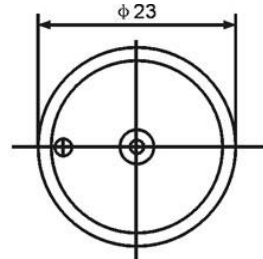



Data Sheet

Piezo buzzer (Pin)

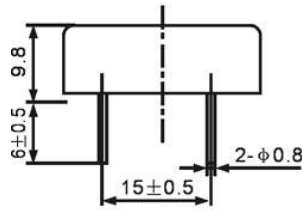

Unit: mm

Frequency response:

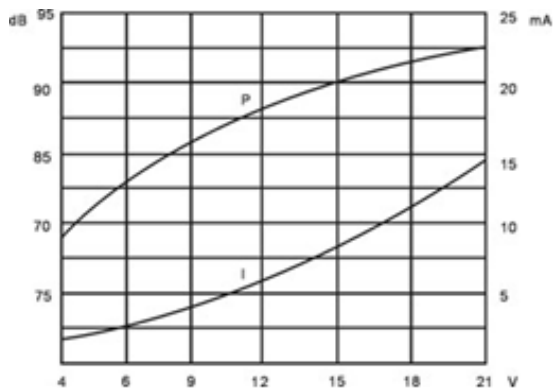

Technical data

Rated voltage	12VDC
Operating voltage	1V-30VDC
Max Rated current	4mA at 12VDC
Min Sound Pressure Level	80dB at 12VDC/20cm
Resonant Frequency	3500±500Hz
Sound tone	Continuous
Operating temperature	-20°C to +60°C
Storage Temperature	-20°C to +60°C
Housing material/color	ABS/black
Weight	3g