

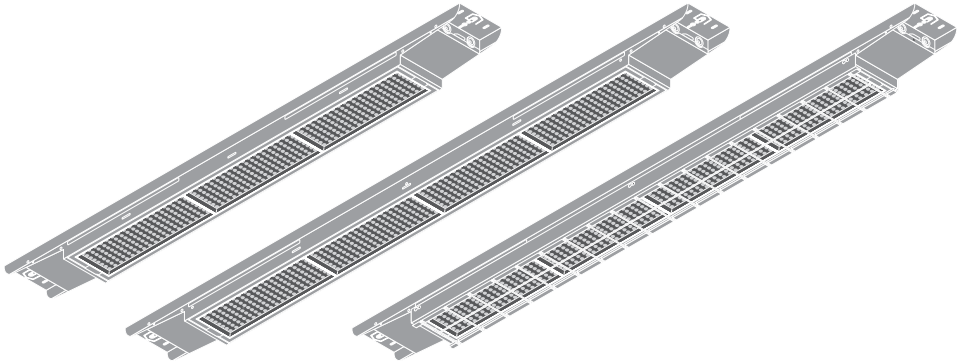
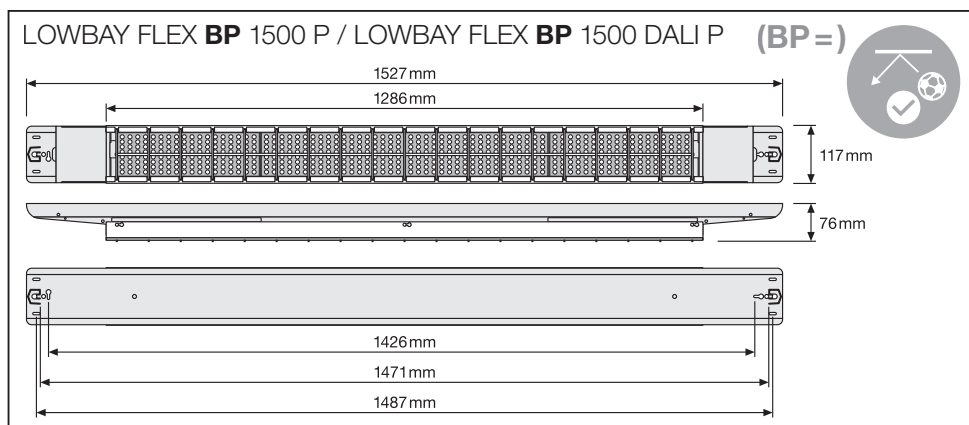






LOWBAY FLEX P / LOWBAY FLEX BP P

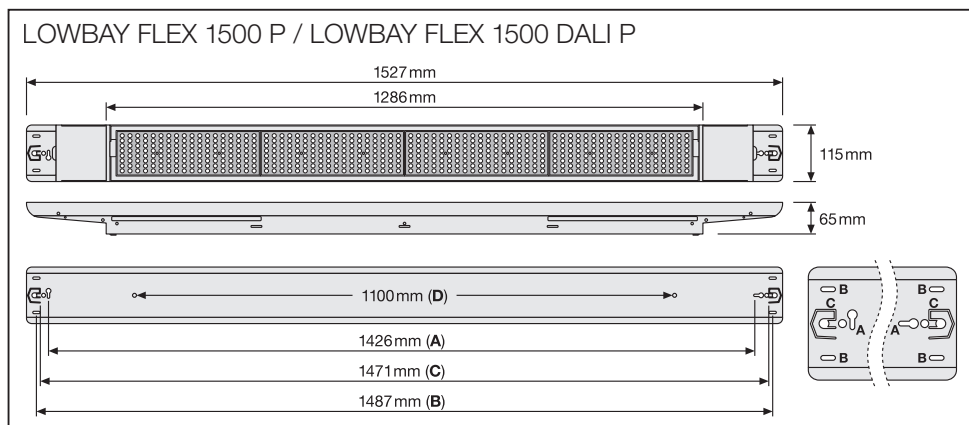



	EAN	l x w x h [mm]	W	V	Hz	lm	lm/W	K
LB FLEX 1200 P 42W 840 W	4058075676060	1236 x 115 x 65	42	220-240V	50/60Hz	6510	155	4000
LB FLEX 1200 P 42W 840 VW	4058075676084	1236 x 115 x 65	42	220-240V	50/60Hz	6510	155	4000
LB FLEX 1200 P 73W 840 W	4058075676107	1236 x 115 x 65	73	220-240V	50/60Hz	11315	155	4000
LB FLEX 1200 P 73W 840 VW	4058075676121	1236 x 115 x 65	73	220-240V	50/60Hz	11315	155	4000
LB FLEX 1500 P 105W 840 N	4058075676244	1527 x 115 x 65	105	220-240V	50/60Hz	16800	160	4000
LB FLEX 1500 P 105W 840 W	4058075676268	1527 x 115 x 65	105	220-240V	50/60Hz	16800	160	4000
LB FLEX 1500 P 105W 840 VW	4058075676282	1527 x 115 x 65	105	220-240V	50/60Hz	16800	160	4000
LB FLEX BP 1500 P 105W 840 W	4058075676367	1527 x 117 x 76	105	220-240V	50/60Hz	16275	155	4000
LB FLEX 1200 DALI P 42W 840 W	4058075676145	1236 x 115 x 65	42	220-240V	0/50/60Hz	6510	155	4000
LB FLEX 1200 DALI P 42W 840 VW	4058075676169	1236 x 115 x 65	42	220-240V	0/50/60Hz	6510	155	4000
LB FLEX 1200 DALI P 73W 840 W	4058075676206	1236 x 115 x 65	73	220-240V	0/50/60Hz	11315	155	4000
LB FLEX 1200 DALI P 73W 840 VW	4058075676220	1236 x 115 x 65	73	220-240V	0/50/60Hz	11315	155	4000
LB FLEX 1500 DALI P 105W 840 N	4058075676305	1527 x 115 x 65	105	220-240V	0/50/60Hz	16800	160	4000
LB FLEX 1500 DALI P 105W 840 W	4058075676329	1527 x 115 x 65	105	220-240V	0/50/60Hz	16800	160	4000
LB FLEX 1500 DALI P 105W 840 VW	4058075676343	1527 x 115 x 65	105	220-240V	0/50/60Hz	16800	160	4000
LB FLEX BP 1500 DALI P 105W 840 W	4058075676381	1527 x 117 x 76	105	220-240V	0/50/60Hz	16275	155	4000

	EAN	IP	IK	∇	R _a	°(°C)	PF	👤
LB FLEX 1200 P 42W 840 W	4058075676060	23	08	90	≥ 80	-25...+50	≥ 0.9	3.40 kg
LB FLEX 1200 P 42W 840 VW	4058075676084	23	08	120	≥ 80	-25...+50	≥ 0.9	3.40 kg
LB FLEX 1200 P 73W 840 W	4058075676107	23	08	90	≥ 80	-25...+50	≥ 0.9	3.40 kg
LB FLEX 1200 P 73W 840 VW	4058075676121	23	08	120	≥ 80	-25...+50	≥ 0.9	3.40 kg
LB FLEX 1500 P 105W 840 N	4058075676244	23	08	60	≥ 80	-25...+50	≥ 0.9	4.45 kg
LB FLEX 1500 P 105W 840 W	4058075676268	23	08	90	≥ 80	-25...+50	≥ 0.9	4.45 kg
LB FLEX 1500 P 105W 840 VW	4058075676282	23	08	120	≥ 80	-25...+50	≥ 0.9	4.45 kg
LB FLEX BP 1500 P 105W 840 W	4058075676367	23	08	90	≥ 80	-25...+50	≥ 0.9	6.00 kg
LB FLEX 1200 DALI P 42W 840 W	4058075676145	23	08	90	≥ 80	-25...+50	≥ 0.9	3.50 kg
LB FLEX 1200 DALI P 42W 840 VW	4058075676169	23	08	120	≥ 80	-25...+50	≥ 0.9	3.50 kg
LB FLEX 1200 DALI P 73W 840 W	4058075676206	23	08	90	≥ 80	-25...+50	≥ 0.9	3.50 kg
LB FLEX 1200 DALI P 73W 840 VW	4058075676220	23	08	120	≥ 80	-25...+50	≥ 0.9	3.50 kg
LB FLEX 1500 DALI P 105W 840 N	4058075676305	23	08	60	≥ 80	-25...+50	≥ 0.9	4.20 kg
LB FLEX 1500 DALI P 105W 840 W	4058075676329	23	08	90	≥ 80	-25...+50	≥ 0.9	4.20 kg
LB FLEX 1500 DALI P 105W 840 VW	4058075676343	23	08	120	≥ 80	-25...+50	≥ 0.9	4.20 kg
LB FLEX BP 1500 DALI P 105W 840 W	4058075676381	23	08	90	≥ 80	-25...+50	≥ 0.9	5.76 kg

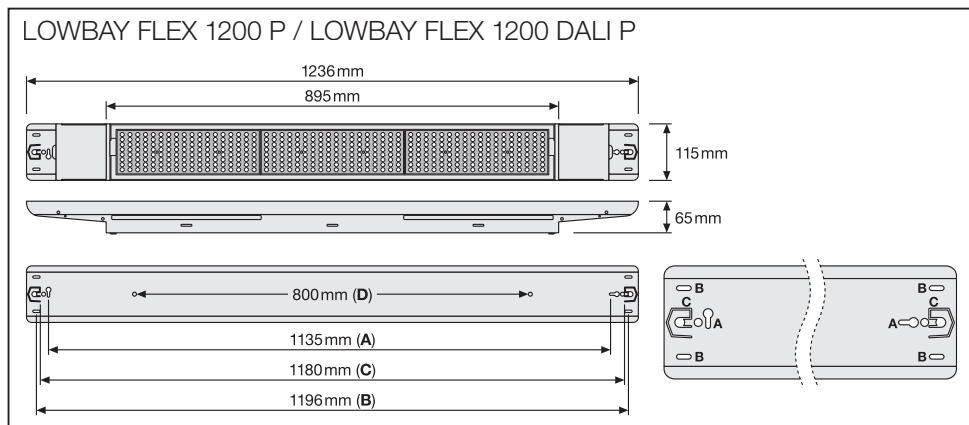


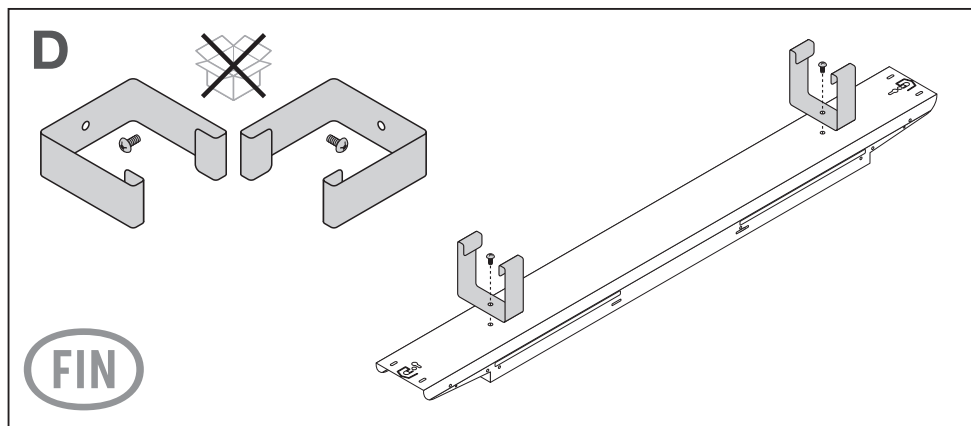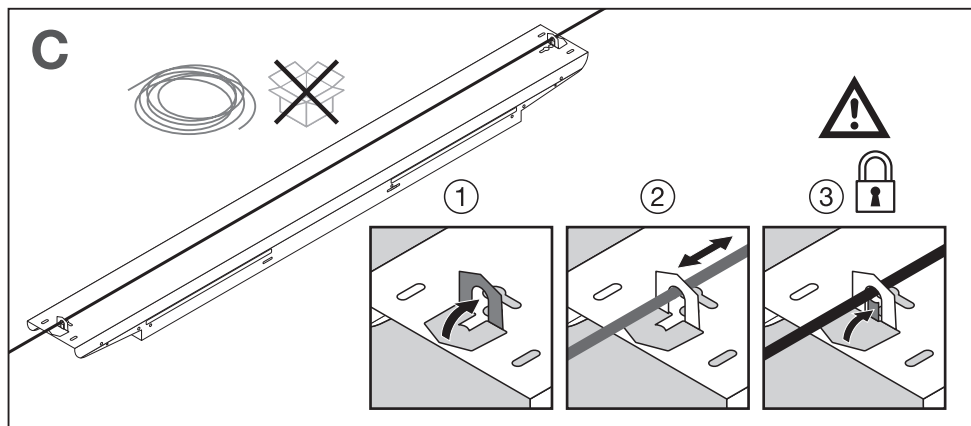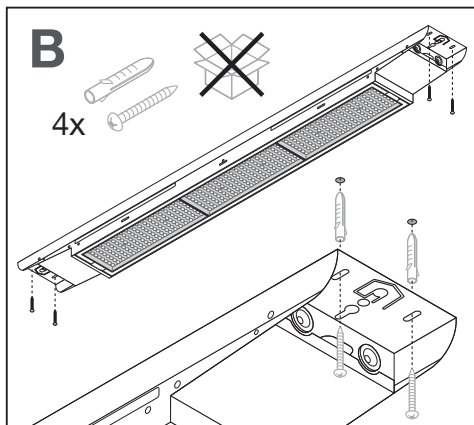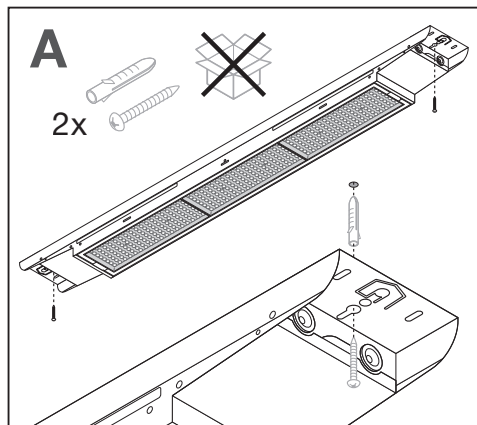


LOWBAY FLEX SUSPENSION KIT
EAN 4058075693722




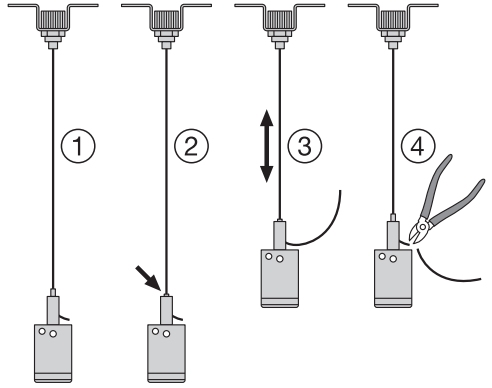
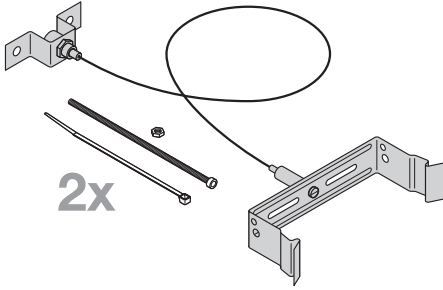





LOWBAY FLEX 1200 P / LOWBAY FLEX 1200 DALI P




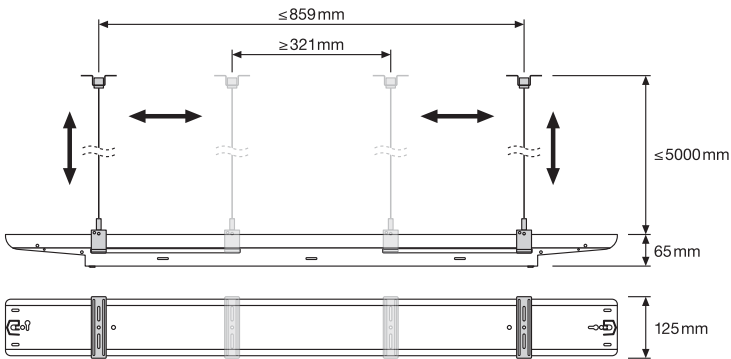









LOWBAY FLEX (BP) 1500 P / LOWBAY FLEX (BP) 1500 DALI P

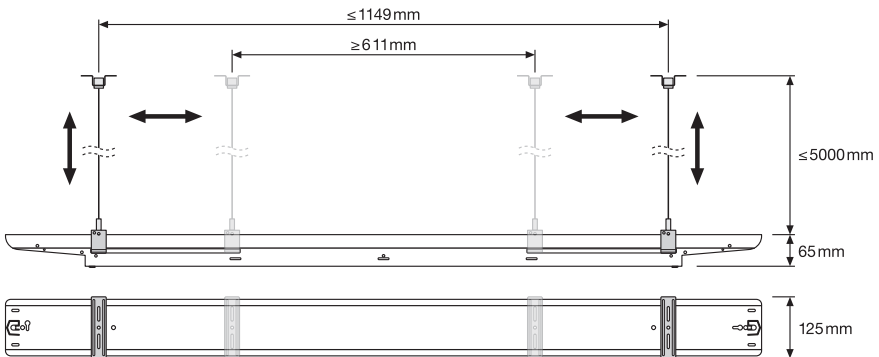

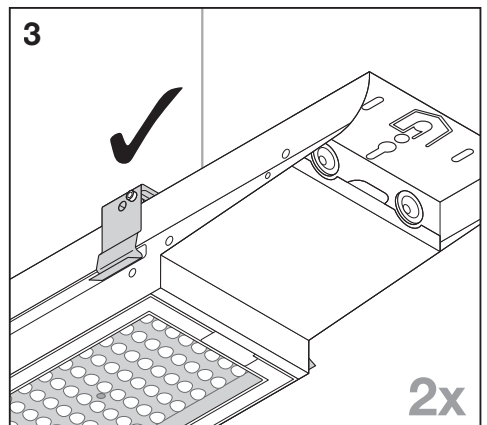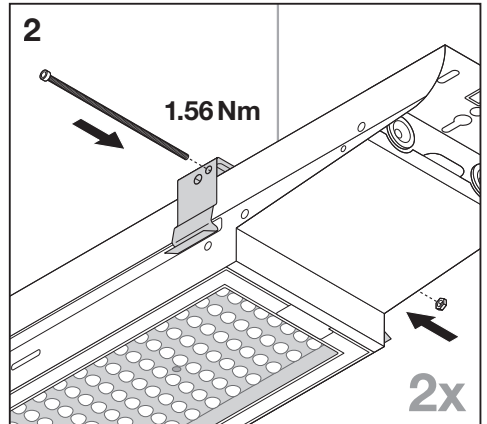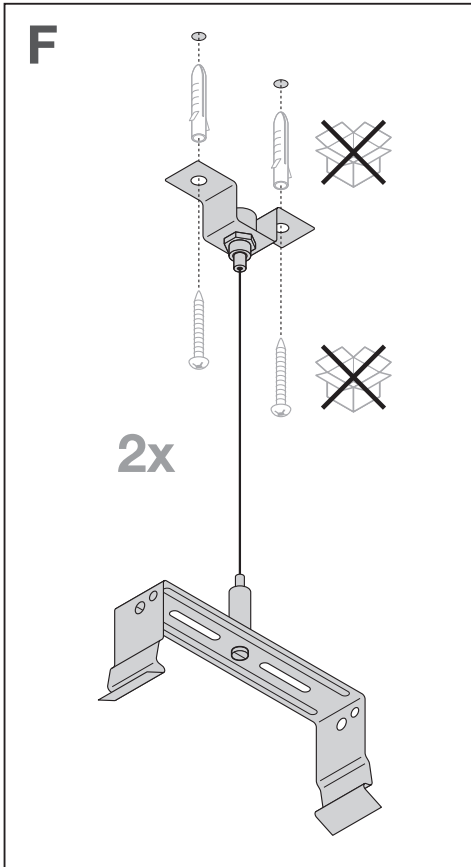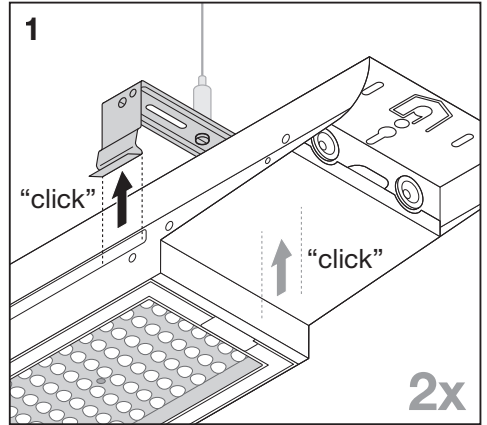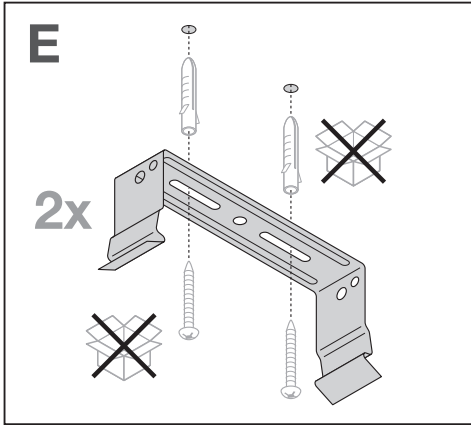

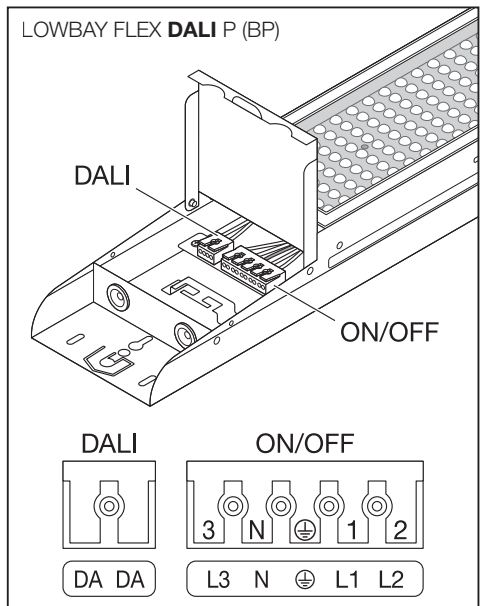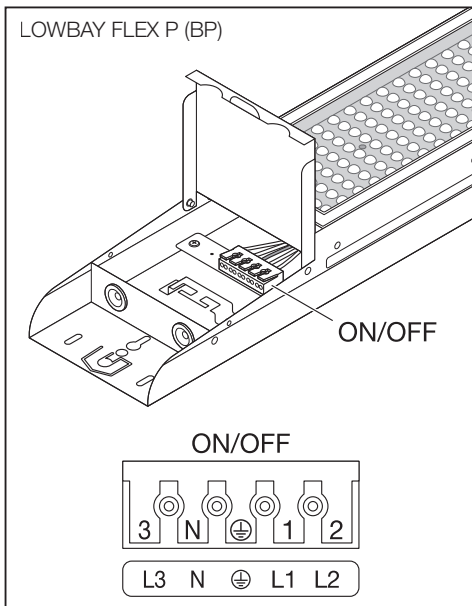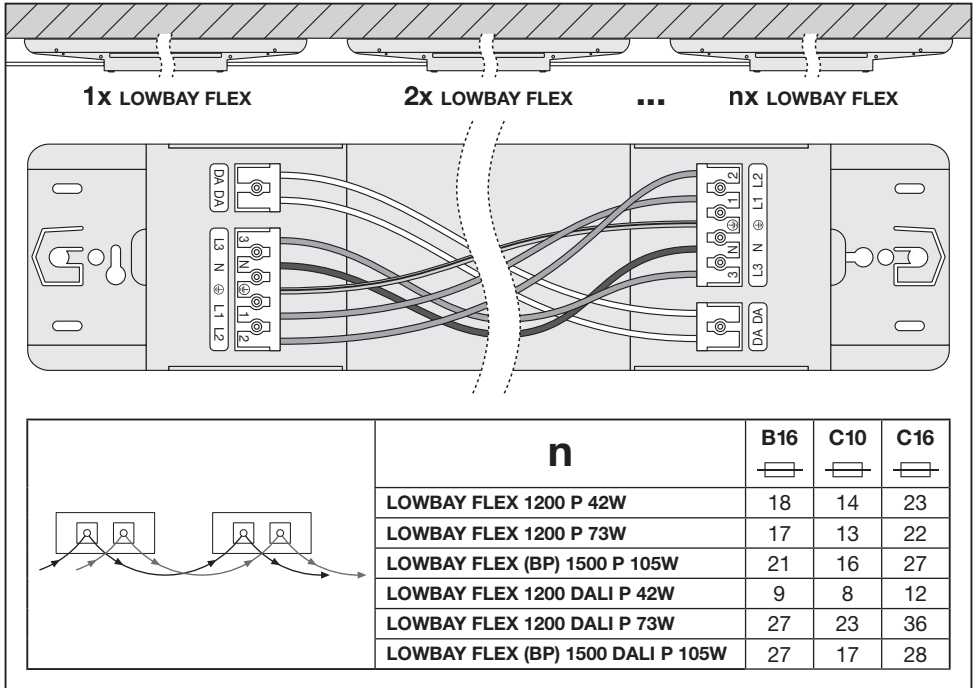

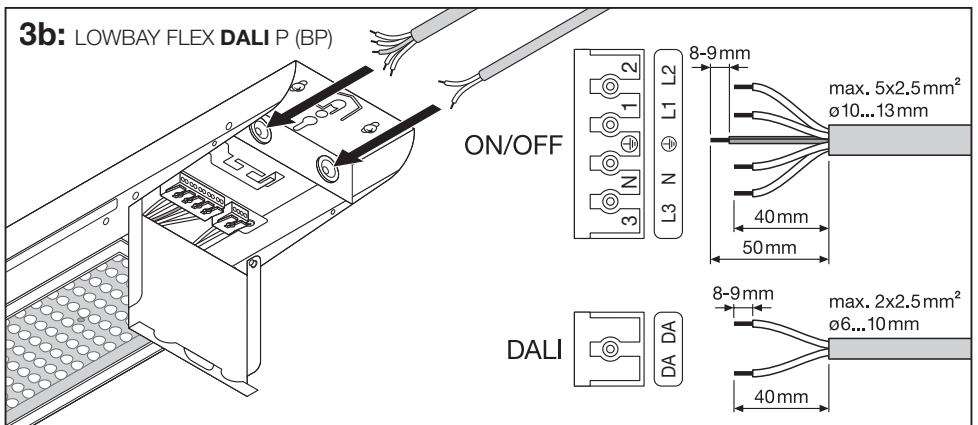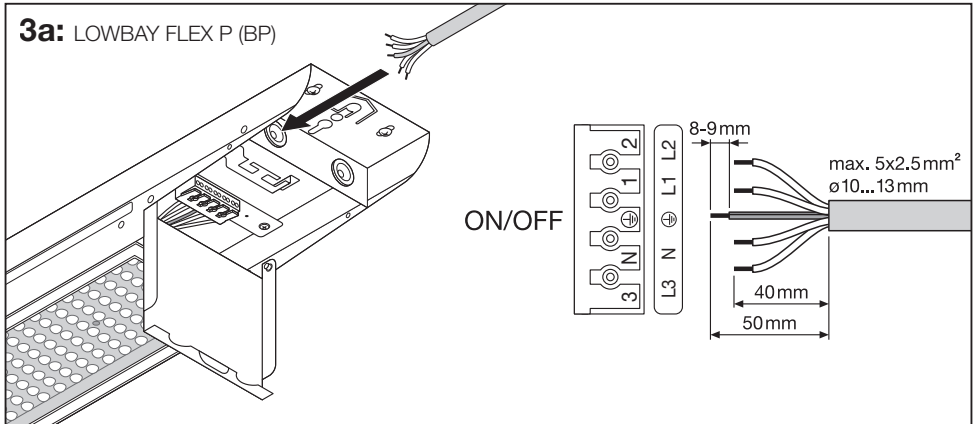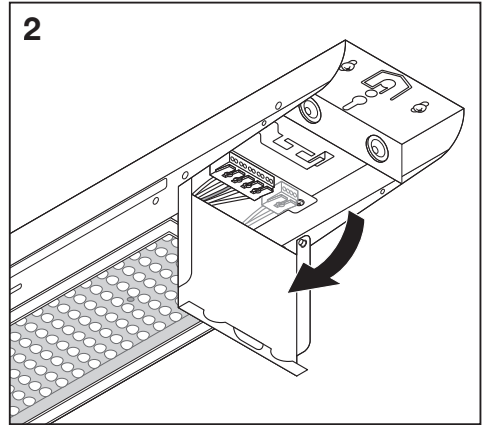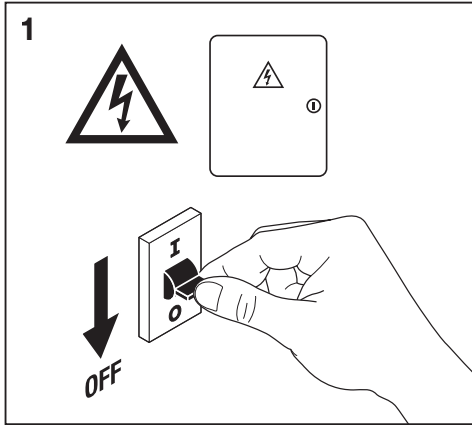

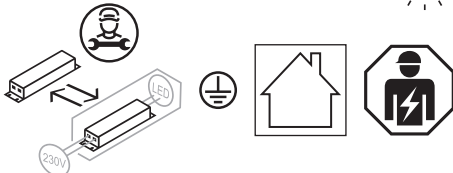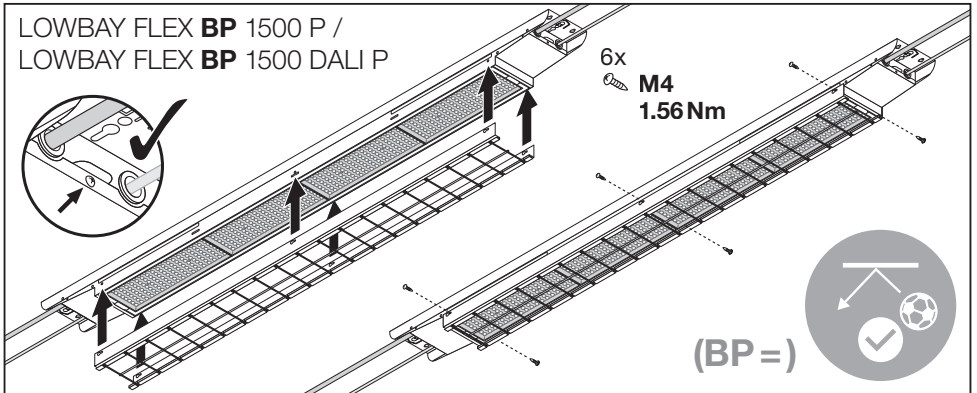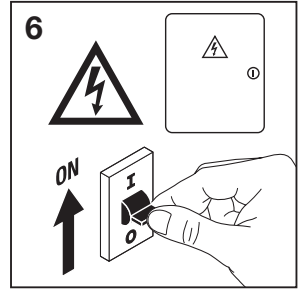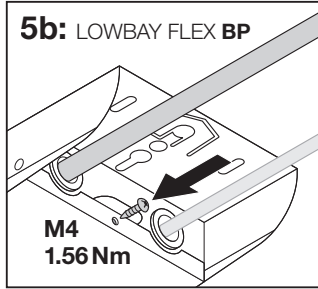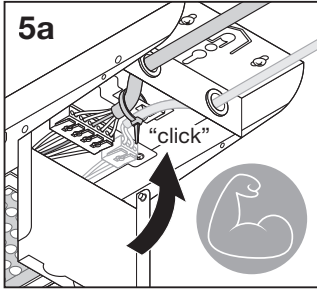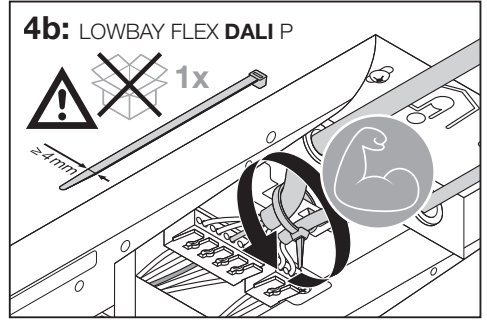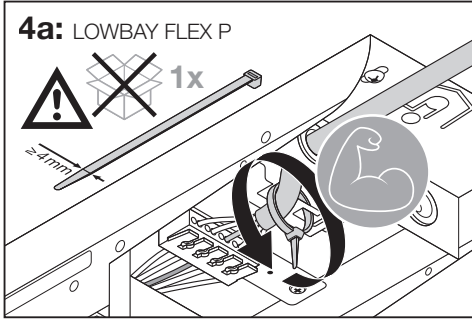

C10449058
G11138985
29.03.22



LEDVANCE GmbH
Steinerne Furt 62
86167 Augsburg, Germany
www.ledvance.com

© LEDVANCE Ltd, Aquila House
Delta Crescent, Westbrook, Warrington
WA5 7NR, United Kingdom