

Series CBX Circuit Breakers

V1.08

Model No. CBA series :



Auto, Manual & Modified Reset Circuit Breakers Specifications

Single Pole Thermal Type Breakers

Applications: Battery chargers, trucks, buses, RVs, trolling motors, etc

Rating: 5-30A, 28Vdc;

Interrupt Rating : 100A@28VDC(5A-10A version);

150A@28VDC(15A version); 200A@28VDC(20A version);

300A@28VDC(25-30A version)

Operating Temperature Rating: -40°F (-40°C) to 185°F (85°C)


Storage Temperature Rating: -40°F (-40°C) to 260°F (125°C)

Termination : Compatible with mini blade type fuse block using 0.32inch (8.1mm) centering spacing.

Compliances: SAE J553 (TYPE I & II & III) Circuit Breakers

Electrical Characteristics :

TRIP TIME VS. PERCENT OF RATED CURRENT

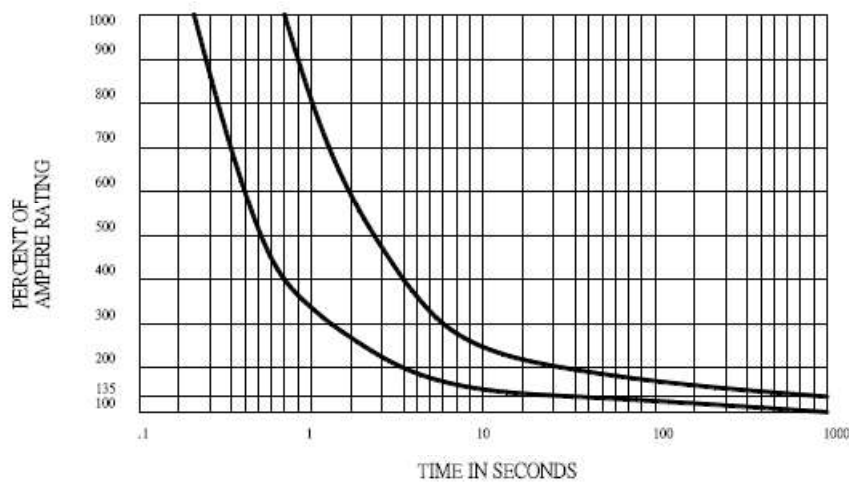

Color Code :


AMP RATING	BODY COLOR
5	TAN
7.5	BROWN
10	RED
15	BLUE
20	YELLOW
25	WHITE
30	GREEN

HANSOR PTC

瀚新科技股份有限公司 Hansor Polymer Technology Corp.

新北市中和區連城路222巷11號2樓 2F, No.11, Lane 222, Liancheng Rd., Zhonghe City, Taipei, Taiwan. TEL:886-2-22220101 (REP.)FAX:886-2-22228080

Dimension :

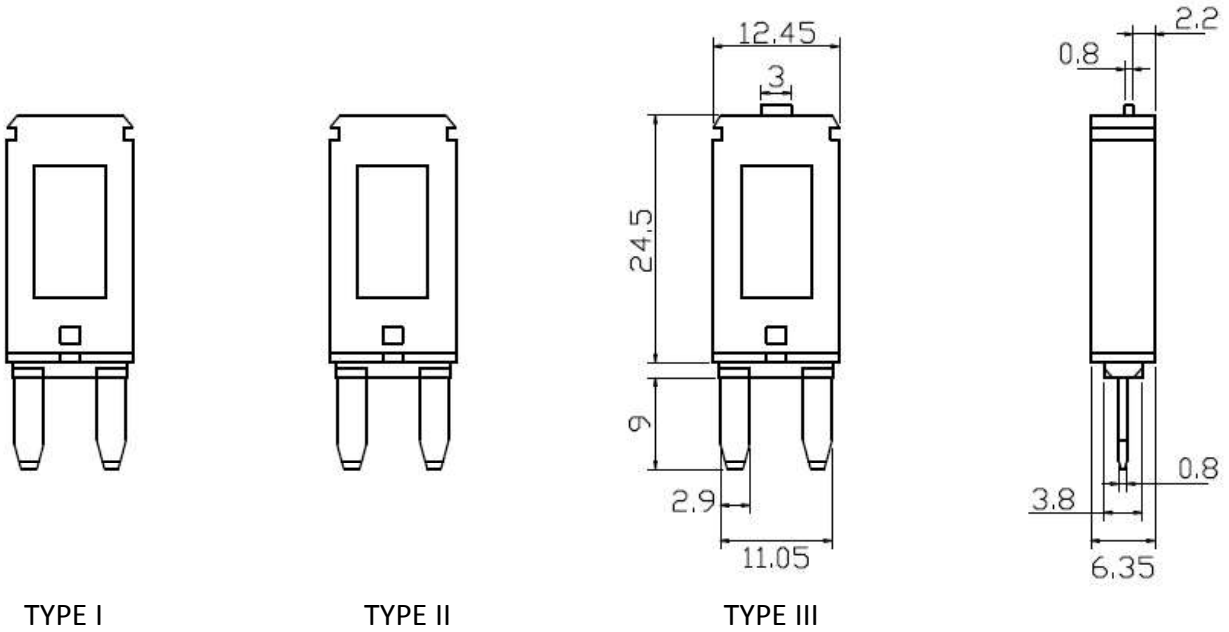

Ordering Information:

Series	Type		Rating	Voltage
CB A	<input type="checkbox"/>	—	<input type="checkbox"/> <input type="checkbox"/>	<input type="checkbox"/> <input type="checkbox"/>
CBA - Plastic cover	1 - TYPE I (auto reset)		05 - 5 amps	14 - 14 volt (for type I & II)
	2 - TYPE II (modified reset)		10 - 10 amps	28 - 28 volt (for type III)
	3 - TYPE III (manual reset)		15 - 15 amps	
			20 - 20 amps	
			25 - 25 amps	
			30 - 30 amps	

HANSOR PTC