


## Data Sheet

### Metal plug cap

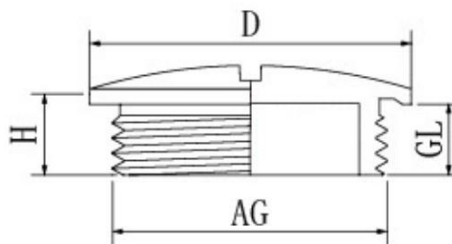

- Material: Nickel-plated brass
- O-ring: NBR, Silicone rubber
- Protection degree: IP54
- Temperature: Static state -40 - 100°C

Item No.	Tread (AG)	(GL)	(H)	Spanner Size (D) mm
		mm	mm	
2758237	PG9	6	9	18
2758238	PG11	6	9	20
2758239	PG13.5	6.5	9.5	22
2758240	PG16	6.5	9.5	24
2758241	PG21	7.5	11	30
2758242	PG29	8	12	40
2758243	PG36	9	15	50
2758244	PG42	10	16	57
2758245	PG48	10	16	64
2758246	M12×1.5	5	8	14
2758247	M16×1.5	6	9	18
2758248	M20×1.5	6.5	9.5	22
2758249	M25×1.5	6.5	10	27
2758250	M32×1.5	7	11	35
2758251	M40×1.5	8	13	45