

Artikel Nr.: 343022

Stehleuchte, Office One Transparent, dimmbar, Weißaluminium RAL 9006, 200-240V AC/50-60Hz, 50,00 W, Neutralweiß

Technische Daten

Charakteristik

Material	Aluminium
Farbe	Weißaluminium RAL 9006
Optik	
im Lieferumfang	inkl. 2,5 m Anschlusskabel mit Anschlussstecker



Elektrische Daten

Leistung / Leistungsaufnahme	50,00 W / 55,00W
Eingangsspannung	200-240V AC/50-60Hz
Eingangsstrom	
Fassung / Sockel	
Anzahl Sockel	
Netzgerät	
Ansteuerung	Touch-Sensor dimmbar
Anschlussmöglichkeit	Netzstecker
Schutzklasse I, II, III	I

Lichttechnische Eigenschaften

Leuchtmittel	LED-Modul fest
Lichtfarbe	Neutralweiß
Farbtemperatur	4000 K
Lichtstrom	6200 lm
Abstrahlwinkel	150°/150°
LED Typ	SMD
LED Anzahl	192
Strahlungsverteilung	578 nm



Artikel Nr.: 343022


Stehleuchte, Office One Transparent, dimmbar, Weißaluminium RAL 9006, 200-240V AC/50-60Hz, 50,00 W, Neutralweiß

Lichtrichtung

Dreh- und Schwenkbereich	feststehend
Neigungswinkel	
Abstrahlverhalten	2 Side
Reflektor / Linse	

Abmessungen und Gewicht

Länge	1950,00
Breite	310,00
Höhe	20,00
Durchmesser	0,00
Gewicht	11900 g

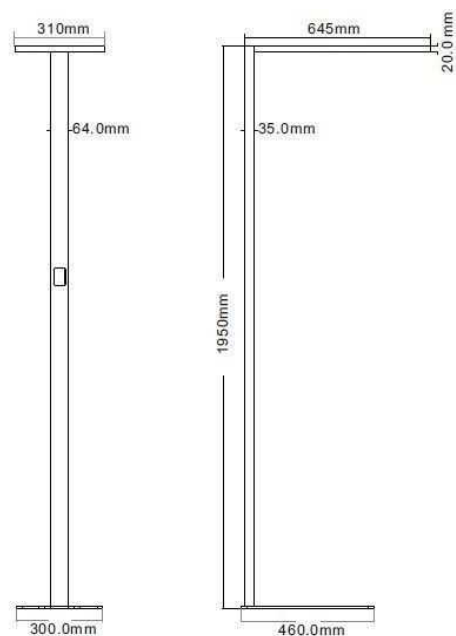

Grenzwerte

Die Überschreitung der Grenzwerte und Betriebsspannung führt zu einer starken Verkürzung der Lebensdauer sowie Zerstörung der LED Module.

Betriebstemperatur	-20°C - +45°C
Lagertemperatur	-40°C - +80°C
IP - Schutzart	IP20

Artikel Nr.: 343022

Stehleuchte, Office One Transparent, dimmbar, Weißaluminium RAL 9006, 200-240V AC/50-60Hz, 50,00 W, Neutralweiß




Allgemeine Eigenschaften

Umwelteigenschaften

Energieeffizienzklasse	
Energieverbrauch	55 kWh/1000h

Lebensdauer

Lebensdauer	50000 h
Lichtstrom Ende Lebensdauer	0,70
Schaltzyklen	25000

IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse I bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern die eine zusätzliche Sicherheitsvorkehrung derart enthält, dass berührbare leitfähige Teile mit Mitteln zum Anschluss an den Schutzleiter der festen Installation ausgerüstet sind, so dass im Fehlerfall der Basisisolierung berührbare leitfähige Teile nicht aktiv werden können.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.
	Die Lichtquelle dieser Leuchte darf nur vom Hersteller oder einem von ihm beauftragten Servicetechniker oder einer vergleichbar qualifizierten Person ersetzt werden

Article no.: 343022

Floor lamp, Office One Transparent, dimmable, White aluminium RAL 9006, 200-240V AC/50-60Hz, 50,00 W, neutral white

Technical Data

General Characteristics

Material	aluminum
Colour	White aluminium RAL 9006
Optics	
included in delivery	incl.2,5 m connector cable with power plug



Electrical Characteristics

Power / power consumption	50,00 W / 55,00W
Input Voltage	200-240V AC/50-60Hz
Input current	
Base (standard designation)	
Number of Bases	
Power supply unit	incl. LED-power supply unit
Electronically reversible	touch switch dimmable
Connection possibility	Powerplug
Protection class I, II, III	I

Light Technical Data

Bulb	LED-module fixed
Colour Designation	neutral white
Colour temperature	4000 K
Luminous flux	6200 lm
Beam angle	150°/150°
LED type	SMD
LED quantity	192
Spectral power distribution	578 nm



Article no.: 343022


Floor lamp, Office One Transparent, dimmable, White aluminium RAL 9006, 200-240V AC/50-60Hz, 50,00 W, neutral white

Light Direction

Rotating and tilting range	fixed
Angle of inclination	
Radiation direction	2 Side
Reflector / lense	

Dimensions & Weight

Length	1950,00
Width	310,00
Height	20,00
Diameter	0,00
Product Weight	11900 g

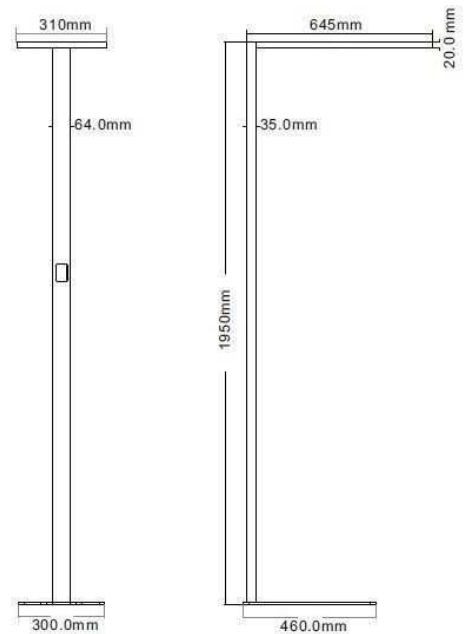

Absolute maximum ratings

The LED will get damaged and the lifetime will decrease when you overrun absolute maximum ratings.

Working temperature	-20°C - +45°C
Storage temperature	-40°C - +80°C
IP - Code	IP20

Article no.: 343022

Floor lamp, Office One Transparent, dimmable, White aluminium RAL 9006, 200-240V AC/50-60Hz, 50,00 W, neutral white

General product data

Environmental Characteristics

Energy label	
Energy consumption	55 kWh/1000h

Lifespan

Lamp life time	50000 h
Luminous flux (end of lifetime)	0,70
Number of switching cycles	25000

IP20 Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.



Lightings of Protection Class I in which the protection against electric shock is not based solely on isolation, but an additional safety measure contains such a way that accessible conductive parts are equipped with means for connection to the protective conductor of the fixed installation, so that in case of failure of the basic insulation exposed conductive parts cannot be active.



Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.



The light source of this luminaire may only be replaced by the manufacturer or by a service technician appointed by him or by a comparable qualified person