

Artikel Nr.: 348078

Deckenaufbauleuchte, Librae Round III, Weiß-matt, 220-240V AC/50-60Hz, 3x max. 50,00 W

Technische Daten**Charakteristik**

Material	Aluminium / Aluminium
Farbe	Weiß-matt / Grau
Optik	
im Lieferumfang	2x Schrauben mit Dübel


**Elektrische Daten**

Leistung	3x max. 50,00 W
Eingangsspannung	220-240V AC/50-60Hz
Eingangsstrom	
Fassung / Sockel	GU10
Anzahl Sockel	3
Netzgerät	
Ansteuerung	dimmbar über optionales Leuchtmittel
Anschlussmöglichkeit	Klemme
Schutzklasse I, II, III	I



Artikel Nr.: 348078

Deckenaufbauleuchte, Librae Round III, Weiß-matt, 220-240V AC/50-60Hz, 3x max. 50,00 W

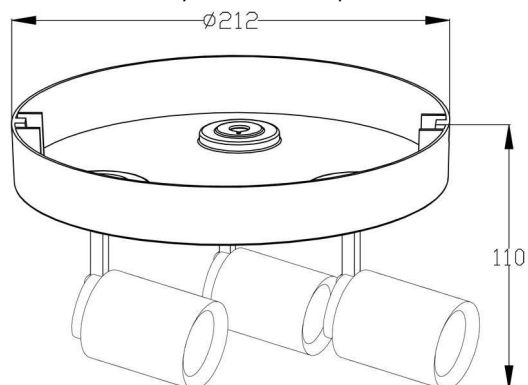

Lichtrichtung

Dreh- und Schwenkbereich	dreh-schwenkbar
Neigungswinkel	90°
Abstrahlverhalten	
Reflektor / Linse	

Abmessungen und Gewicht

Länge	
Breite	
Höhe	110 mm
Durchmesser	65 mm
Deckenabhängung	
Gewicht	1170 g

Sockelmaß


Länge	
Breite	
Höhe	30 mm
Durchmesser	212 mm

Artikel Nr.: 348078

Deckenaufbauleuchte, Librae Round III, Weiß-matt, 220-240V AC/50-60Hz, 3x max. 50,00 W

Grenzwerte

Betriebstemperatur	-5°C - +40°C
Lagertemperatur	-10°C - +40°C
IP - Schutzart	IP20

EEL	Die Leuchte ist geeignet für Leuchtmittel der Energieeffizienzklassen A++ bis E
IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse I bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern die eine zusätzliche Sicherheitsvorkehrung derart enthält, dass berührbare leitfähige Teile mit Mitteln zum Anschluss an den Schutzleiter der festen Installation ausgerüstet sind, so dass im Fehlerfall der Basisisolierung berührbare leitfähige Teile nicht aktiv werden können.

Article no.: 348078

Surface mounted ceiling lamp, Librae Round III, matt white, 220-240V AC/50-60Hz, 3x max. 50,00 W

**Technical Data****General Characteristics**

Material	aluminum / aluminum
Colour	matt white / gray
Optics	
included in delivery	2x screws with dowels


Electrical Characteristics

Power	3x max. 50,00 W
Input voltage	220-240V AC/50-60Hz
Input current	
Base (standard designation)	GU10
Number of bases	3
Power supply unit	
Electronically reversible	dimnable via optional bulb
Connection possibility	clamp
Protection class I, II, III	I



Article no.: 348078

Surface mounted ceiling lamp, Librae Round III, matt white, 220-240V AC/50-60Hz, 3x max. 50,00 W

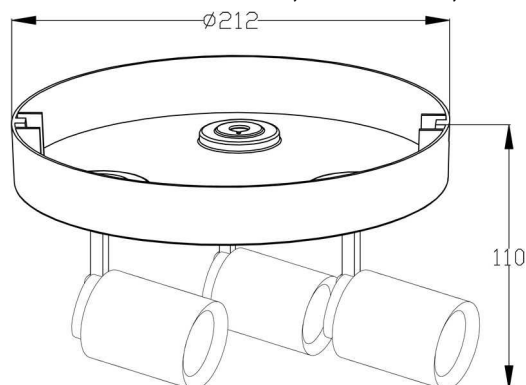**Light Direction**

Rotating and tilting range	rotatable-swivel
Angle of inclination	90°
Radiation direction	
Reflector / lense	

Dimensions & Weight

Length	
Width	
Height	110 mm
Diameter	65 mm
Suspensions from ceiling	
Product Weight	1170 g

Base dimensions


Length	
Width	
Height	30 mm
Diameter	212 mm

Article no.: 348078

Surface mounted ceiling lamp, Librae Round III, matt white, 220-240V AC/50-60Hz, 3x max. 50,00W

Absolute maximum ratings

Working temperature	-5°C - +40°C
Storage temperature	-10°C - +40°C
IP - Code	IP20

EEL	The luminaire is suitable for lamps of energy efficiency classes A++ to E.
IP20	Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.
	Lightings of Protection Class I in which the protection against electric shock is not based solely on isolation, but an additional safety measure contains such a way that accessible conductive parts are equipped with means for connection to the protective conductor of the fixed installation, so that in case of failure of the basic insulation exposed conductive parts cannot be active.
