

Artikel Nr.: 565163

Deckeneinbauleuchte, LED Panel Square 20, Perlhellgrau RAL 9022, 23-24V DC, Neutralweiß

Technische Daten

Charakteristik

Material	Aluminium Druckguss
Farbe	Perlhellgrau RAL 9022
Optik	
im Lieferumfang	



Elektrische Daten

Leistung	16,00 W
Eingangsspannung	23-24V DC
Eingangsstrom	700 mA
Fassung / Sockel	
Anzahl Sockel	
Netzgerät	exkl. LED-Netzgerät
Ansteuerung	dimmbar über optionales Netzgerät
Anschlussmöglichkeit	AMP Stecker
Schutzklasse I, II, III	III



Artikel Nr.: 565163


Deckeneinbauleuchte, LED Panel Square 20, Perlhellgrau RAL 9022, 23-24V DC, Neutralweiß

Lichtrichtung

Dreh- und Schwenkbereich	feststehend
Neigungswinkel	
Abstrahlverhalten	
Reflektor / Linse	symmetrisch

Abmessungen und Gewicht

Länge	237,00
Breite	237,00
Höhe	20,00
Durchmesser	0,00
Einbautiefe	20,00
Gewicht	638 g

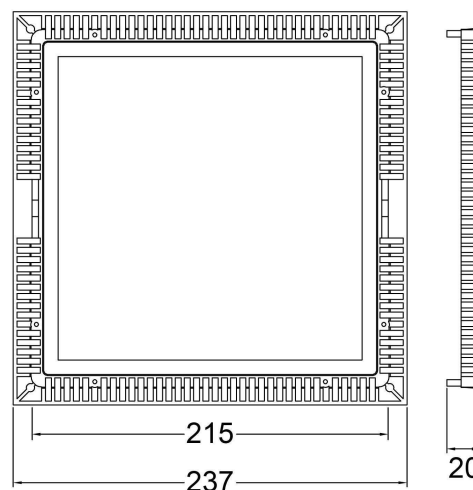

Ausschnittsmaß

Länge	215,00
Breite	215,00
Durchmesser	0,00

Artikel Nr.: 565163

Deckeneinbauleuchte, LED Panel Square 20, Perlhellgrau RAL 9022, 23-24V DC, Neutralweiß

Grenzwerte

Betriebstemperatur	-5°C - +40°C
Lagertemperatur	-10°C - +60°C
IP - Schutzart	IP20

EEI	Dieses Produkt enthält eine Lichtquelle der Energieeffizienzklasse G
IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse III Leuchte, bei der der Schutz gegen elektrischen Schlag auf der Anwendung der Schutzkleinspannung (SELV) beruht und in der Spannungen höher als SELV nicht erzeugt werden.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.

Article no.: 565163

Built in ceiling lamp, LED Panel Square 20, Pearl light grey RAL 9022, 23-24V DC, neutral white

Technical Data**General Characteristics**

Material	aluminum die casting
Colour	Pearl light grey RAL 9022
Optics	
included in delivery	

**Electrical Characteristics**

Power	16,00 W
input voltage	23-24V DC
input current	700 mA
Base (standard designation)	
Number of bases	
Power supply unit	excl. LED-power supply unit
Electronically reversible	dimnable via optional power supply
Connection possibility	AMP plug
Protection class I, II, III	III



Article no.: 565163

Built in ceiling lamp, LED Panel Square 20, Pearl light grey RAL 9022, 23-24V DC, neutral white

Light Direction


Rotating and tilting range	fixed
Angle of inclination	
Radiation direction	
Reflector / lense	symmetrisch

Dimensions & Weight

Length	237,00
Width	237,00
Height	20,00
Diameter	0,00
Mounting Depth	20,00
Product Weight	638 g

Cut-out dimensions

Length	215,00
Width	215,00
Diameter	0,00

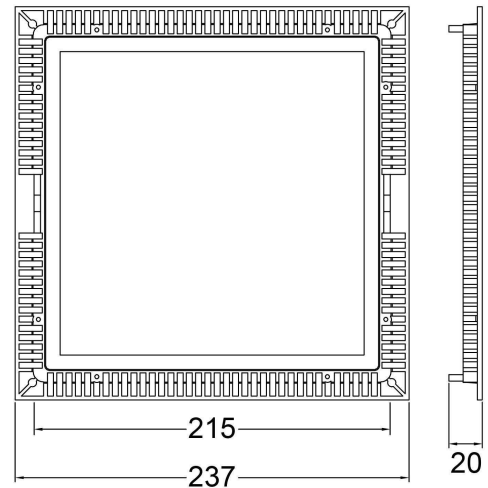

Article no.: 565163

Built in ceiling lamp, LED Panel Square 20, Pearl light grey RAL 9022, 23-24V DC, neutral white

Absolute maximum ratings

Working temperature	-5°C - +40°C
Storage temperature	-10°C - +60°C
IP - Code	IP20

EEL	This product contains a light source of energy efficiency class G
IP20	Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.
	Lightings of Protection Class III Luminaire in which protection against electric shock relies on supply at safety extra-low voltage (SELV) and in which voltages higher than those of SELV are not generated.
	Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.