

Artikel Nr.: 565255

Deckeneinbauleuchte, Ceti 15 Hide, schwarz, 44-45V DC, Warmweiß

Technische Daten

Charakteristik

Material	Aluminium Druckguss
Farbe	schwarz
Optik	
im Lieferumfang	1x Einbautopf, 4x Befestigungswinkel, 8x Schrauben, 2x Haken



Elektrische Daten

Leistung	30,50 W
Eingangsspannung	44-45V DC
Eingangsstrom	700 mA
Fassung / Sockel	
Anzahl Sockel	
Netzgerät	exkl. LED-Netzgerät
Ansteuerung	dimmbar über optionales Netzgerät
Anschlussmöglichkeit	offene Kabel
Schutzklasse I, II, III	III



Artikel Nr.: 565255

Deckeneinbauleuchte, Ceti 15 Hide, schwarz, 44-45V DC, Warmweiß

Lichttrichtung


Dreh- und Schwenkbereich	feststehend
Neigungswinkel	
Abstrahlverhalten	
Reflektor / Linse	symmetrisch

Abmessungen und Gewicht

Länge	370,00
Breite	48,00
Höhe	56,00
Durchmesser	0,00
Einbautiefe	50,00
Gewicht	920 g

Ausschnittsmaß

Länge	372,00
Breite	48,00
Durchmesser	0,00

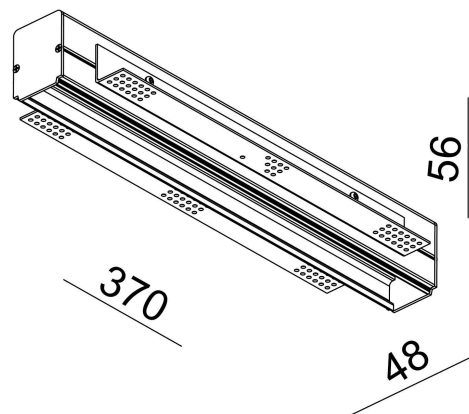

Artikel Nr.: 565255

Deckeneinbauleuchte, Ceti 15 Hide, schwarz, 44-45V DC, Warmweiß

Grenzwerte

Betriebstemperatur	-5°C - +40°C
Lagertemperatur	-10°C - +40°C
IP - Schutzart	IP20

EEI	Dieses Produkt enthält eine Lichtquelle der Energieeffizienzklasse G
IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse III Leuchte, bei der der Schutz gegen elektrischen Schlag auf der Anwendung der Schutzkleinspannung (SELV) beruht und in der Spannungen höher als SELV nicht erzeugt werden.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.

Article no.: 565255

Built in ceiling lamp, Ceti 15 Hide, black, 44-45V DC, warmwhite

Technical Data



General Characteristics

Material	aluminum die casting
Colour	black
Optics	
included in delivery	1x mounting sleeve, 4x mounting angles 8x screws, 2x hooks

Electrical Characteristics

Power	30,50 W
input voltage	44-45V DC
input current	700 mA
Base (standard designation)	
Number of bases	
Power supply unit	excl. LED-power supply unit
Electronically reversible	dimnable via optional power supply
Connection possibility	wire with open ends
Protection class I, II, III	III



Article no.: 565255

Built in ceiling lamp, Ceti 15 Hide, black, 44-45V DC, warmwhite

Light Direction


Rotating and tilting range	fixed
Angle of inclination	
Radiation direction	
Reflector / lense	symmetrisch

Dimensions & Weight

Length	370,00
Width	48,00
Height	56,00
Diameter	0,00
Mounting Depth	50,00
Product Weight	920 g

Cut-out dimensions

Length	372,00
Width	48,00
Diameter	0,00

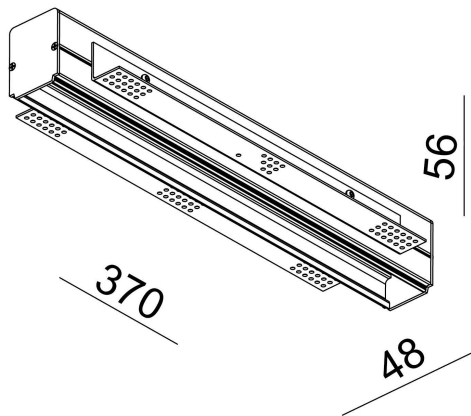

Article no.: 565255

Built in ceiling lamp, Ceti 15 Hide, black, 44-45V DC, warmwhite

Absolute maximum ratings

Working temperature	-5°C - +40°C
Storage temperature	-10°C - +40°C
IP - Code	IP20

EEI	This product contains a light source of energy efficiency class G
IP20	Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.
	Lightings of Protection Class III Luminaire in which protection against electric shock relies on supply at safety extra-low voltage (SELV) and in which voltages higher than those of SELV are not generated.
	Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.