

## Artikel Nr.: 348139

Deckenaufbauleuchte, TRI PROOF Slim 1300, Weiß, 220-240V AC/50-60Hz, 40,00 W, Neutralweiß



### Technische Daten

#### Charakteristik

<b>Material</b>	Kunststoff
<b>Farbe</b>	Weiß
<b>Optik</b>	mattiert
<b>im Lieferumfang</b>	4x Schrauben, 4x Dübel 2x Bügelclip, 2x Schnellmontageclip 1x Kabelanschlusskappe

#### Elektrische Daten

<b>Leistung / Leistungsaufnahme</b>	40,00 W / 40,00 W
<b>Eingangsspannung</b>	220-240V AC/50-60Hz
<b>Eingangsstrom</b>	
<b>Fassung / Sockel</b>	
<b>Anzahl Sockel</b>	
<b>Netzgerät</b>	inkl. LED-Netzgerät
<b>Ansteuerung</b>	nicht dimmbar
<b>Anschlussmöglichkeit</b>	Klemme
<b>Schutzklasse I, II, III</b>	I

#### Lichttechnische Eigenschaften

<b>Leuchtmittel</b>	LED-Modul fest
<b>Lichtfarbe</b>	Neutralweiß
<b>Farbtemperatur</b>	5000 K
<b>Lichtstrom</b>	4575 lm
<b>Abstrahlwinkel</b>	100°
<b>LED Typ</b>	SMD
<b>LED Anzahl</b>	220
<b>Strahlungsverteilung</b>	



**Artikel Nr.: 348139**

Deckenaufbauleuchte, TRI PROOF Slim 1300, Weiß, 220-240V AC/50-60Hz, 40,00 W, Neutralweiß

**Lichtrichtung**

 
Dreh- und Schwenkbereich	drehbar
Neigungswinkel	360 °
Abstrahlverhalten	
Reflektor / Linse	symmetrisch

**Abmessungen und Gewicht**

Länge	1300,00
Breite	0,00
Höhe	0,00
Durchmesser	39,00
Deckenabhängung	0,00
Gewicht	750 g

**Sockelmaß**

Länge	0,00
Breite	0,00
Höhe	0,00
Durchmesser	0,00



**Artikel Nr.: 348139**

Deckenaufbauleuchte, TRI PROOF Slim 1300, Weiß, 220-240V AC/50-60Hz, 40,00 W, Neutralweiß

**Grenzwerte**

Die Überschreitung der Grenzwerte und Betriebsspannung führt zu einer starken Verkürzung der Lebensdauer sowie Zerstörung der LED Module.

Betriebstemperatur	-20°C - +40°C
Lagertemperatur	-40°C - +70°C
IP - Schutzart	IP68/max.2m

**Allgemeine Eigenschaften**

**Umwelteigenschaften**

Energieeffizienzklasse	
Energieverbrauch	40 kWh/1000h

**Lebensdauer**

Lebensdauer	50000 h
Lichtstrom Ende Lebensdauer	0,7
Schaltzyklen	25000

**IP68/max.2m**



Leuchte der Schutzklasse I bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern die eine zusätzliche Sicherheitsvorkehrung derart enthält, dass berührbare leitfähige Teile mit Mitteln zum Anschluss an den Schutzleiter der festen Installation ausgerüstet sind, so dass im Fehlerfall der Basisisolierung berührbare leitfähige Teile nicht aktiv werden können.



Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.



Die Lichtquelle dieser Leuchte darf nur vom Hersteller oder einem von ihm beauftragten Servicetechniker oder einer vergleichbar qualifizierten Person ersetzt werden

## Article no.: 348139

Surface mounted ceiling lamp, TRI PROOF Slim 1300, white, 220-240V AC/50-60Hz, 40,00 W, neutral white



## Technical Data

### General Characteristics

<b>Material</b>	plastic
<b>Colour</b>	white
<b>Optics</b>	matt
<b>included in delivery</b>	4x screws, 4x rawlplugs 2x templeclip, 2x fast assembly clip 1x cable connection cap

### Electrical Characteristics

<b>Power / power consumption</b>	40,00 W / 40,00 W
<b>Input voltage</b>	220-240V AC/50-60Hz
<b>Input current</b>	
<b>Base (standard designation)</b>	
<b>Number of bases</b>	
<b>Power supply unit</b>	incl. LED-power supply unit
<b>Electronically reversible</b>	not dimmable
<b>Connection possibility</b>	clamp
<b>Protection class I, II, III</b>	I

### Light Technical Data

<b>Bulb</b>	LED-module fixed
<b>Colour Designation</b>	neutral white
<b>Colour temperature</b>	5000 K
<b>Luminous flux</b>	4575 lm
<b>Beam angle</b>	100°
<b>LED type</b>	SMD
<b>LED quantity</b>	220
<b>Spectral power distribution</b>	



## Article no.: 348139

Surface mounted ceiling lamp, TRI PROOF Slim 1300, white, 220-240V AC/50-60Hz, 40,00 W, neutral white

### Light Direction


Rotating and tilting range	rotatable
Angle of inclination	360 °
Radiation direction	
Reflector / lense	symmetrisch

### Dimensions & Weight

Length	1300,00
Width	0,00
Height	0,00
Diameter	39,00
Suspensions from ceiling	0,00
Product Weight	750 g

### Base dimensions

Length	0,00
Width	0,00
Height	0,00
Diameter	0,00

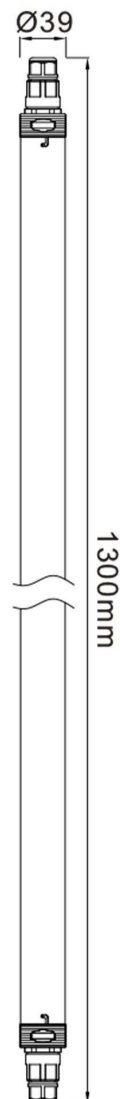

## Article no.: 348139

Surface mounted ceiling lamp, TRI PROOF Slim 1300, white, 220-240V AC/50-60Hz, 40,00 W, neutral white

### Absolute maximum ratings

The LED will get damaged and the lifetime will decrease when you overrun absolute maximum ratings.

Working temperature	-20°C - +40°C
Storage temperature	-40°C - +70°C
IP - Code	IP68/max.2m

### General product data

#### Environmental Characteristics

Energy label	
Energy consumption	40 kWh/1000h

#### Lifespan

Lamp life time	50000 h
Luminous flux (end of lifetime)	0,7
Number of switching cycles	25000

IP68/max.2m



Lightings of Protection Class I

in which the protection against electric shock is not based solely on isolation, but an additional safety measure contains such a way that accessible conductive parts are equipped with means for connection to the protective conductor of the fixed installation, so that in case of failure of the basic insulation exposed conductive parts cannot be active.



Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.



The light source of this luminaire may only be replaced by the manufacturer or by a service technician appointed by him or by a comparable qualified person