

Artikel Nr.: 732084

Boden- / Wand- / Deckenleuchte, Highbay Normae, dunkelgrau, 200-240V AC/50-60Hz, 136,00 W, Neutralweiß



Technische Daten

Charakteristik

Material	Aluminium Druckguss
Farbe	dunkelgrau
Optik	
im Lieferumfang	inkl. verstellbares Befestigungsset DALI STANDARDS IEC62386-101, 102, 207

Elektrische Daten

Leistung / Leistungsaufnahme	136,00 W / 150,00 W
Eingangsspannung	200-240V AC/50-60Hz
Eingangsstrom	
Fassung / Sockel	
Anzahl Sockel	
Netzgerät	
Ansteuerung	DALI-Bus nach IEC 62386 DALI 1.0
Anschlussmöglichkeit	Klemme
Schutzklasse I, II, III	I

Lichttechnische Eigenschaften

Leuchtmittel	LED-Modul fest
Lichtfarbe	Neutralweiß
Farbtemperatur	5000 K
Lichtstrom	16700 lm
Abstrahlwinkel	90°
LED Typ	SMD
LED Anzahl	192
Strahlungsverteilung	570 nm



Artikel Nr.: 732084

Boden- / Wand- / Deckenleuchte, Highbay Normae, dunkelgrau, 200-240V AC/50-60Hz, 136,00 W, Neutralweiß

Lichtrichtung

Dreh- und Schwenkbereich	schwenkbar
Neigungswinkel	180°
Abstrahlverhalten	
Reflektor / Linse	symmetrisch



Abmessungen und Gewicht

Länge	923,00
Breite	126,00
Höhe	99,00
Durchmesser	0,00
Gewicht	6075 g

Grenzwerte

Die Überschreitung der Grenzwerte und Betriebsspannung führt zu einer starken Verkürzung der Lebensdauer sowie Zerstörung der LED Module.

Betriebstemperatur	-20°C - +50°C
Lagertemperatur	-20°C - +50°C
IP - Schutzart	IP65

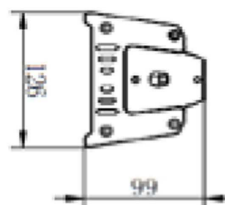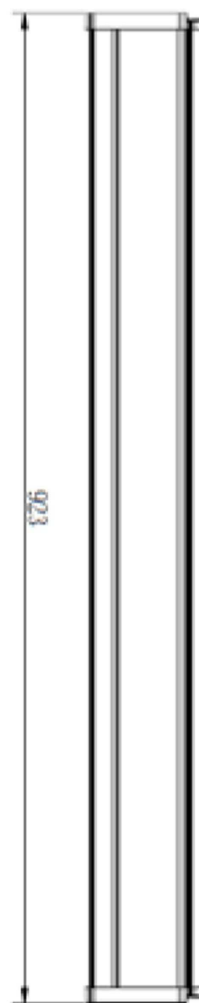

Artikel Nr.: 732084

Boden- / Wand- / Deckenleuchte, Highbay Normae, dunkelgrau, 200-240V AC/50-60Hz, 136,00 W, Neutralweiß


 

Allgemeine Eigenschaften

Umwelteigenschaften

Energieeffizienzklasse	
Energieverbrauch	150 kWh/1000h

Lebensdauer

Lebensdauer	40000 h
Lichtstrom Ende Lebensdauer	0,7
Schaltzyklen	10000

IP65	Schutz gegen das Eindringen von Staub. (Staubdicht) Geschützt gegen Strahlwasser.
	Leuchte der Schutzklasse I bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern die eine zusätzliche Sicherheitsvorkehrung derart enthält, dass berührbare leitfähige Teile mit Mitteln zum Anschluss an den Schutzleiter der festen Installation ausgerüstet sind, so dass im Fehlerfall der Basisisolierung berührbare leitfähige Teile nicht aktiv werden können.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.
	Die Lichtquelle dieser Leuchte darf nur vom Hersteller oder einem von ihm beauftragten Servicetechniker oder einer vergleichbar qualifizierten Person ersetzt werden

Article no.: 732084

Ground- / Wall- / Ceiling lamp, Highbay Normae, dark gray, 200-240V AC/50-60Hz, 136,00 W, neutral white



Technical Data

General Characteristics

Material	aluminum die casting
Colour	dark gray
Optics	
included in delivery	incl. surface mounting bracket set adjustable DALI STANDARDS IEC62386-101, 102

Electrical Characteristics

Power / power consumption	136,00 W / 150,00 W
Input Voltage	200-240V AC/50-60Hz
Input current	
Base (standard designation)	
Number of Bases	
Power supply unit	incl. LED-power supply unit
Electronically reversible	DALI-Bus according to IEC 62386 DALI 1.0
Connection possibility	clamp
Protection class I, II, III	I

Light Technical Data

Bulb	LED-module fixed
Colour Designation	neutral white
Colour temperature	5000 K
Luminous flux	16700 lm
Beam angle	90°
LED type	SMD
LED quantity	192
Spectral power distribution	570 nm



Article no.: 732084

Ground- / Wall- / Ceiling lamp, Highbay Normae, dark gray, 200-240V AC/50-60Hz, 136,00 W, neutral white

Light Direction

Rotating and tilting range	swivel
Angle of inclination	180°
Radiation direction	
Reflector / lense	symmetrisch



Dimensions & Weight

Length	923,00
Width	126,00
Height	99,00
Diameter	0,00
Product Weight	6075 g

Absolute maximum ratings

The LED will get damaged and the lifetime will decrease when you overrun absolute maximum ratings.

Working temperature	-20°C - +50°C
Storage temperature	-20°C - +50°C
IP - Code	IP65

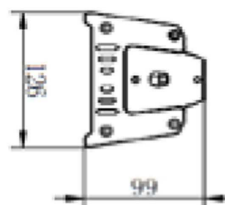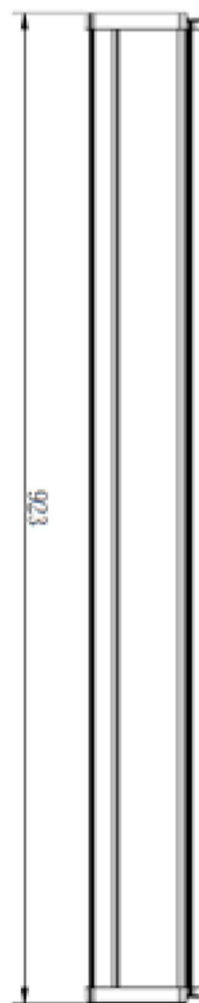

Article no.: 732084

Ground- / Wall- / Ceiling lamp, Highbay Normae, dark gray, 200-240V AC/50-60Hz, 136,00 W, neutral white

General product data

Environmental Characteristics

Energy label	
Energy consumption	150 kWh/1000h

Lifespan

Lamp life time	40000 h
Luminous flux (end of lifetime)	0,7
Number of switching cycles	10000

IP65 Protection against penetration of dust. (complete dust protection) Protection against penetration of water jets.



Lightings of Protection Class I in which the protection against electric shock is not based solely on isolation, but an additional safety measure contains such a way that accessible conductive parts are equipped with means for connection to the protective conductor of the fixed installation, so that in case of failure of the basic insulation exposed conductive parts cannot be active.



Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.



The light source of this luminaire may only be replaced by the manufacturer or by a service technician appointed by him or by a comparable qualified person